


Strip length:	5,60 mm
cable type:	FLRY-B
insulation Ø [mm]:	2,20 - 3,00
seal:	

core:
C-2.75-4.5-19
DPN 10713703


insulation:
IO-3.50-3.5-12
DPN 10713881

anvil:
AS-2.75-3.50-8.8-3.7-0
DPN 10714145

two piece anvil:

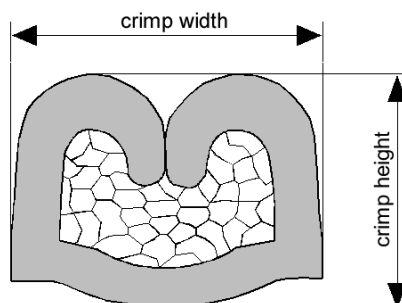[illegible]

DELPHI PN 15344999

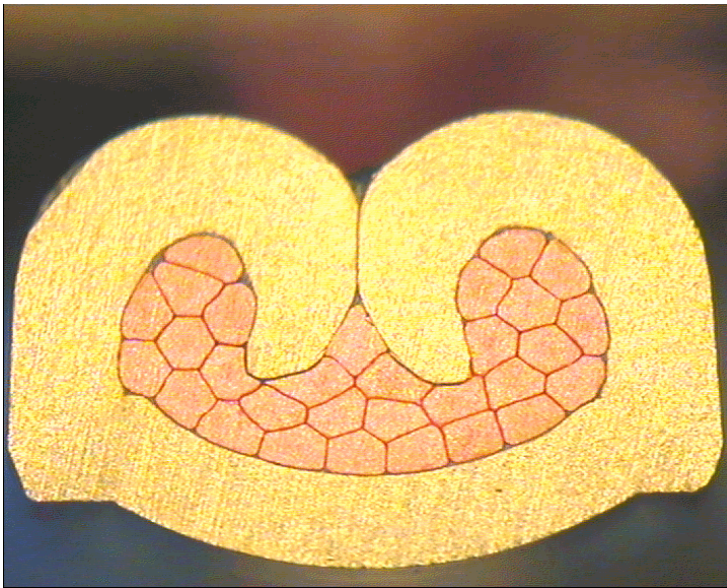

cable:


1,50 mm² = 30 x 0,26 mm

crimp height:

1,85 mm

crimp width:

2,85 mm

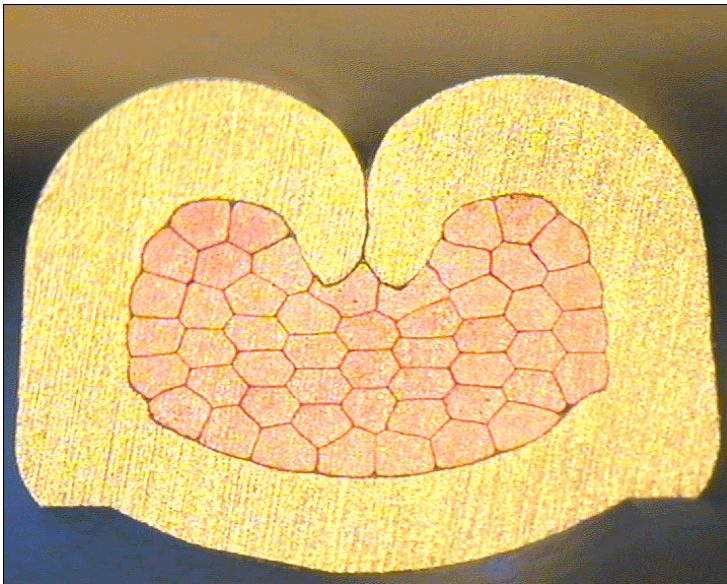

cable:

2,50 mm² = 50 x 0,26 mm

crimp height:

2,05 mm

crimp width:

2,95 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[15344999](#)