
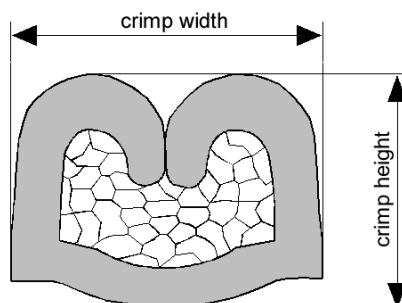


Strip length:	4,00 mm
cable type:	FLRY-B
insulation Ø [mm]:	2,20 - 2,40
seal:	

two piece anvil:
AC-2.30-3.25-A
DPN 10805324
AI-3.00-3.6-0.2
DPN 10806829

[illegible]

DELPHI PN 15458185

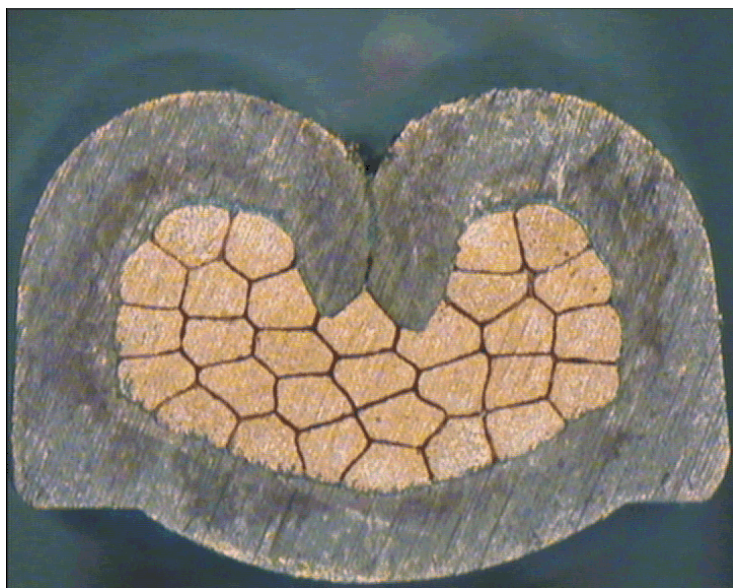

cable:

1,50 mm² = 30 x 0,26 mm

crimp height:

1,50 mm

crimp width:

2,40 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)
[15458185](#)