
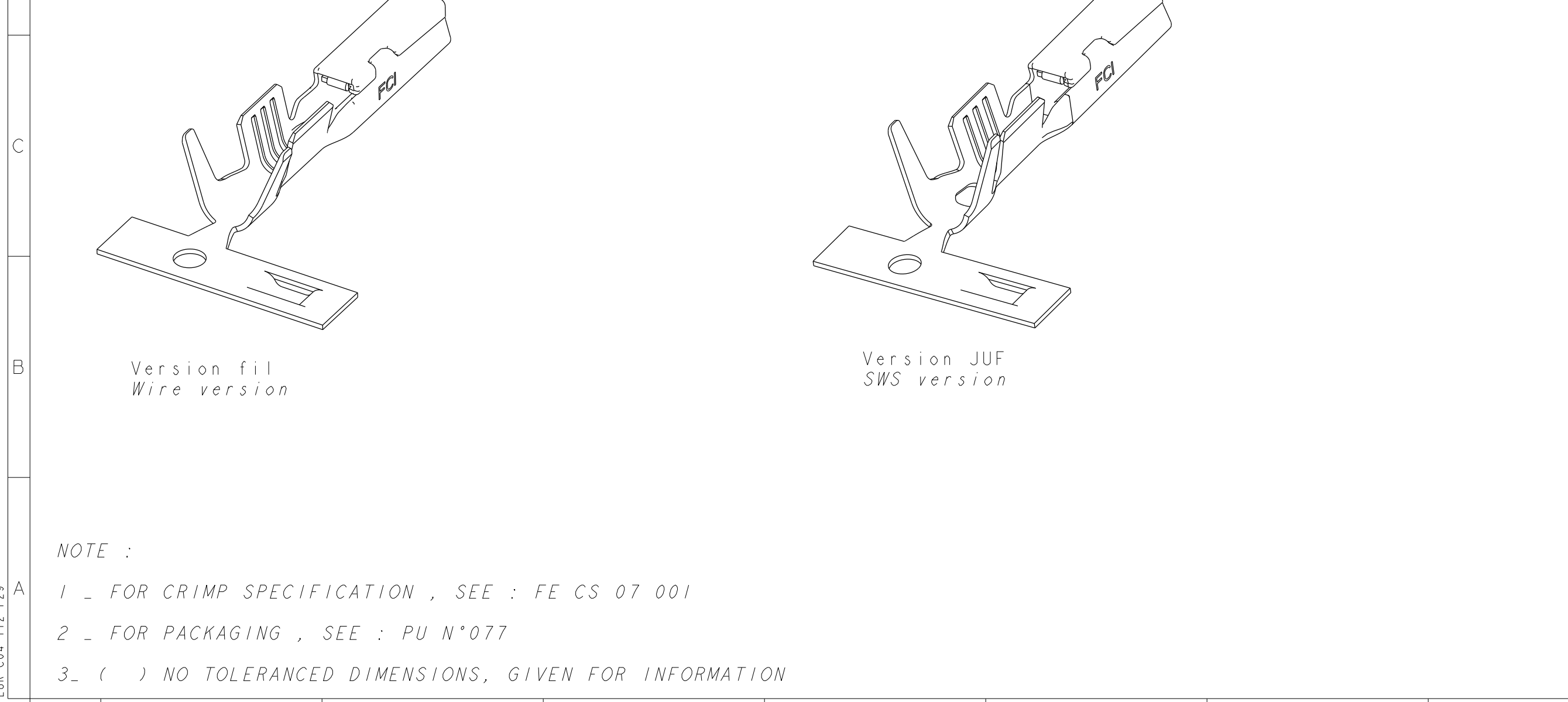
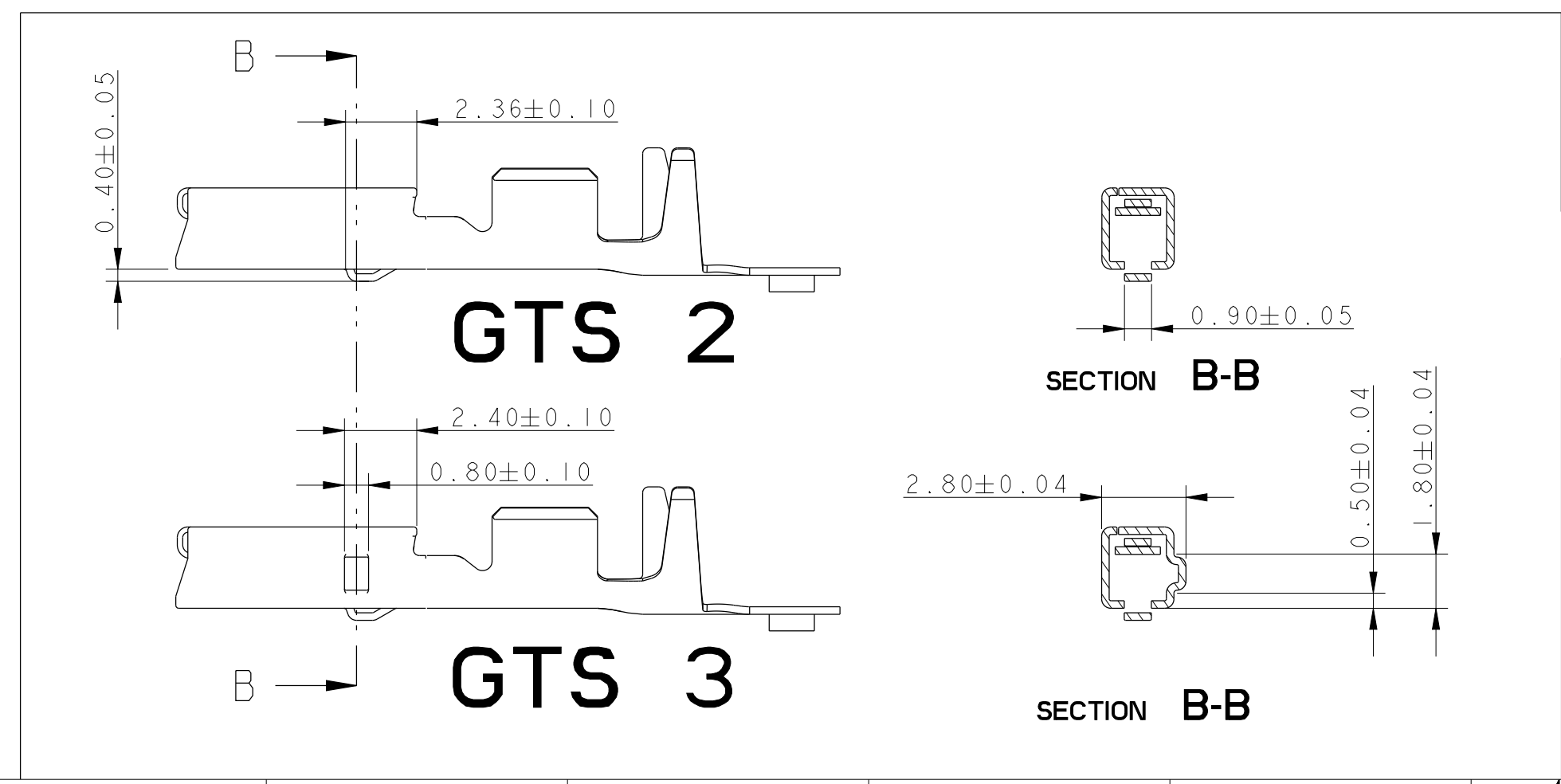


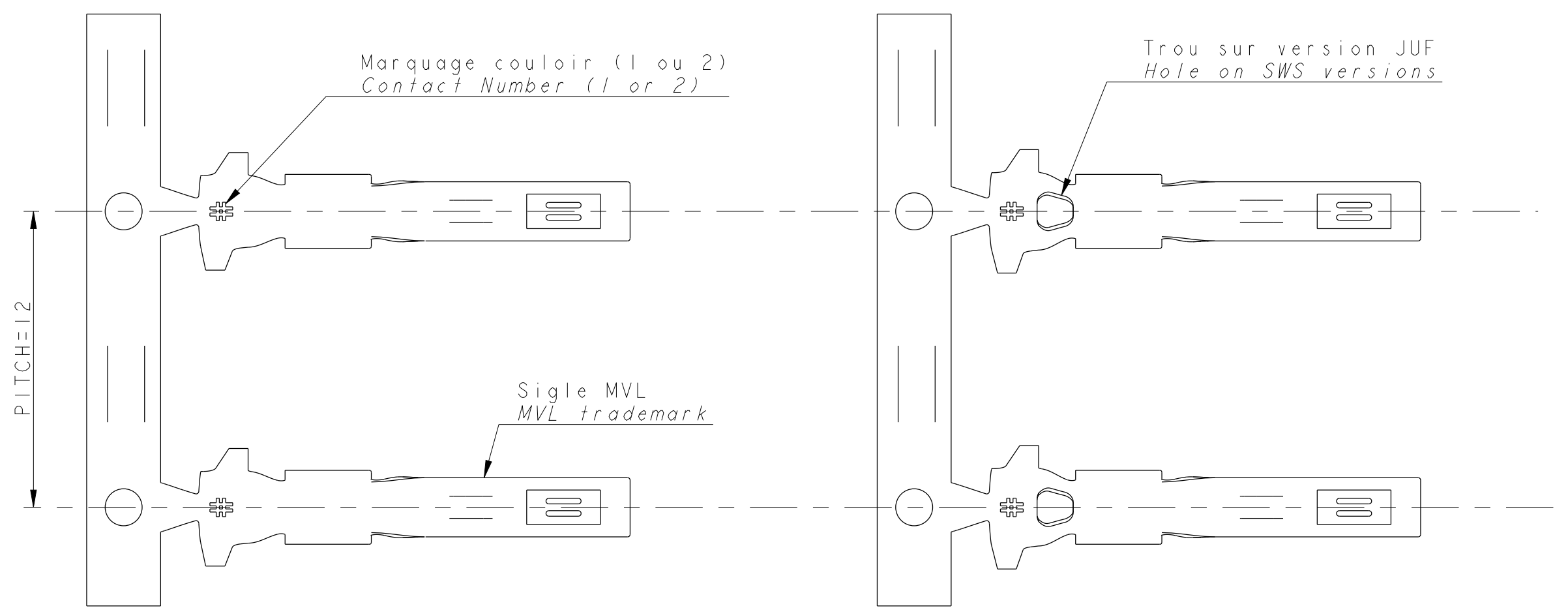

		9	8		7	6		5	4		3	2		1
Etat / State			Références									Material	Classe	
Pré-étamé / Pre-tinned	GTS 2 	MVL P/N	F761110	PPI0001580	PPI0001482	F112300	PPI0001483	F343100	PPI0001484	F443100	Cu Ni Si	125°		
		Revision	-	A	A	A	A	A	A	A			A	
		DELPHI P/N	33510897	13648599	13712871	13737770	13741954	13860784	13749482	13737773				
		Revision	01	01	01	01	01	01	01	01			01	
	GTS 3 	MVL P/N	F196400	PPI0000597	PPI0000596	F243300	PPI0000598	F543100	PPI0000599	F643100		150°		
		Revision	-	E	E	-	E	-	E	-				
		DELPHI P/N	33510898	33510899	33510901	33510902	33510904	33510906	33510908	33510910				
		Revision	01	01	01	01	01	01	01	01			01	
Pré-pisté 1.27µ Au Pré-tracked Au 1.27µ	GTS 2 	MVL P/N	NOT AVAILABLE	F861110	NOT AVAILABLE	F212300	F961110	F743100	F071110	F843100	150°			
		Revision		A		-	A	A	A	A				
		DELPHI P/N	-	33510900	-	33510903	33510905	33510907	33510909	33510911				
		Revision		01		01	01	01	01	01		01		
	GTS 3 	MVL P/N	NOT AVAILABLE	NOT AVAILABLE	NOT AVAILABLE	NOT AVAILABLE	NOT AVAILABLE	NOT AVAILABLE	NOT AVAILABLE	NOT AVAILABLE		NOT AVAILABLE		
		Revision												
		DELPHI P/N	-	-	-	-	-	-	-	-		-		
		Revision												
Section / Gauge			0.22 to 0.35	0.5 to 0.85			1 to 1.3		1.4 to 2					
Ø Isolant pour non étanche Ø Insulation for unsealed			1.15 to 1.50	1.4 to 1.9			1.75 to 2.2		2.1 to 2.8					
A			1.78	2.24			2.78		3.15					
B			2.24	2.36			2.95		3.30					
C			0.38	0.52			0.67		0.80					
D ± 0.3			2.53	3.08	5.00		4.00	5.00	5.00	5.20				
E			2.55	3.09	4.15		3.20	4.50	4.15	4.90				
F			0.65	0.82	1.25		1.00	1.35	1.25	1.35				
					Avec joint sur fil With wire tube		Avec JUF With SMS		Avec JUF With SMS		Avec JUF With SMS			

[illegible]

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[PPI0001484](#) [PPI0001580](#) [PPI0001483](#) [PPI0001482](#) [PPI0000599](#)