

Direct Link

Cross reference

RoHS/LF P/N Search

Customer drawing search

3D model search

Application tooling

Services

Contact us

Distributor list

Price request

Order samples

Documentation


Free search

Search by category

Start > Search=30310261* > 30310261

30310261

30310261 : 5 Way Male Inline sectioning

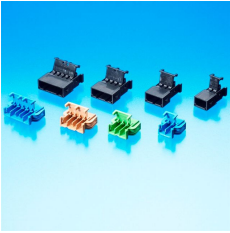

Assistant

Add to Favorites

Email Datasheet

Print Datasheet

FCI Brings You More

Contact our sales/technical support

Sample request

Price request

Customer Drawing

Specifications

Mating Half

General

Physical

Terminal 1 Type

Environmental

Other Features

General	
Application	Wire to Wire Sectioning
Ways	5
Coding version	Black
Product Type	Housing
Coding	Yes
Features	Simple to use housing for 2.8 mm terminals with a TPA that ensure good retention.
Hybrid	No
Main Terminal family	DCS-2
Main Terminal size	2.8 mm
Sealed	No
Terminal Size	5x2,8
Physical	
Color	Black
Temperature (Range)	-40 °C to +100 °C
Terminal 1 Type	
Terminal type 1	DCS-2 Male 2.8 mm Terminal
Ways for Terminal Type 1	5
Environmental	
IMDS	Yes
Other Features	
Market	Passenger Vehicles
Type	Male
Part Situation	Active
Disclaimer	Displayed data is for information purposes only. For more information, please contact your local sales office. The supply of some products might be limited to some customers.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[30310261](#)