


|                    |             |
|--------------------|-------------|
| Strip length:      | 3,50 mm     |
| cable type:        | FLRY-B      |
| insulation Ø [mm]: | 1,70 - 1,90 |
| seal:              |             |

two piece anvil:  
AC-1.60-2.75-A  
DPN 10764132  
AI-2.00-2.8-0.2  
DPN 10804102

[illegible]

DELPHI PN 15440185

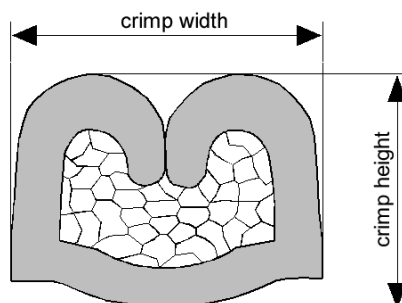

cable:

0,75 mm<sup>2</sup> = 24 x 0,21 mm

crimp height:

1,20 mm

crimp width:

1,65 mm

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[15440185](#)