




Replacement Tips Item: [00-CB-SA-RT](#)

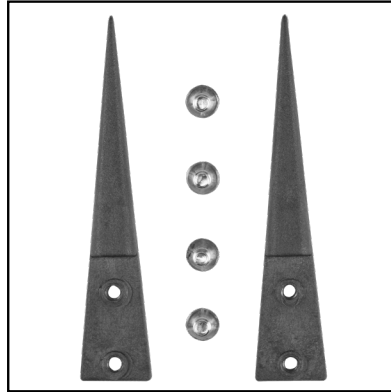

Features:

- **International Style:** 00
- **Handle Material:** Stainless Steel
 - **Magnetic Properties:** Anti-Magnetic
 - **Corrosion Resistance:** Anti-Acid
 - **Finish:** Polished
- **Tips:** Replaceable Carbon Fiber, Fine
 - **Material:** Polyamide 66 with carbon fiber, Black
 - **Resistance:**
 - Tip to Tip: $< 1 \times 10^4$ ohms tested per ANSI/ESD STM11.12
- Made in Switzerland

Tip Specifications:

Test	Norm	Unit	Value
Density	ISO 1183	g/cm ³	1,28
Tensile strength	ISO 527	MPa	210
Elongation at break	ISO 527	%	2,5
Flexural Modulus	ISO 527	MPa	17000
Heat distribution Temperature	ASTM D 648	°C	95°
Melting point	ASTM D1525	°C	>260°
Charpy impact strength	DIN 53453	kJ/m ²	30

Unless otherwise noted, tolerance is $\pm 10\%$.

Specifications and procedures subject to change without notice.

PRECISION STAINLESS STEEL TWEEZER W/ REPLACEABLE CARBON FIBER TIPS, STRONG FLAT TIP, FINE, STYLE 00

TRONEX

2860 CORDELIA RD STE 230, FAIRFIELD CA, 94534
PHONE: (909) 627-2453
WEBSITE: TronexTools.com

**DRAWING
NUMBER**
00-CB-SA-CH

DATE
June
2023

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Menda:

00-CB-SA-CH