




Made in the
United States of America

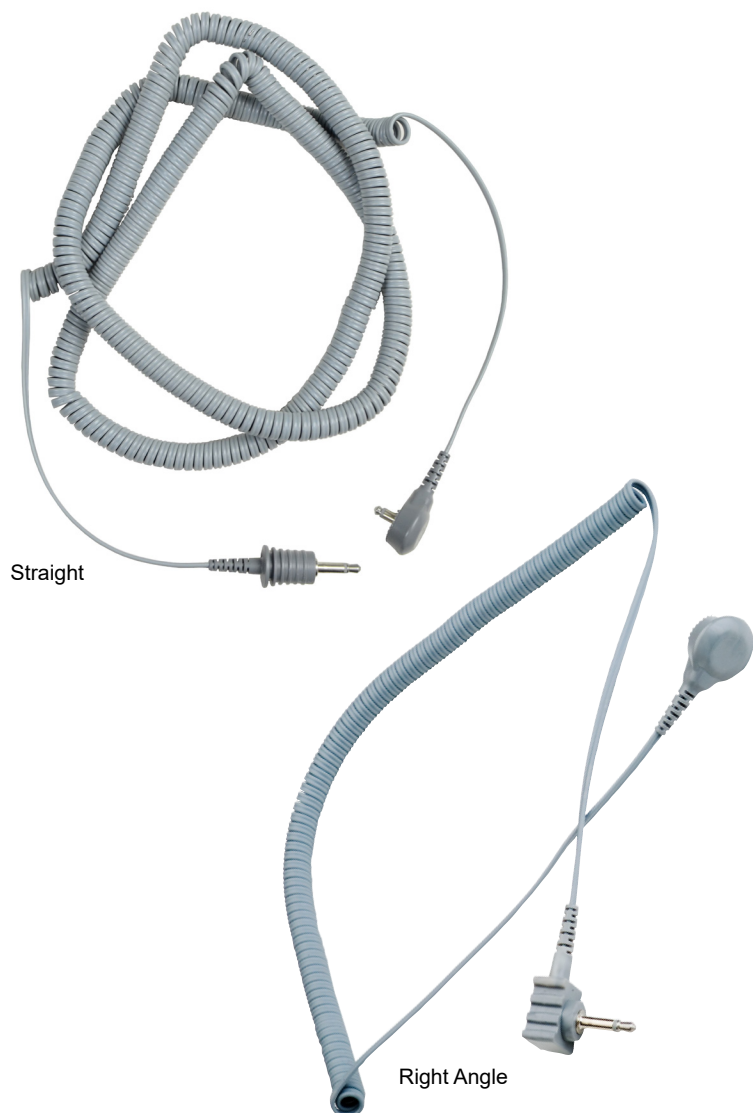

The 2300 Series Dual Conductor Coil Cord is for use with dual conductor wrist straps and SCS Workstation Monitors. The Dual Conductor Coil Cord features an improved grip that is wider in diameter and easier to grasp when inserting and removing the cord from the remote unit. 1 megohm current limiting resistors on both conductors that meet the resistance requirements of ANSI/ESD S20.20, EIA 625.

Properties	Typical Value
Resistance	One megohm
Flex Life	> 16,000 flexes
Plug Size	3.4mm
Plug Type	Straight or Right Angle
Color	Gray

Item	Description
2360	5ft. (1.5m), Straight
2370	10ft. (30.m), Straight
2371	20ft. (6.1m), Straight
2360R*	5ft. (1.5m), Right Angle
2370R*	10ft. (30.m), Right Angle
2371R*	20ft. (6.1m), Right Angle

*To be used with SCS Dual Wire Monitors only

Note: This product is not recommended for use on equipment with operating voltage exceeding 250 VAC.

Specifications and procedures subject to change without notice.

SCS

2300 SERIES - DUAL CONDUCTOR COIL CORD

926 JR Industrial Drive, Sanford, NC 27332
WEB SITE: StaticControl.com
PHONE (919) 718-0000

**DRAWING
NUMBER**
2300 Series

DATE
February
2017

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Desco:

[2371](#) [2360](#) [2370](#) [2360R](#) [2370R](#) [2371R](#)