




Made in the United States of America


MODE 1



 MODE 2



MODE 3

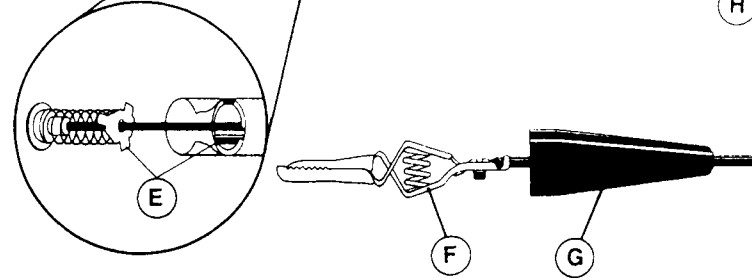

MODE 1: Continuity tester for unpowered circuits. 0-10 ohms; uses the Menda [35121](#) lamp and two AAA batteries (not supplied).

MODE 2: Voltage tester for 60-600 volts AC or DC; uses the neon cartridge and no batteries.

MODE 3: Voltage tester for 0-60 volts AC or DC; uses the Menda [35121](#) lamp and no batteries.

- A. Probe tip (included)
- B. Menda [35121](#) (included) - For use in Modes 1 and 3. Operates from 2 to 3 volts in Mode 3.
- C. Neon Cartridge (included) - For use in Mode 2.
- D. Two AAA batteries (not included) - For use in Mode 1
- E. Three point washer rides on internal steps in handle. Slides to lower position for Mode 1; upper position for Modes 2 and 3.
- F. The other end of the 3 ft wire lead is terminated with a #85 Mueller ground clip.
- G. Black insulator over clip for high voltage applications.
- H. Wire is 0.1" high flex 105 strand copper with black PVC insulated jacket; 3' length
- I. Clear butyrate window provides a 360° view of the indicator light

Specifications and procedures subject to change without notice.

CIRCUITRACER® CONTINUITY AND VOLTAGE TESTER

MENDA

3651 WALNUT AVENUE, CHINO, CA 91710
PHONE: (909) 627-2453 FAX: (909) 627-7449
WEBSITE: MendaPump.com

**DRAWING
NUMBER**
35100

DATE
October
2017

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Desco:](#)

[35100](#)

[Menda:](#)

[35121](#)