




Features

- Solder sponge or soaker removes oxides and excess solders from soldering iron tips
- Provides extended tip life and precise soldering
- Manufactured with natural biodegradable wood pulp fibers, compressed cellulose
- Expanded sponge is 5/8" thick
- Custom die-cut sponges available

Solder Sponge Center-Hole Part Numbers

Part Number	Description
S1525-O-M	Center-Hole, 1.5" x 2.5", 1000 per pack
S1525-O-T	Center-Hole, 1.5" x 2.5", 10 per pack
S2235-O-T	Center-Hole, 2.2" x 3.5", 10 per pack
S2325-O-M	Center-Hole, 2.3" x 2.5", 1000 per pack
S2432-O-M	Center-Hole, 2.4" x 3.2", 1000 per pack
S2432-O-T	Center-Hole, 2.4" x 3.2", 10 per pack
S2626-O-T	Center-Hole, 2.6" x 2.6", 10 per pack
S3017-O-M	Center-Hole, 3.0" x 1.7", 1000 per pack
S3017-O-T	Center-Hole, 3.0" x 1.7", 10 per pack
S3030R-O-M	Round, Center-Hole, 3", 1000 per pack
S3030R-O-T	Round, Center-Hole, 3", 10 per pack
S3219-O-M	Center-Hole, 3.2" x 1.9", 1000 per pack
S3219-O-T	Center-Hole, 3.2" x 1.9", 10 per pack
S3444-O-M	Center-Hole, 3.4" x 4.4", 1000 per pack
S3444-O-T	Center-Hole, 3.4" x 4.4", 10 per pack
S4017-O-T	Center-Hole, 4.0" x 1.7", 10 per pack

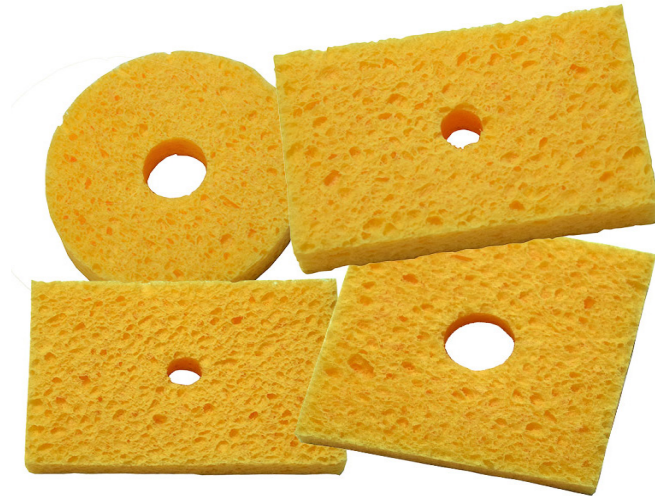

Die Cut Dimensional Tolerances:
Dry Sponge: +/- 1/32"

EasyBraid expressly warrants that for a period of one (1) year from the date of purchase, EasyBraid products will be free of defects in material (parts) and workmanship (labor). Within the warranty period, a unit/product will be tested, repaired or replaced at EasyBraid's option, free of charge.

Specifications and procedures subject to change without notice.

EasyBraid

SOLDER SPONGE CENTER HOLE

11520 K-TEL DRIVE, MINNETONKA, MN 55343
PHONE: (909) 627-2453
WEBSITE: EASYBRAIDCO.COM

DRAWING NUMBER
Sponge Center Hole

DATE:
August 2019

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Menda:

[S1525-O-M](#) [S2325-O-M](#) [S3020-P-T](#) [S3030R-O-T](#) [S2222-O-M](#) [S2745-S-M](#) [S2626-O-T](#) [S2626-S-M](#) [S2626-P-T](#)
[S2626-S-T](#) [S3444-S-T](#) [S4017-O-T](#) [S3017-O-M](#) [S3444-S-M](#) [S2626-M-M](#) [S3444-O-M](#) [S2626-M-T](#) [S2745-S-T](#)
[S3219-O-T](#) [S3444-O-T](#) [S2235-M-T](#) [S3219-O-M](#) [S1525-O-T](#) [S2432-O-M](#) [S2626-P-M](#) [S2222-O-T](#) [S2235-O-T](#)
[S3020-P-M](#) [S2432-O-T](#) [S3017-O-T](#)