



Important notes about Classic Panel Mount Indicator Catalog Pages

SCROLL DOWN TO VIEW CATALOG PAGE

This catalog page is out-of-print and is used with the understanding that the information shown could be out-of-date. In many cases, part numbers shown on this page are discontinued. Most notably, many "Complete Assembly" parts, which consist of a cap and a base, can no longer be ordered by the 14-digit ordering code. To obtain these parts, please order the cap and base part numbers separately. This process provides the components contained with the original "Complete Assembly" part number.

All Dialight Classic Panel Mount Indicators need a leading 3-digit numerical series. In some cases, this catalog will show a 2-digit series. In this case, please add a leading zero. For example, 81-0211-300 becomes 081-0211-300.

Part numbers listed on Dialight catalog pages designate parts with Red lenses. For ordering lens colors other than red, consult the chart below. In most cases, the color is dictated by the 7th digit. For example, 095-0932-003 for a green cap.

Lens Colors	
1 - Red	5 - White
2 - Green	6 - Light Yellow
3 - Yellow	7 - Clear
4 - Blue	

 
[Click here for a cross reference guide to assembly part numbers.](#)

[Click here to view Frequently Asked Questions concerning Panel Mount Indicators.](#)

SCROLL DOWN TO VIEW CATALOG PAGE

Miniature Incandescent Indicators

FOR REAR MOUNTING IN 9/16" CLEARANCE HOLE
FOR 2 TO 120V OPERATION



T-3 1/4
MINIATURE
BAYONET BASE


See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.


75W., 125V.



For materials and finishes of products in this group, see page 2D.

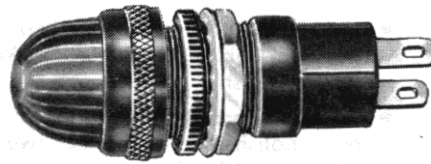

70-0410-1191-206
Stovepipe lens

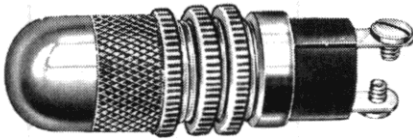

17-1310-0931-205
Stovepipe lens

17 SERIES
70 SERIES

WITH SCREW-ON LENS CAPS

solder terminal	screw terminal
70-0410-11-205	70-1310-11-205

BASE PART NUMBERS

CAP PART NUMBERS		COMPLETE ASSEMBLY PART NUMBERS	
	<p>STOVEPIPE 17-0931-200 transparent ■ 17-0951-200 translucent</p>	<p>17-0410-0931-205 ■ 17-0410-0951-205</p>	<p>17-1310-0931-205 ■ 17-1310-0951-205</p>
	<p>STOVEPIPE 17-0991-200 internal fluting</p>	<p>17-0410-0991-205</p>	<p>17-1310-0991-205</p>
	<p>STOVEPIPE 70-1111-200 back frosted 70-1131-200 transparent</p>	<p>70-0410-1111-205 70-0410-1131-205</p>	<p>70-1310-1111-205 70-1310-1131-205</p>
	<p>STOVEPIPE 70-1191-200 internal fluting</p>	<p>70-0410-1191-205</p>	<p>70-1310-1191-205</p>

■ Specify translucent colors as follows: Red-0951, Green-0952, Yellow (amber)-0973, White-0975, Light Yellow-0976.

Order complete with lamp to be assured of receiving the indicator light and correct lamp together for immediate use.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[070-1137-300](#) [070-0410-11-305](#) [070-1191-300](#) [070-1131-200](#) [070-1191-200](#) [070-0410-11-206](#) [070-1192-200](#) [070-1310-11-205](#) [070-1135-300](#) [070-1195-300](#) [070-1197-300](#) [070-0410-11-100](#) [070-0410-11-200](#) [070-1310-11-100](#) [070-1310-11-200](#) [070-1137-200](#) [070-1131-300](#) [070-1193-300](#) [070-1133-300](#) [070-1310-11-206](#) [070-0410-11-205](#) [070-1136-200](#) [070-0410-11-306](#) [070-1310-11-305](#) [070-1133-200](#) [070-1192-300](#) [070-1132-300](#) [070-1310-11-105](#) [017-0931-200](#) [017-0932-200](#) [017-0933-200](#) [017-0937-200](#) [017-0951-200](#) [017-0952-200](#) [017-0991-200](#) [070-1193-200](#)