 


OIL TIGHT Miniature Neon Indicators

FOR MOUNTING IN 11/16" CLEARANCE HOLE

When connecting a Neon Light to a circuit having one side grounded, always connect the hot side of the circuit to the terminal marked + (center contact).



T-3 1/4
B1A (NE-51)
B2A (NE-51H)
MINIATURE BAYONET BASE

See lamp ratings
on page L.

Recognized under the component
program of Underwriters'
Laboratories Inc.



MATERIALS AND FINISHES


- **Mounting Bushing:** Brass, white nickel finish. Optional, black nickel finish.
- **Lens Holder:** Brass, satin chrome finish. Optional, polished chrome or black nickel finish.
- **Internal-tooth-Lockwasher:** Phosphor bronze, white nickel finish.
- **Mounting Nut:** Brass, white nickel finish.

How to designate the three digit part number suffix (-XXX)

("Resistor" designations are given for B1A (NE-51) and B2A (NE-51H) Lamps.

FINISH	RESISTOR	HARDWARE
-2 black nickel	1-22K	3-water-tight,
-3 polished chrome	3-33K	oil tight on
-4 satin chrome	4-56K	the face of
	6-68K	the panel
	7-100K	

Note: The part numbers given in this catalog indicate standard indicator lights. The above table provides the standard and optional designations for Finish and Resistor where appropriate.

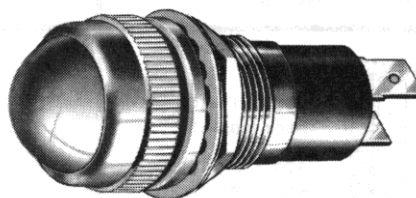

123-5863-1231-463
Dome lens


123 SERIES

screw terminals	soldering terminals	quick connect terminals

BASE PART NUMBERS

VOLTAGES	LAMP	COMPLETE ASSEMBLY PART NUMBERS
105-125V AC-DC	B1A	123-1308-12-143
110-125VAC	B2A	123-1363-12-113
210-250V AC-DC	B2A	123-9363-12-163
		123-0408-12-143
		123-0463-12-113
		123-9463-12-163
		123-5708-12-143
		123-5763-12-113
		123-5863-12-163

CAP PART NUMBERS

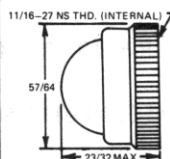

DOME

123-1231-403
unfrosted

Part numbers listed in this catalog designate products with RED lens. For ordering lens colors other than red, consult chart on page 1E.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[123-9363-12-163](#) [123-9463-12-163](#) [123-1308-12-143](#) [123-0408-12-143](#) [123-0463-12-113](#) [123-1363-12-113](#) [123-5863-12-163](#) [123-5763-12-113](#)