 


Miniature Incandescent Indicators

FOR MOUNTING IN 11/16" CLEARANCE HOLE
FOR 2 TO 120V OPERATION

For materials and finishes of products in this group, see page 6D.




T-3 1/4
MINIATURE
BAYONET BASE


See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.


75W., 125V.

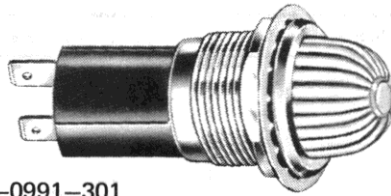


52-5710-0991-301
Screw-in lens cap

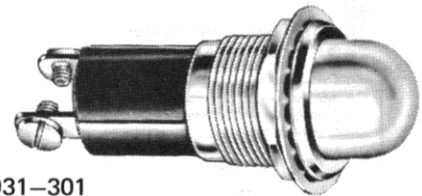

95-1310-0931-301
Screw-in lens cap

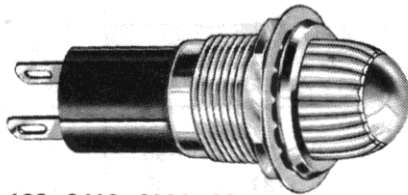

132-0410-0991-301
Screw-in lens cap

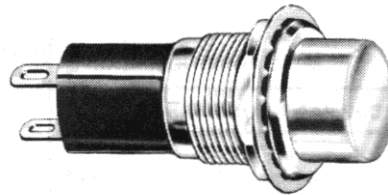

135-0410-1431-301
Screw-in lens cap

WITH SCREW-IN LENS CAPS

52 SERIES
95 SERIES
132 SERIES
135 SERIES

BASE PART NUMBERS

solder terminals	screw terminals	quick connect terminals	solder terminals *
95-0410-09-301	95-1310-09-301	95-5710-09-301	95-9110-09-102

CAP PART NUMBERS

COMPLETE ASSEMBLY PART NUMBERS

CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS			
<p>STOVEPIPE 52-0991 internal fluting 52-3191 internal fluting Lexan †</p>	52-0410-0991-301 52-0410-3191-301	52-1310-0991-301 52-1310-3191-301	52-5710-0991-301 52-5710-3191-301	52-9110-0991-102 52-9110-3191-102
<p>STOVEPIPE 95-0931 transparent 95-0971 translucent 95-3171 translucent Lexan †</p>	95-0410-0931-301 95-0410-0971-301 95-0410-3171-301	95-1310-0931-301 95-1310-0971-301 95-1310-3171-301	95-5710-0931-301 95-5710-0971-301 95-5710-3171-301	95-9110-0931-102 95-9110-0971-102 95-9110-3171-102
<p>STOVEPIPE 132-0991 internal fluting</p>	132-0410-0991-301	132-1310-0991-301	132-5710-0991-301	132-9110-0991-102
<p>CYLINDRICAL 135-1431 transparent 135-1471 translucent 135-3271 translucent Lexan † See page P for legends</p>	135-0410-1431-301 135-0410-1471-301 135-0410-3271-301	135-1310-1431-301 135-1310-1471-301 135-1310-3271-301	135-5710-1431-301 135-5710-1471-301 135-5710-3271-301	135-9110-1431-102 135-9110-1471-102 135-9110-3271-102

*These units are designed for commercial application where military standards are not required.

† For use with lamps rated over 2 watts.

Order complete with lamp to be assured of receiving the indicator light and correct lamp together for immediate use.

Part numbers shown in gray are normally in inventory at your Dialight Distributor.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[095-3176-003](#) [095-3174](#) [095-0933-003](#) [135-1432-003](#) [095-5710-09-100](#) [095-5710-09-300](#) [095-0410-09-102](#) [095-0971-003](#) [095-3173](#) [135-1472](#) [095-0932-003](#) [095-3174-003](#) [135-1431-003](#) [135-3232-003](#) [095-0410-09-201](#) [095-5710-09-303](#) [095-0937-003](#) [132-0994](#) [135-1471](#) [095-3173-003](#) [135-1435](#) [095-0931-003](#) [095-9110-09-102](#) [132-0991](#) [095-1310-09-102](#) [095-0933](#) [095-3176](#) [095-1310-09-201](#) [095-3171-003](#) [135-1431](#) [095-0932](#) [095-5710-09-200](#) [135-3231](#) [052-3193](#) [095-0931](#) [095-1310-09-103](#) [135-3232](#) [095-0410-09-203](#) [095-5710-09-805](#) [052-0996](#) [135-1471-003](#) [095-3175](#) [135-1435-003](#) [135-1476](#) [095-0934-003](#) [095-0972-003](#) [095-0975-003](#) [095-0410-09-200](#) [095-0410-09-300](#) [095-1310-09-100](#) [095-1310-09-101](#) [095-1310-09-200](#) [095-1310-09-300](#) [095-9110-09-300](#) [135-3233](#) [095-5710-09-301](#) [095-0973-003](#) [135-1433-003](#) [095-0410-09-303](#) [095-0410-09-301](#) [095-0410-09-302](#) [095-5710-09-101](#) [095-1310-09-301](#) [095-1310-09-303](#) [052-3191](#) [052-3192](#) [052-3194](#) [052-0992-003](#) [135-3032](#) [095-3172](#) [095-3171](#) [135-1432](#) [135-1436](#) [135-1437](#) [135-1474](#) [135-1473](#) [135-1475](#) [095-5710-09-203](#) [095-5710-09-201](#) [095-1312-30-203](#) [095-3172-003F](#) [095-1310-09-403](#) [052-0992](#) [052-0994](#) [052-0997](#) [052-0993](#) [052-0991](#) [052-0995](#) [132-0993](#) [132-0995](#) [132-0992](#) [095-3175-003](#) [095-0935-003](#) [095-3173-003F](#) [052-3192-003](#) [132-0991-003](#) [095-1310-09-203](#) [095-1310-0931-203](#) [135-1437-003](#) [095-9110-09-302](#)