

Dialight

657 Series - Right Angle LED Watertight - 11/16" Mounting Hole Panel Mount Indicators



FEATURES / BENEFITS

- ▲ Cool-to-the-touch white light
- ▲ IP67 / NEMA 4X
- ▲ Wide viewing angle – 110°
- ▲ Variable input voltage
- ▲ No light spill
- ▲ Non-polarized
- ▲ Resistant to shock and vibration
- ▲ RoHS compliant

APPLICATIONS

- Instrument panels
- Gauges
- Dash boards
- Storage compartments
- Control panels

SPECIFICATIONS

- ▲ Operating Voltage - 12 to 32 VDC
- ▲ Operating temperature -35° C to + 65° C
- ▲ Storage temperature -40° C to +100° C
- ▲ Front Mounting in 11/16" clearance hole
- ▲ IP67 / NEMA 4X
- ▲ Lead wire – 18 AWG anti-capillary
- ▲ Available in Cool White (For other colors, consult factory)
- ▲ Horizontal Viewing Angle 110°
- ▲ Vertical Viewing Angle 80°

PART NUMBERS

Part Number	Color	Voltage	Forward Current (typ)	Intensity (typ)
657-3009-213F	Cool White	12-32 VDC	24mA	2000 mcd

Dialight reserves the right to make changes at any time
in order to supply the best product possible.


Dialight Corporation

1501 Route 34 South • Farmingdale, NJ 07727 USA

Tel: (1) 732-919-3119 • Fax: (1) 732-751-5778 • www.dialight.com



MDEL657X001_A

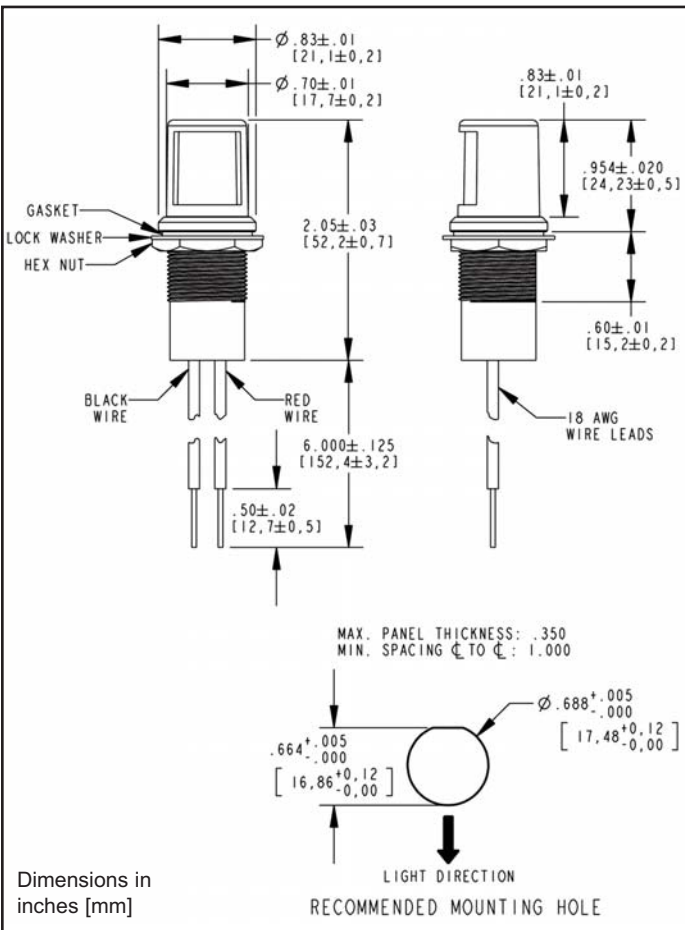

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

657-3009-213F