



### Certifications & Ratings

- RoHS compliant
- NEMA 4X (Watertight only)
- IP66 (Watertight only)

### Application


The 609 Series LED Panel Mount Indicators are designed for a variety of applications such as:

- Main power indication
- Remote power indication
- Status indication
- Maintenance and warning indication
- Instrumentation
- ... and many more!


### Dimensions

inches [mm]

#### Protruding

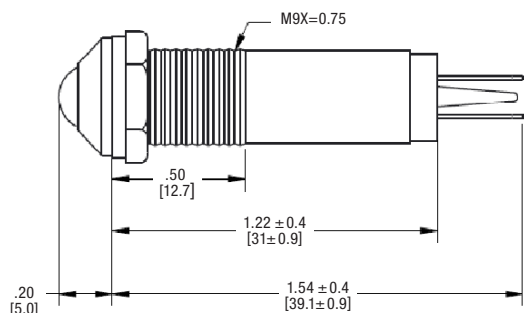

#### Recessed

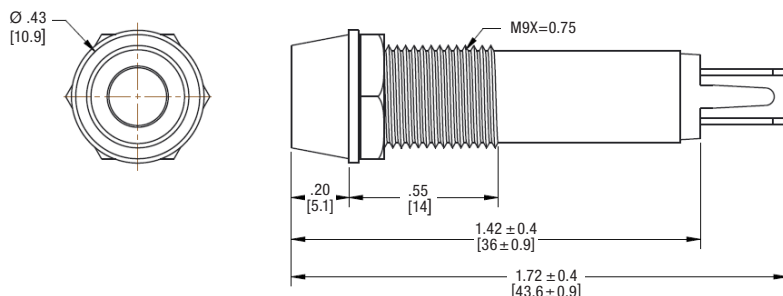

### Mechanical Information

- Mounting Hole Size:** 0.374" (9.5 mm)
- Max Panel Thickness:** 0.374" (9.5 mm);  
with Gasket: 0.318" (8.0 mm)
- Mounting Torque:** 0.362 lbs/ft (5 kg/cm)

### Specifications

- Voltage Options:** 6, 12 & 24 V DC (no resistor required)
- Operating Temp:** -30 °C to +85 °C (-22 °F to +185 °F)
- Storage Temp:** -40 °C to +85 °C (-40 °F to +185 °F)
- Electrical Connection:** Solder terminals
- Housing:** Brass—Chrome or Black Plated
- Terminals:** Copper—Nickel Plated
- Lock washer:** Iron—Nickel Plated
- Nut:** Brass—Nickel Plated



## Ordering Information 609 Series

| Part Number Guide |   |   |   |         |   |            |   |         |   | RoHS Compliant |   |   |
|-------------------|---|---|---|---------|---|------------|---|---------|---|----------------|---|---|
| 6                 | 0 | 9 | - | X       | X | X          | 2 | -       | X | X              | 0 | F |
| LED Position      |   |   |   | Plating |   |            |   | Voltage |   |                |   |   |
| Protruding        |   | 1 |   | 1       |   | Chrome     |   | 2       |   | 6VDC           |   |   |
| Recessed          |   | 2 |   | 2       |   | Black      |   | 3       |   | 12VDC          |   |   |
| Color             |   |   |   |         |   |            |   | 4       |   | 24VDC          |   |   |
| Red               |   | 1 |   | 1       |   | Standard   |   |         |   |                |   |   |
| Green             |   | 2 |   | 3       |   | Watertight |   |         |   |                |   |   |
| Yellow            |   | 3 |   |         |   |            |   |         |   |                |   |   |

### Protruding LED

| Part Number   | Part Number   | Color  | Voltage<br>(V DC) | Current<br>(mA) | Intensity<br>Typ.<br>(mcd) | Plating |
|---------------|---------------|--------|-------------------|-----------------|----------------------------|---------|
| Standard      | Watertight    |        |                   |                 |                            |         |
| 609-1112-120F | 609-1112-320F | Red    | 6                 | 15              | 85                         | Chrome  |
| 609-1212-120F | 609-1212-320F | Green  |                   |                 | 115                        |         |
| 609-1312-120F | 609-1312-320F | Yellow |                   |                 | 90                         |         |
| 609-1112-130F | 609-1112-330F | Red    | 12                |                 | 85                         |         |
| 609-1212-130F | 609-1212-330F | Green  |                   |                 | 115                        |         |
| 609-1312-130F | 609-1312-330F | Yellow |                   |                 | 90                         |         |
| 609-1112-140F | 609-1112-340F | Red    | 24                |                 | 85                         |         |
| 609-1212-140F | 609-1212-340F | Green  |                   |                 | 115                        |         |
| 609-1312-140F | 609-1312-340F | Yellow |                   |                 | 90                         |         |
| 609-1122-120F | 609-1122-320F | Red    | 6                 |                 | 85                         | Black   |
| 609-1222-120F | 609-1222-320F | Green  |                   |                 | 115                        |         |
| 609-1322-120F | 609-1322-320F | Yellow |                   |                 | 90                         |         |
| 609-1122-130F | 609-1122-330F | Red    | 12                |                 | 85                         |         |
| 609-1222-130F | 609-1222-330F | Green  |                   |                 | 115                        |         |
| 609-1322-130F | 609-1322-330F | Yellow |                   |                 | 90                         |         |
| 609-1122-140F | 609-1122-340F | Red    | 24                |                 | 85                         |         |
| 609-1222-140F | 609-1222-340F | Green  |                   |                 | 115                        |         |
| 609-1322-140F | 609-1322-340F | Yellow |                   |                 | 90                         |         |

### Recessed LED

| Part Number   | Part Number   | Color    | Voltage<br>(V DC) | Current<br>(mA) | Intensity<br>Typ.<br>(mcd) | Plating |
|---------------|---------------|----------|-------------------|-----------------|----------------------------|---------|
| Standard      | Watertight    |          |                   |                 |                            |         |
| 609-2112-120F | 609-2112-320F | ● Red    | 6                 | 15              | 85                         | Chrome  |
| 609-2212-120F | 609-2212-320F | ● Green  |                   |                 | 115                        |         |
| 609-2312-120F | 609-2312-320F | ● Yellow |                   |                 | 90                         |         |
| 609-2112-130F | 609-2112-330F | ● Red    | 12                |                 | 85                         |         |
| 609-2212-130F | 609-2212-330F | ● Green  |                   |                 | 115                        |         |
| 609-2312-130F | 609-2312-330F | ● Yellow |                   |                 | 90                         |         |
| 609-2112-140F | 609-2112-340F | ● Red    | 24                |                 | 85                         |         |
| 609-2212-140F | 609-2212-340F | ● Green  |                   |                 | 115                        |         |
| 609-2312-140F | 609-2312-340F | ● Yellow |                   |                 | 90                         |         |
| 609-2122-120F | 609-2122-320F | ● Red    | 6                 |                 | 85                         | Black   |
| 609-2222-120F | 609-2222-320F | ● Green  |                   |                 | 115                        |         |
| 609-2322-120F | 609-2322-320F | ● Yellow |                   |                 | 90                         |         |
| 609-2122-130F | 609-2122-330F | ● Red    | 12                |                 | 85                         |         |
| 609-2222-130F | 609-2222-330F | ● Green  |                   |                 | 115                        |         |
| 609-2322-130F | 609-2322-330F | ● Yellow |                   |                 | 90                         |         |
| 609-2122-140F | 609-2122-340F | ● Red    | 24                |                 | 85                         |         |
| 609-2222-140F | 609-2222-340F | ● Green  |                   |                 | 115                        |         |
| 609-2322-140F | 609-2322-340F | ● Yellow |                   |                 | 90                         |         |

Dialight reserves the right to make changes at any time in order to supply the best product possible. The most current version of this document will always be available at: [www.dialightsignalsandcomponents.com](http://www.dialightsignalsandcomponents.com)

**Warranty Statement:** Except for the warranty expressly provided for [herein/above/below], Dialight disclaims any and all other warranties, express or implied, including, without limitation, any warranties of merchantability, fitness for a particular purpose, title, and noninfringement.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Dialight:

[609-1122-130F](#) [609-2212-120F](#) [609-1312-130F](#) [609-2112-120F](#) [609-2112-120](#) [609-2212-130](#) [609-1212-130F](#) [609-2112-140](#) [609-1112-130F](#) [609-1112-120](#) [609-1212-130](#) [609-2212-130F](#) [609-2312-130](#) [609-2312-130F](#) [609-1112-130](#) [609-2122-120](#) [609-2212-140](#) [609-2112-130F](#) [609-2112-130](#) [609-1212-120](#) [609-1122-120F](#) [609-1312-140F](#) [609-2212-140F](#) [609-1322-120F](#) [609-1322-130F](#) [609-2322-130F](#) [609-2122-130F](#) [609-2222-120F](#) [609-2122-120F](#) [609-1222-120F](#) [609-1212-120F](#) [609-1312-120F](#) [609-1112-120F](#) [609-2312-140F](#) [609-2322-140F](#) [609-2112-140F](#) [609-2122-140F](#) [609-2222-140F](#) [609-1112-140F](#) [609-1122-140F](#) [609-1322-140F](#) [609-1212-140F](#) [609-1222-140F](#) [609-1222-130F](#) [609-1312-130](#) [609-2222-120](#) [609-2222-140](#) [609-1222-140](#) [609-2322-130](#) [609-2312-140](#) [609-1312-140](#) [609-1322-120](#) [609-2312-120](#) [609-1312-120](#) [609-1222-130](#) [609-2322-140](#) [609-2122-130](#) [609-1212-140](#) [609-2322-120](#) [609-1112-140](#) [609-2222-130F](#) [609-2322-120F](#) [609-2312-120F](#) [609-2222-330F](#) [609-1222-340F](#) [609-1212-340F](#) [609-2222-340F](#) [609-1112-330F](#) [609-2122-330F](#) [609-1122-330F](#) [609-2122-340F](#) [609-1122-340F](#) [609-1112-340F](#) [609-2122-320F](#) [609-1312-340F](#) [609-2322-330F](#) [609-2312-340F](#) [609-1322-340F](#) [609-1122-320F](#) [609-2112-330F](#) [609-2222-320F](#) [609-1222-330F](#) [609-2312-330F](#) [609-2212-330F](#) [609-1212-330F](#) [609-1222-320F](#) [609-1322-320F](#) [6091112320F](#) [6091212320F](#) [6091312320F](#) [6091312330F](#) [6091322330F](#) [6092112320F](#) [6092112340F](#) [6092212320F](#) [6092322340F](#) [609-2322-320F](#) [609-2212-340F](#) [609-2312-320F](#)