

Incandescent Indicators

TWO TERMINALS – FULLY INSULATED

MEET OR EXCEED ENVIRONMENTAL AND OPERATIONAL REQUIREMENTS
OF MIL-L-6723 AND MIL-L-3661B



T-1 3/4
MIDGET
FLANGE BASE

See lamp ratings
on page J.

For materials and finishes of products
in this group, see preceding page.

101 SERIES
108 SERIES
109 SERIES
111 SERIES
112 SERIES
134 SERIES
140 SERIES

Features

- Available for mounting FRONT or BACK of panel in 15/32" or 1/2" clearance hole; also from FRONT of panel in 15/32" or 17/32" clearance hole.
- Rugged-phenolic insulated: The socket, lamp and all connections are well insulated from the mounting bushing by means of phenolic material of military specification grade.
- Lens cap assembly unscrews from front of panel for easy replacement of the lamp. Indicators on Pages 10C – 11C have friction-fit lens caps which are also easily removed from front of panel.
- Two terminals (soldering) are provided for electrical connections.

COLORLED LEGENDS

134 SERIES FLAT LENS ONLY



Colored Legends on black or gray lenses: Legends can also be furnished in "negative" or "reverse" style. That is, the legend is illuminated in white or other color while the background remains opaque black or gray. To specify black or gray lens, change the first two digits of the code block preceding the last dash in the catalog number. To obtain black lens, use "57"; to obtain gray lens, use "58".
Examples: 134-3830-5752-201 (black);
134-5030-5875-201 (gray)

- Specify translucent colors as follows: Red-0351...Green-0352...
Yellow (amber) -0373...Blue-0374...White-0375...Light Yellow-0376

How to designate the Three Digit Part Number Suffix (-XXX)

Finish	Resistor	Hardware
1 – white nickel	0 – none	1 – brass
2 – black nickel		3 – water tight on face of panel
3 – polished chrome		

Example: 101-3830-0931-201 (Black nickel finish, no resistor, brass hardware)
101-3830-0931-203 (same, water tight)

Lens Colors

1-Red	5-White translucent
2-Green*	6-Light yellow
3-Yellow (amber)	7-Clear colorless
4-Blue*	

*Not recommended with Neon Glow Lamps.

The digit before the last dash in the part number designates the lens color. When color other than red is desired, change this digit to a figure noted above. Example: 101-5030-0936-201


Part numbers listed in this catalog designate products with RED lens. For ordering lens colors other than red, consult chart above.

Order complete with lamp to be assured of receiving the indicator light and correct lamp together for immediate use.


Part numbers shown in gray are normally in inventory at your Dialight Distributor.

BASE PART NUMBERS

CAP PART NUMBERS

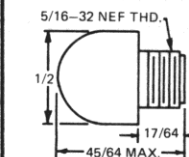


STOVEPIPE
101-0931
transparent
101-0971
translucent

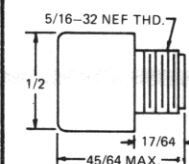


CYLINDRICAL
140-1431
transparent
140-1471
translucent


For legends on flat faced lens, see page P.

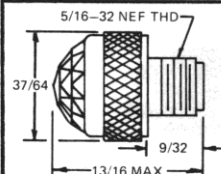

FACETED
134-2131-200
unfrosted

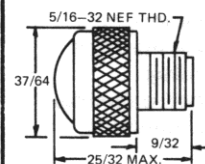


CONVEX
134-0131-200
unfrosted
134-0111-200
back frosted

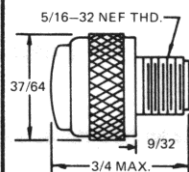


**ROTATABLE LENS
FLAT**
134-0331-200
transparent
134-0351-200
translucent

For legends on flat faced lens, see page P.

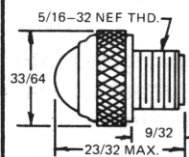

**NON-DIMMING TYPES
CONVEX**
111-0131-200
unfrosted
111-0111-200
back frosted

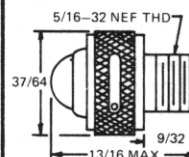

**DIMMER TYPES
CONVEX**
Complete Blackout
108-0131-200
unfrosted
108-0111-200
back frosted
Semi-Blackout
109-0131-200
unfrosted
109-0111-200
back frosted
Polaroid
112-0131-200
unfrosted
112-0111-200
back frosted

FRONT OR BACK MOUNTING with MOVABLE FLANGE 101-3830-09-201	FRONT MOUNTING with FIXED FLANGE 101-5030-09-201	FRONT MOUNTING with FIXED FLANGE 101-8430-09-201
---	---	---

COMPLETE ASSEMBLY PART NUMBERS

101-3830-0931-201 101-3830-0971-201	101-5030-0931-201 101-5030-0971-201	101-8430-0931-201 101-8430-0971-201
140-3830-1431-201 140-3830-1471-201	140-5030-1431-201 140-5030-1471-201	140-8430-1431-201 140-8430-1471-201
134-3830-2131-201 134-3830-0131-201 134-3830-0111-201 134-3830-0331-201 ■ 134-3830-0351-201	134-5030-2131-201 134-5030-0131-201 134-5030-0111-201 134-5030-0331-201 ■ 134-5030-0351-201	134-8430-2131-201 134-8430-0131-201 134-8430-0111-201 134-8430-0331-201 ■ 134-8430-0351-201
111-3830-0131-201 111-3830-0111-201	111-5030-0131-201 111-5030-0111-201	111-8430-0131-201 111-8430-0111-201
108-3830-0131-201 108-3830-0111-201 109-3830-0131-201 109-3830-0111-201 112-3830-0131-201 112-3830-0111-201	108-5030-0131-201 108-5030-0111-201 109-5030-0131-201 109-5030-0111-201 112-5030-0131-201 112-5030-0111-201	108-8430-0131-201 108-8430-0111-201 109-8430-0131-201 109-8430-0111-201 112-8430-0131-201 112-8430-0111-201

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[109-0133-200](#) [134-2131-200](#) [101-0976](#) [101-5030-09-303](#) [101-3830-09-200](#) [101-0937](#) [134-0331-200](#) [134-0352-200](#) [109-0114-200](#) [134-0113-200](#) [101-7130-09-200](#) [109-0113-200](#) [109-0132-200](#) [134-0352-203](#) [134-0132-300](#) [101-7130-09-201](#) [134-0351-203](#) [101-0975-003](#) [109-0111-200](#) [101-0935-003](#) [101-3830-09-300](#) [101-4630-09-200](#) [101-4630-09-203](#) [101-5030-09-100](#) [101-5030-09-101](#) [101-5030-09-200](#) [101-5030-09-300](#) [101-8430-09-200](#) [101-0931-003](#) [101-5030-09-201](#) [101-5030-09-203](#) [101-8430-09-201](#) [109-0112-200](#) [101-0937-003](#) [101-0972-003](#) [101-3830-09-301](#) [101-0974](#) [101-0972](#) [101-0975](#) [101-0971](#) [101-0973](#) [101-0934](#) [101-0932](#) [101-0935](#) [101-0931](#) [101-0933](#) [134-2133-200](#) [134-0333-200](#) [134-0376-203](#) [101-4630-09-201](#) [134-7551-203](#) [134-6451-200](#) [134-0351-200](#) [108-0132-200](#) [101-0933-003](#) [134-0111-200](#) [101-3830-09-206](#) [101-3830-09-203](#) [109-0135-200](#) [134-2137-200](#) [108-0137-200](#) [134-0375-200](#) [134-0332-200](#) [134-2132-200](#) [101-5030-09-301](#) [101-0932-003](#) [134-0334-200](#) [108-0131-200](#) [134-0373-200](#) [134-0373-203](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Dialight:](#)

[101-5030-0931-201](#) [101-3830-0931-201](#) [101-8430-0931-201](#)