

Certifications & Ratings

- RoHS compliant


Application

Dialight's 559 series LED panel mount indicator is available with a variety of LEDs including AlInGaP and InGaN technology for high brightness applications, bicolor and integral resistors.

- Fan tray assemblies
- Data-center Infrastructure (Servers and Storage)
- Next-Gen Wireless Infrastructure
- Electronic Test & Measurement Instruments
- Communications Testing Equipment
- Hand held Devices
- ... and many more!

Dimensions

inches [mm]

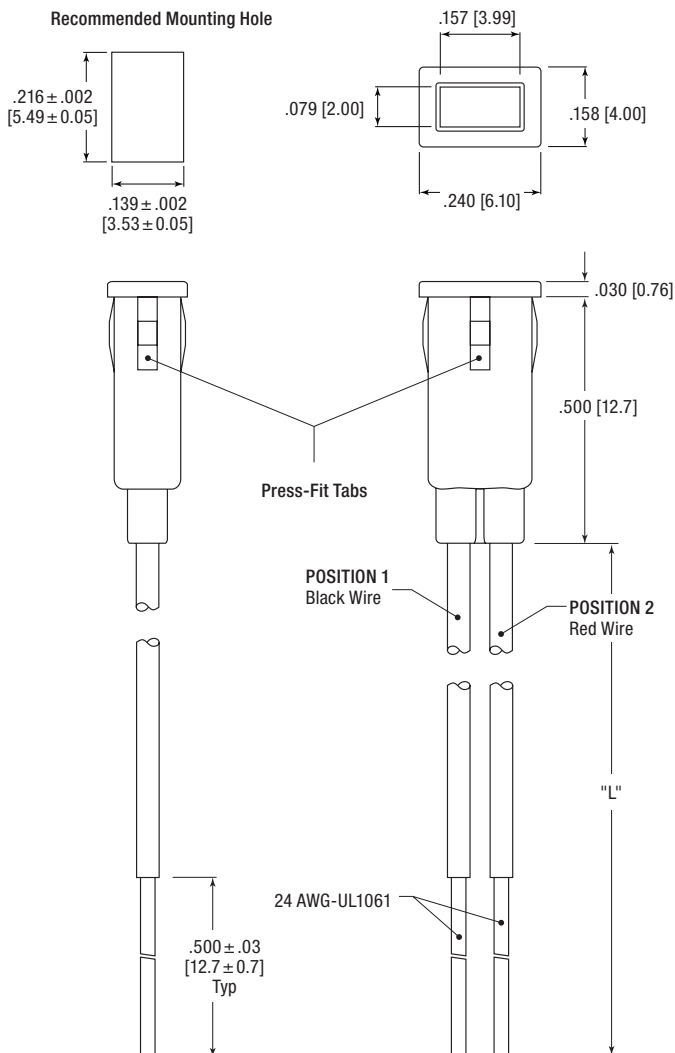

Mechanical Information

Mounting Hole Size: 0.216 ± .002" x .139 ± .002"
(5.49 ± .05 mm x 3.53 ± .05 mm)

Max Panel Thickness: 0.031 – 0.062" (.787 – 1.57 mm)

Specifications

Voltage Options: 1.6 – 2.3 V DC typical
(resistor required)

Operating Temp: See table

Storage Temp: See table


Electrical Connection: 24 AWG 14" lead wire

Housing: Black — UL94V-0 and enhances LED contrast

SINGLE COLOR LED SCHEMATIC



BICOLOR LED SCHEMATIC

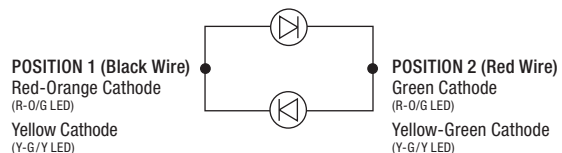



Ordering Information 559 Rectangle Series

Part Number Guide										RoHS Compliant			
5	5	9	-	8	X	X	0	-	0	0	7	F	
Color						Termination							
1	0	● Red						7	24 AWG 14" wire leads				
2	0	● Green											
3	0	● Yellow											
1	2	● Red-Orange / ● Green											
3	2	● Yellow-Green / ● Yellow											

Part Number	Color	Peak Wavelength (nm)	Intensity Typ. (mcd)	If Typ. (mA)	Vf Typ. (V DC)	Viewing Angle	Max DC Forward Current (mA)	Operating Temp	Storage Temp
559-8100-007F	Red	635	125	20	2.0	104	30	-55 °C to +100 °C	-55 °C to +100 °C
559-8200-007F	Green	565	120		2.1	104	30	-20 °C to +100 °C	
559-8300-007F	Yellow	585	140		2.1	104	20	-55 °C to +100 °C	
559-8120-007F	Red-Orange / Green	630 / 565	90 / 40		2.1	140	30	-55 °C to +100 °C	
559-8320-007F	Yellow-Green / Yellow	570 / 591	30 / 50		2.1	120	20	-30 °C to +85 °C	-40 °C to +100 °C

Dialight reserves the right to make changes at any time in order to supply the best product possible. The most current version of this document will always be available at: www.dialightsignalsandcomponents.com

Warranty Statement: Except for the warranty expressly provided for [herein/above/below], Dialight disclaims any and all other warranties, express or implied, including, without limitation, any warranties of merchantability, fitness for a particular purpose, title, and noninfringement.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[559-8100-007F](#) [559-8120-007F](#) [559-8200-007F](#) [559-8300-007F](#) [559-8320-007F](#)