





Dimensions


inches [mm]

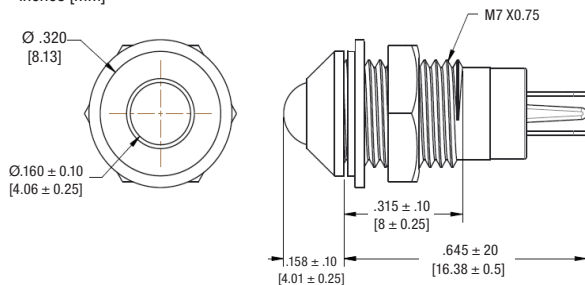


Non-Polarized
Figure 1

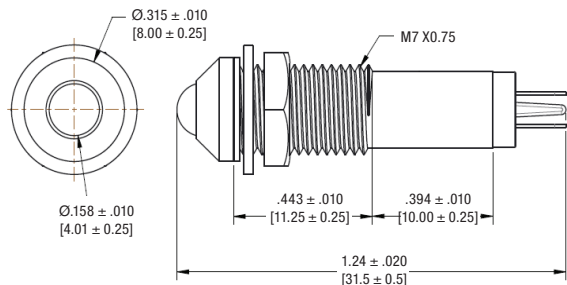

Non-Polarized
Figure 2

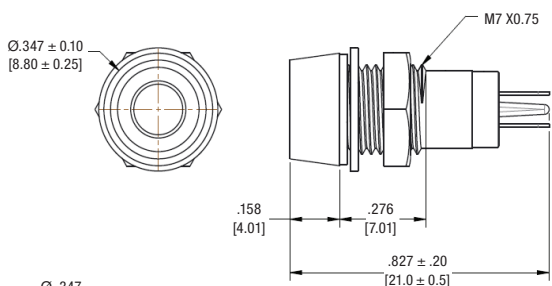

Non-Polarized
Figure 3

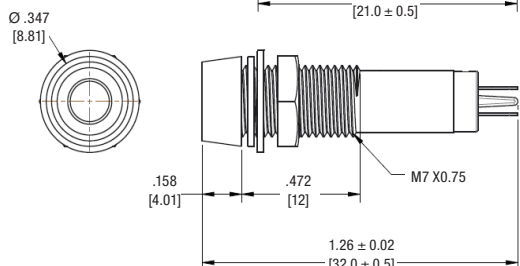

Non-Polarized
Figure 4

Certifications & Ratings

- RoHS compliant
- NEMA 4X (Watertight only)
- IP66 (Watertight only)

Application

The 607 Series LED Panel Mount Indicators are designed for a variety of applications such as:

- Main power indication
- Remote power indication
- Status indication
- Maintenance and warning indication
- Instrumentation


... and many more!

Mechanical Information

Mounting Hole Size:	0.283" (7.2 mm)
Max Panel Thickness:	See part numbers
Mounting Torque:	0.362 lbs/ft (5 kg/cm) 0.217 lbs/ft or 3 kg/cm (Figure 5 only)

Specifications

Voltage Options:	2 VDC and 3 VDC (resistor required) 6, 12 & 24 VDC (no resistor required)
Operating Temp:	-30 °C to +85 °C (-22 °F to +185 °F)
Storage Temp:	-40 °C to +85 °C (-40 °F to +185 °F)
Electrical Connection:	Solder terminals
Housing:	Protruding & recessed positions: Brass—Chrome Plated Internal position: Polycarbonate
Terminals:	Copper—Nickel Plated
Lock Washer:	Iron—Nickel Plated
Nut:	Brass—Nickel Plated

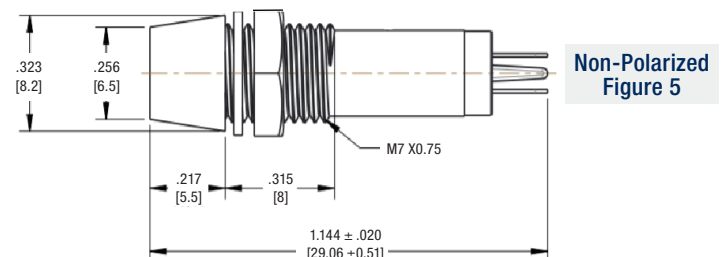

Non-Polarized
Figure 5

Ordering Information 607 Series

Standard		Watertight								
Part Number	Part Number	Color	Voltage (VDC)	Current (mA)	Intensity Typ. (mcd)	LED Positions	Polarity	Figure	Panel Thickness	
607-1112-110F	607-1112-310F	Red	2	15	40	Protruding	Non-Polarized (Bi-Directional LED)	1	0.187" (4.75 mm)	
607-1212-110F	607-1212-310F	Green	3		65					
607-1312-110F	607-1312-310F	Yellow	2		55					
607-1112-120F	607-1112-320F	Red	6		40			2	0.265" (6.75 mm)	
607-1212-120F	607-1212-320F	Green			65					
607-1312-120F	607-1312-320F	Yellow			55					
607-1112-130F	607-1112-330F	Red	12		40					
607-1212-130F	607-1212-330F	Green			65					
607-1312-130F	607-1312-330F	Yellow			55					
607-2112-110F	607-2112-310F	Red	2		65	Recessed		3	0.136" (3.45 mm)	
607-2212-110F	607-2212-310F	Green	3		85					
607-2312-110F	607-2312-310F	Yellow	2		70					
607-2112-120F	607-2112-320F	Red	6		65			4	0.336" (8.50 mm)	
607-2212-120F	607-2212-320F	Green			85					
607-2312-120F	607-2312-320F	Yellow			70					
607-2112-130F	607-2112-330F	Red	12		65					
607-2212-130F	607-2212-330F	Green			85					
607-2312-130F	607-2312-330F	Yellow			70					
607-3132-120F	607-3132-320F	Red	6		35	Internal		Polarized	5	0.187" (4.75 mm)
607-3232-120F	607-3232-320F	Green			45					
607-3332-120F	607-3332-320F	Yellow			40					
607-3132-130F	607-3132-330F	Red	12		35					
607-3232-130F	607-3232-330F	Green			45					
607-3332-130F	607-3332-330F	Yellow			40					
607-3132-140F	607-3132-340F	Red	24		35					
607-3232-140F	607-3232-340F	Green			45					
607-3332-140F	607-3332-340F	Yellow			40					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

607-1212-120F	607-1112-120F	607-2312-130F	607-2112-110F	607-2312-110F	607-2312-120F	607-2212-110F
607-3232-120F	607-2112-130F	607-2212-120F	607-2112-120F	607-3232-130F	607-2212-130F	607-3132-120F
607-1212-130F	607-1112-130F	607-1212-110F	607-3132-130F	607-3332-120F	607-1312-120F	607-3332-130F
607-1312-110F	607-1112-110F	607-1312-130F	607-3132-140F	607-1312-310F	607-3332-340F	607-3132-340F
607-3132-330F	607-1212-320F	607-3232-140F	607-3232-340F	607-2212-330F	607-3332-330F	607-1112-330F
607-2312-310F	607-1112-310F	607-1212-310F	607-2212-310F	607-2112-330F	607-1212-330F	607-2112-310F
607-3132-320F	607-2312-330F	607-3232-330F	607-1112-320F	607-1312-330F	607-3332-140F	607-2312-320F
607-2412-120F	607-2512-120F	607-1115-320F	607-1115-330F	607-1215-320F	607-1215-330F	607-1315-320F
607-1315-330F	607-2115-320F	607-2115-330F	607-2215-320F	607-2215-330F	607-2315-320F	607-2315-330F
607-3135-320F	607-3135-330F	607-3135-340F	607-3235-320F	607-3235-330F	607-3235-340F	607-3335-320F
607-3335-330F	607-3335-340F	607-1412-110F	607-1412-120F	607-1512-110F	607-1512-120F	607-2412-110F
607-2412-130F	607-2412-140F	607-2415-120F	607-2415-130F	607-2415-140F	607-2512-110F	607-2512-130F
607-2512-140F	607-2515-120F	607-2515-130F	607-2515-140F			