



682 SERIES

12mm High Intensity Panel Mount Indicators

MECHANICAL / SPECIFICATIONS

MOUNTING HOLE SIZE:

0.492" (12.5 mm)

MAX PANEL THICKNESS:

0.236" (6.0 mm)

MOUNTING TORQUE:

0.217 lbs/ft (3 kg/cm)

VOLTAGE OPTIONS:

6, 12 & 24VDC (no resistor required)

OPERATING TEMP:

-20 °C to +75 °C (-4 °F to +167 °F)

STORAGE TEMP:

-40 °C to +100 °C (-40 °F to +212 °F)

ELECTRICAL CONNECTION:

Solder terminals or
26AWG UL 1007 6" wire leads

HOUSING:

Polycarbonate

TERMINALS:

Copper-Nickel Plated

LOCK WASHER:

Iron-Nickel Plated

NUT:

Brass-Nickel Plated

CERTIFICATIONS & RATINGS


RoHS compliant

APPLICATION

The 682 Series LED Panel Mount Indicators are designed for a variety of applications such as:

- Main power indication
- Remote power indication
- Status indication
- Maintenance and warning indication
- Instrumentation

DIMENSIONS inches [mm]

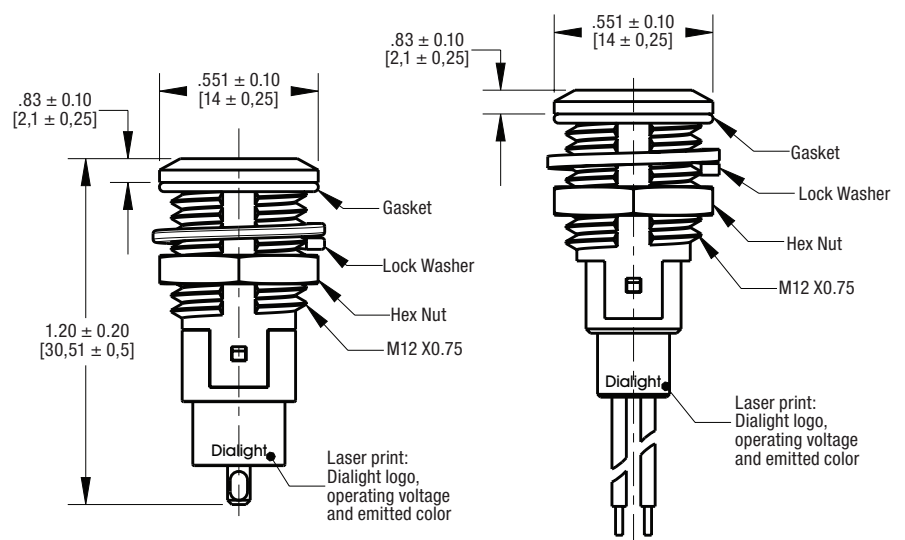

These indicators are un-polarized

ORDERING INFORMATION

Part Number		Color	Voltage (VDC)	Current (mA)	Intensity Typ. (mcd)
Terminals	Wire Leads				
682-3132-121F	682-3135-121F	● Red	6	15	510
682-3232-122F	682-3235-122F	● Green			2225
682-3332-123F	682-3335-123F	● Orange			510
682-3432-124F	682-3435-124F	● Blue			260
682-3132-131F	682-3135-131F	● Red	12		510
682-3232-132F	682-3235-132F	● Green			2225
682-3332-133F	682-3335-133F	● Orange			510
682-3432-134F	682-3435-134F	● Blue			260
682-3132-141F	682-3135-141F	● Red	24		510
682-3232-142F	682-3235-142F	● Green			2225
682-3332-143F	682-3335-143F	● Orange			510
682-3432-144F	682-3435-144F	● Blue			260



Dialight reserves the right to make changes at any time in order to supply the best product possible. The most current version of this document will always be available at: www.dialightsignalsandcomponents.com

Warranty Statement: Except for the warranty expressly provided for at: www.dialight.com/resources/warranties/, Dialight disclaims any and all other warranties, express or implied, including, without limitation, any warranties of merchantability, fitness for a particular purpose, title, and noninfringement.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[682-3335-133F](#) [682-3135-121F](#) [682-3435-124F](#) [682-3232-142F](#) [682-3235-142F](#) [682-3135-131F](#) [682-3432-144F](#)
[682-3132-121F](#) [682-3335-143F](#) [682-3235-132F](#) [682-3332-123F](#) [682-3132-131F](#) [682-3235-122F](#) [682-3135-141F](#)
[682-3332-143F](#) [682-3432-134F](#) [682-3435-134F](#) [682-3332-133F](#) [682-3335-123F](#) [682-3432-124F](#) [682-3132-141F](#)
[682-3435-144F](#) [682-3232-132F](#) [682-3232-122F](#)