



## MICRODRIVER MLV3



### FEATURES / BENEFITS

- ▲ 10-30 Volt DC input
- ▲ Compact in size
- ▲ Very lightweight
- ▲ Short and open circuit protected
- ▲ 350mA or 700mA models available

### OPERATING CONDITIONS

- ▲ Operating Ambient Temperature -10°C to +70°C
- ▲ Maximum case temperature 85°C
- ▲ Input voltage 10-30VDC
- ▲ 350mA version drives 1-3 LEDs,  $V_{out}$  : 3-12VDC
- ▲ 700mA version drives 1 to 2 LEDs with min 12V input & 1 to 4 LEDs with min 23V input,  $V_{out}$  : 4-18VDC

### MECHANICAL DIMENSIONS

51.0mm X 32.0mm X 18.0mm  
(2.01" X 1.26" X 0.71")

### APPLICATION

- ▲ Low voltage track lighting
- ▲ Landscape lighting
- ▲ Emergency lighting
- ▲ Signage
- ▲ Vehicle lighting
- ▲ Beacons and signage

### PART NUMBERS

MLV3-C-35 : 350mA version  
MLV3-C-70 : 700mA version

Dialight reserves the right to make changes at any time  
in order to supply the best product possible.


**Dialight Corporation**

1501 Route 34 South • Farmingdale, NJ 07727 USA  
Tel: (1) 732-919-3119 • Fax: (1) 732-751-5778 • [www.dialight.com](http://www.dialight.com)




MDEXLUMMLV3\_B

MECHANICAL DRAWING

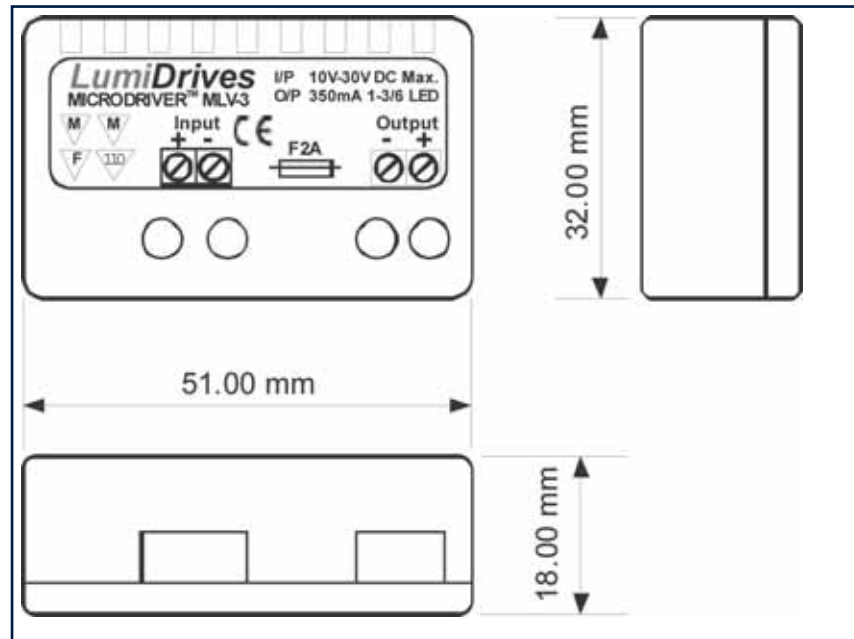

WIRING INFORMATION (350MA VERSION)

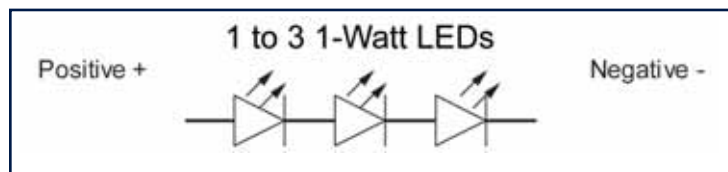

Dialight reserves the right to make changes at any time in order to supply the best product possible.

**Dialight Corporation**  
1501 Route 34 South • Farmingdale, NJ 07727 USA  
Tel: (1) 732-919-3119 • Fax: (1) 732-751-5778 • [www.dialight.com](http://www.dialight.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

[MLV-3C70](#) [MLV-3C35](#)