



Dimensions

inches [mm]

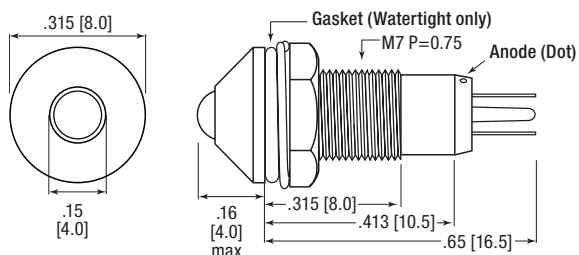


Figure 1

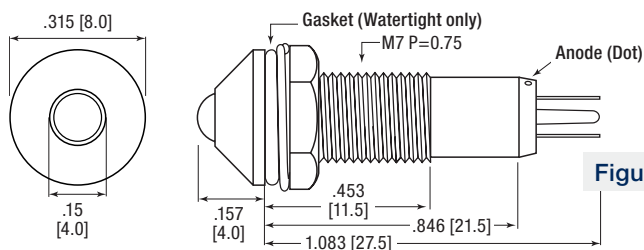


Figure 2

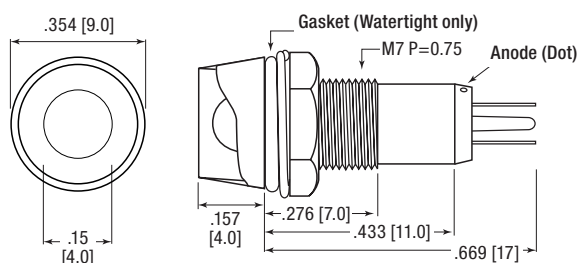


Figure 3

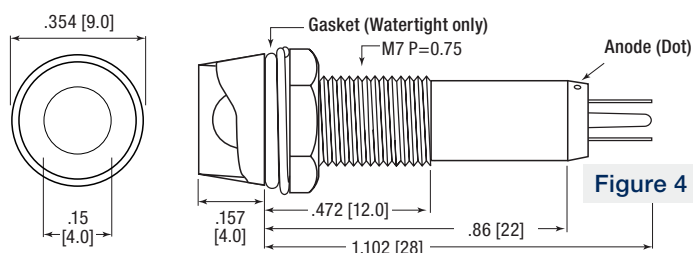


Figure 4

Certifications & Ratings

- RoHS compliant
- NEMA 4X (Watertight only)
- IP66 (Watertight only)

Application

The 607 Series LED Panel Mount Indicators are designed for a variety of applications such as:

- Main power indication
- Remote power indication
- Status indication
- Maintenance and warning indication
- Instrumentation

... and many more!

Mechanical Information

Mounting Hole Size:	0.283" (7.2 mm)
Max Panel Thickness:	See part numbers
Mounting Torque:	0.362 lbs/ft (5 kg/cm) 0.217 lbs/ft or 3 kg/cm (Figure 5 only)

Specifications

Voltage Options:	2 VDC (resistor required) 6, 12 & 24 VDC (no resistor required)
Operating Temp:	-30 °C to +85 °C (-22 °F to +185 °F)
Storage Temp:	-40 °C to +85 °C (-40 °F to +185 °F)
Electrical Connection:	Solder terminals
Housing:	Protruding & recessed positions: Brass—Chrome Plated Internal position: Polycarbonate
Terminals:	Copper—Nickel Plated
Lock Washer:	Iron—Nickel Plated
Nut:	Brass—Nickel Plated

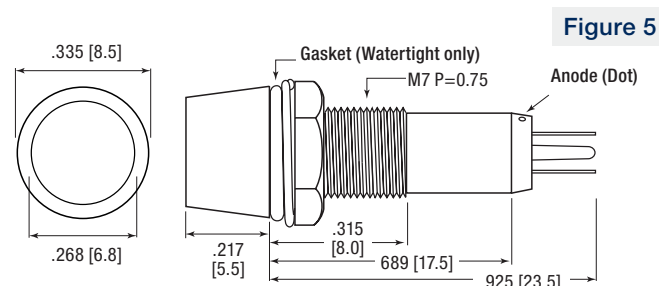


Figure 5

Ordering Information 607 Series

Standard	Watertight							
Part Number	Part Number	Color	Voltage (VDC)	Current (mA)	Intensity Typ. (mcd)	LED Positions	Figure	Panel Thickness
607-1112-110F	607-1112-310F	● Red	2	15	40	Protruding	1	0.187" (4.75 mm)
607-1212-110F	607-1212-310F	● Green			65			
607-1312-110F	607-1312-310F	● Yellow			55			
607-1112-120F	607-1112-320F	● Red	6		40		2	0.265" (6.75 mm)
607-1212-120F	607-1212-320F	● Green			65			
607-1312-120F	607-1312-320F	● Yellow			55			
607-1112-130F	607-1112-330F	● Red	12		40			
607-1212-130F	607-1212-330F	● Green			65			
607-1312-130F	607-1312-330F	● Yellow			55			
607-2112-110F	607-2112-310F	● Red	2		65	Recessed	3	0.136" (3.45 mm)
607-2212-110F	607-2212-310F	● Green			85			
607-2312-110F	607-2312-310F	● Yellow			70			
607-2112-120F	607-2112-320F	● Red	6		65		4	0.336" (8.50 mm)
607-2212-120F	607-2212-320F	● Green			85			
607-2312-120F	607-2312-320F	● Yellow			70			
607-2112-130F	607-2112-330F	● Red	12		65			
607-2212-130F	607-2212-330F	● Green			85			
607-2312-130F	607-2312-330F	● Yellow			70			
607-3132-120F	607-3132-320F	● Red	6		35	Internal	5	0.187" (4.75 mm)
607-3232-120F	607-3232-320F	● Green			45			
607-3332-120F	607-3332-320F	● Yellow			40			
607-3132-130F	607-3132-330F	● Red	12		35			
607-3232-130F	607-3232-330F	● Green			45			
607-3332-130F	607-3332-330F	● Yellow			40			
607-3132-140F	607-3132-340F	● Red	24		35			
607-3232-140F	607-3232-340F	● Green			45			
607-3332-140F	607-3332-340F	● Yellow			40			

Dialight reserves the right to make changes at any time in order to supply the best product possible. The most current version of this document will always be available at: www.dialightsignalsandcomponents.com
Warranty Statement: Except for the warranty expressly provided for [herein/above/below], Dialight disclaims any and all other warranties, express or implied, including, without limitation, any warranties of merchantability, fitness for a particular purpose, title, and noninfringement.



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

<u>607-1212-120F</u>	<u>607-1112-120F</u>	<u>607-2312-130F</u>	<u>607-2112-110F</u>	<u>607-2312-110F</u>	<u>607-2312-120F</u>	<u>607-2212-110F</u>
<u>607-3232-120F</u>	<u>607-2112-130F</u>	<u>607-2212-120F</u>	<u>607-2112-120F</u>	<u>607-3232-130F</u>	<u>607-2212-130F</u>	<u>607-3132-120F</u>
<u>607-1212-130F</u>	<u>607-1112-130F</u>	<u>607-1212-110F</u>	<u>607-3132-130F</u>	<u>607-3332-120F</u>	<u>607-1312-120F</u>	<u>607-3332-130F</u>
<u>607-1312-110F</u>	<u>607-1112-110F</u>	<u>607-1312-130F</u>	<u>607-3132-140F</u>	<u>607-3232-140F</u>	<u>607-3332-140F</u>	