



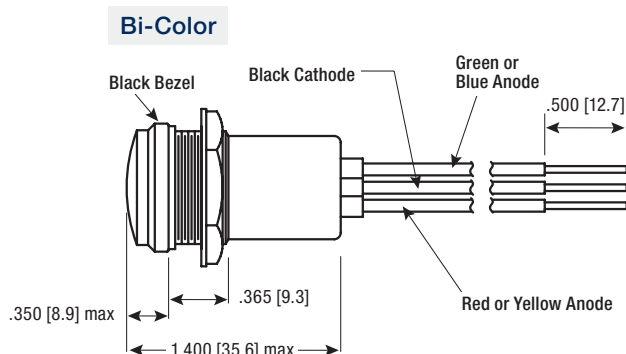


Dimensions


inches [mm]

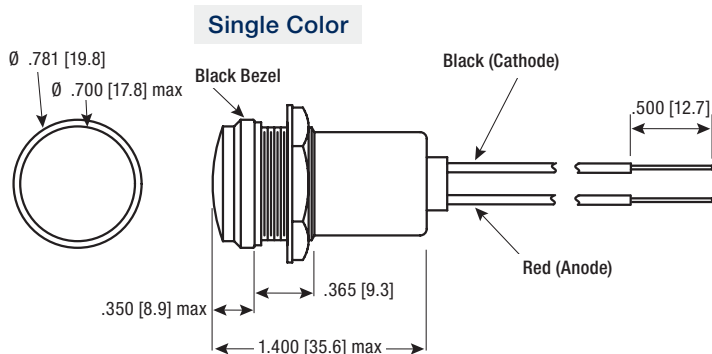

Back View of Housing

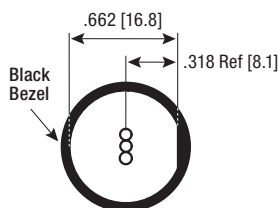

Recommended Mounting Hole

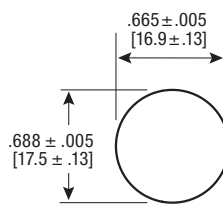

Certifications & Ratings

- RoHS Compliant
- Watertight to Mil-L-3661B spec

Application

The 557 Series LED Panel Mount Indicators incorporate both InGaN and AlInGaP technologies to offer higher intensities. This is a highly durable package, designed to withstand outdoor applications susceptible to rain, dust, and sunlight.

- Instrument panels
- Safety applications
- Transportation—rail, bus, airline
- Vending, gaming
- Lane control
- ... and many more!

Mechanical information

Mounting Hole Size: 0.687" (17.46 mm)

Max Panel Thickness: 0.156" (3.96 mm)

Mounting Torque: 15 in-lbs torque

Specifications

Voltage Options: 5, 12, 24, and 28 VDC (bi-color: 5 VDC)

Operating Temp: -25 °C to +85 °C
(bi-color: -30 °C to +80 °C)

Storage Temp: -30 °C to +100 °C
(bi-color: -40 °C to +85 °C)

Electrical Connection: 24 AWG Wire Leads

Housing: White Polycarbonate

Lens Material: Transparent Polycarbonate (UL 94V-0)

Wire Leads: 5.5"

Lock Washer: Phosphor Bronze—White Nickel Plated

Nut: Brass—White Nickel Plated

Ordering Information 557 Series

Part Number Guide

RoHS Compliant

5	5	7	-	1	X	X	X	-	2	0	3	F						
Color					Voltage													
○ White	0	0																
● Red	5	0																
● Green	6	0	2	5VDC														
● Yellow	7	0	3	12VDC*														
● Blue	8	0	4	28VDC*														
● ● Red / Green	4	1	5	*single color only														
● ● Red / Blue	4	2																
● ● Yellow / Green	4	3																
● ● Yellow / Blue	4	4																
● ● Yellow / Red	4	5																

Part Number	Color	Voltage (V DC)	Current (mA)	Typical Intensity (mcd)
557-1002-203F	○ White	5	16	5350
557-1502-203F	● Red		80	800
557-1602-203F	● Green		16	4900
557-1702-203F	● Yellow		80	1550
557-1802-203F	● Blue		16	1200
557-1412-203F	● Red / Green		70 / 16	720 / 1800
557-1422-203F	● Red / Blue		70 / 16	625 / 425
557-1432-203F	● Yellow / Green		70 / 16	585 / 1700
557-1442-203F	● Yellow / Blue		70 / 16	635 / 445
557-1452-203F	● Yellow / Red		70 / 20	650 / 350
557-1003-203F	○ White	12	16	5350
557-1503-203F	● Red		20	800
557-1603-203F	● Green		16	4900
557-1703-203F	● Yellow		20	1550
557-1803-203F	● Blue		16	1200
557-1005-203F	○ White	24	16	5350
557-1505-203F	● Red		20	800
557-1605-203F	● Green		16	4900
557-1705-203F	● Yellow		20	1550
557-1805-203F	● Blue		16	1200
557-1604-203F	● Green	28	16	4900
557-1704-203F	● Yellow		20	1550
557-1804-203F	● Blue		16	1200

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Dialight:

<u>557-1805-203F</u>	<u>557-1203-203F</u>	<u>557-1703-203F</u>	<u>557-1602-203F</u>	<u>557-1705-203F</u>	<u>557-1603-203F</u>	<u>557-1502-203F</u>
<u>557-1803-203F</u>	<u>557-1503-203F</u>	<u>557-1802-203F</u>	<u>557-1505-203F</u>	<u>557-1605-203F</u>	<u>557-1412-203F</u>	<u>557-1702-203F</u>
<u>557-1432-203F</u>	<u>557-1002-203F</u>	<u>557-1003-203F</u>	<u>557-1005-203F</u>	<u>557-1422-203F</u>	<u>557-1442-203F</u>	<u>557-1452-203F</u>
<u>557-1303-203F</u>	<u>557-1804-203F</u>	<u>557-1704-203F</u>	<u>557-1604-203F</u>			