

QBiX-Lite SDM Kits

Media Display System with Intel® Smart Display Module (Intel® SDM) Support



Specifications

Dimension	195W x 158D x 30H(mm)
CPU	Support SDM module as follows: SDM-1135G7L SDM-1115G4L SDM-7300L (with Intel vPro support) SDM-7100L SDM-4000L SDM-3350L-HW SDM-3350L-QV
Memory	Depends on SDM module: SDM-1135G7L (2 x DDR4 SO-DIMM sockets, Dual Channel 3200 MHz memory Modules, Max. Capacity 64 GB) SDM-1115G4L (2 x DDR4 SO-DIMM sockets, Dual Channel 3200 MHz memory Modules, Max. Capacity 64 GB) SDM-7300L (2 x DDR4 SO-DIMM sockets, Dual Channel 2133 MHz memory Module, Max. Capacity 32 GB) SDM-7100L (2 x DDR4 SO-DIMM sockets, Dual Channel 2133 MHz memory Module, Max. Capacity 32 GB) SDM-4000L (2 x DDR4 SO-DIMM sockets, Dual Channel 2400 MHz memory Module, Max. Capacity 8 GB) SDM-3350L-HW (2 x DDR3L SO-DIMM sockets, Dual Channel 1866 MHz memory Module, Max. Capacity 8 GB) SDM-3350L-QV (2 x DDR3L SO-DIMM sockets, Dual Channel 1866 MHz memory Module, Max. Capacity 8 GB)
Ethernet	1 x GbE LAN port

Features


- SDM Chassis Kit (Support SDM Module)
- System Size: 195W x 158D x 30H (mm)

Graphic Support	Depends on SDM module: SDM-1135G7L (3 x HDMI 2.0, 1 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz) SDM-1115G4L (3 x HDMI 2.0, 1 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz) SDM-7300L (1 x HDMI 2.0, 1 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz) SDM-7100L (1 x HDMI 2.0, 1 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz) SDM-4000L (1 x HDMI 2.0, 1 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz) SDM-3350L-HW (1 x HDMI 2.0, 1 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz) SDM-3350L-QV (1 x HDMI 2.0, 2 x Display Port, supporting a maximum resolution of 4096x2160 @60Hz)
Audio	Intel® Integrated Audio
Storage	Depends on SDM module: SDM-1135G7L (TBD) SDM-1115G4L (TBD) SDM-7300L (TBD) SDM-7100L (TBD) SDM-4000L (1 x eMMC 32GB) SDM-3350L-HW (1 x eMMC 32GB) SDM-3350L-QV (1 x eMMC 32GB)
Expansion Slots	1 x 2280 M.2 M-Key (SATA 6Gb/s) 1 x 2230 M.2 E-key (WiFi/BT)
Rear I/O	1 x USB 3.0 1 x Display Port (Co-lay with front Display port) 1 x HDMI 1 x UART 1 x DC-Jack 1 x 2x2 Power connector
Power	DC +12V/+19V/+24V SDM-1135G7L / SDM-1115G4L : 19V / 90W adapter SDM-7300L / SDM-7100L / SDM-4000L / SDM-3350-HW / SDM-3350-QV : 19V / 65W adapter
Operation Temperature	Operating temperature: 0°C to 50°C Operating humidity: 0-90% (non-condensing) Non-operating temperature: -20°C to 70°C Non-operating humidity: 0%-95% (non-condensing) Use wide temperature range memory and storage
Vibration During Operation	Operation: IEC 60068-2-64, 1 Grms, random, 5 ~ 500 Hz, 1 hr / Per Axis, With SSD/M.2 2242 Non-operation: IEC 60068-2-6, 2 G, Sine, 10 ~ 500 Hz, 1 Oct/min, 1 hr / Per Axis
Shock During Operation	Operation: IEC 60068-2-27, 50 G, half sine, 11 ms duration, with SSD

GIGAIPC reserves the right to modify or change technical data without prior notice.

Dimension

Unit: mm

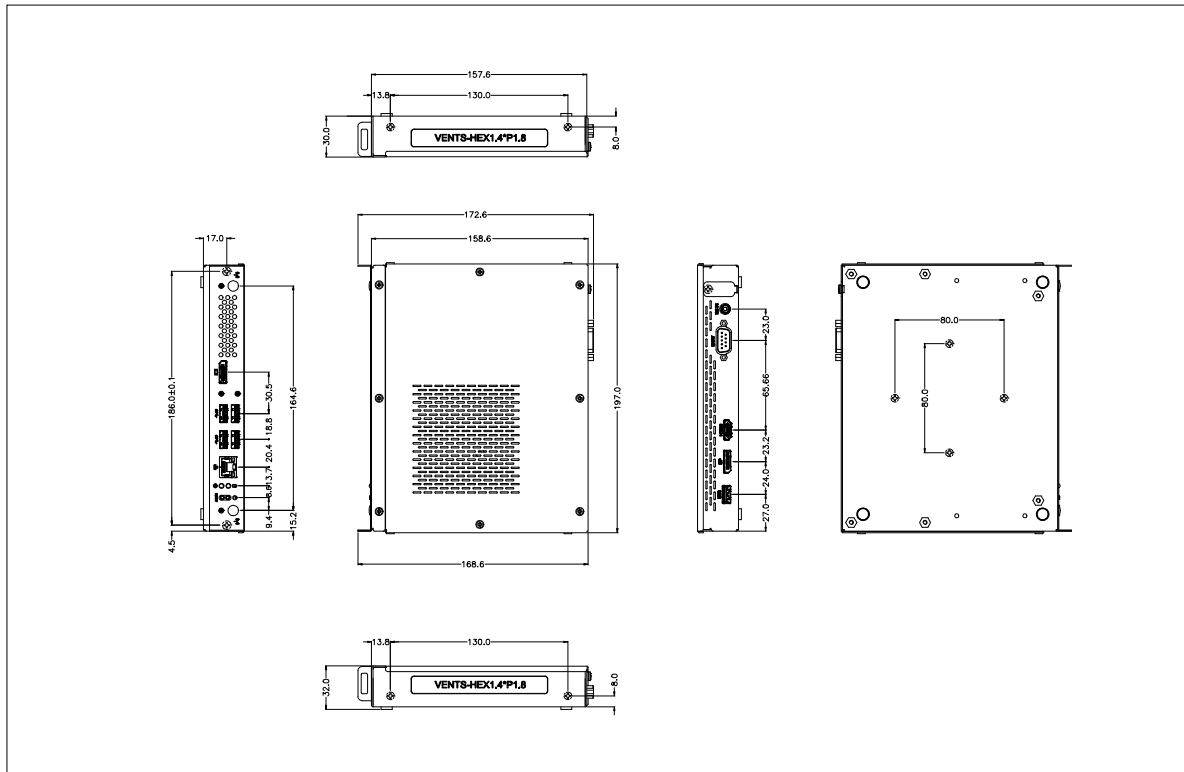

Packing Content

- Box Packing Capacity: 10
- Carton size: 25AC0-400000-Y1R (464x376x367mm)
- Content:
 - Bracket for Wall Mount x 2: 25HB1-SD4000-R0R
 - PSU ADP 19V 65W x 1 or 19V 90W x 1 (depends on SDM module)
 - Power Cord: Optional (by region)

Order Information

- System: 6BSD4000AMR-SI

GIGAIPC reserves the right to modify or change technical data without prior notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

GIGAIPC:

QBiX-Lite-SDM Kits