

## Peak Emission Wavelength: 470nm


The MTE4047N2-UB consists of a 470nm high output blue die in a water-clear 5mm plastic molded package. Custom package solutions and sorting are available.

### FEATURES

- > High Output Power
- > High Reliability

### APPLICATIONS

- > Optical Sensors
- > Color Sensor (Money-bill)
- > Paper Sensor (Money-bill)

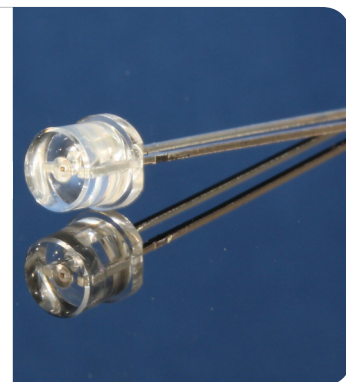

## Absolute Maximum Ratings (Ta=25°C)







| ITEMS                        | SYMBOL | RATINGS    | UNIT |
|------------------------------|--------|------------|------|
| Forward Current (DC)         | IF     | 50         | mA   |
| Forward Current (Pulse)*1    | IFP    | 0.5        | A    |
| Reverse Voltage              | VR     | 5          | V    |
| Power Dissipation            | PD     | 140        | mW   |
| Operating Temperature Range  | Topr   | -20 ~ +80  | °C   |
| Storage Temperature Range    | Tstg   | -30 ~ +100 | °C   |
| Junction Temperature         | Tj     | 100        | °C   |
| Lead Soldering Temperature*2 | Tls    | 260        | °C   |

\*1: Tw=10μsec, T=10msec; \*2: Time 5 Sec max, Position: Up to 3mm from the body.


## Electrical & Optical Characteristics (Ta = 25°C)

| ITEMS                     | SYMBOL | CONDITIONS | MIN | TYP  | MAX | UNIT |
|---------------------------|--------|------------|-----|------|-----|------|
| Power Output              | PO     | IF=20mA    | --  | 15.0 | --  | mW   |
| Forward Voltage           | VF     | IF=20mA    | --  | 3.0  | 3.5 | V    |
| Reverse Current           | IR     | VR=5V      | --  | --   | 100 | μA   |
| Peak Emission Wavelength  | λp     | IF=20mA    | --  | 470  | --  | nm   |
| Spectral Line Half Width  | Δλ     | IF=20mA    | --  | 35   | --  | nm   |
| Half Intensity Beam Angle | Θ      | IF=20mA    | --  | ±40  | --  | deg  |

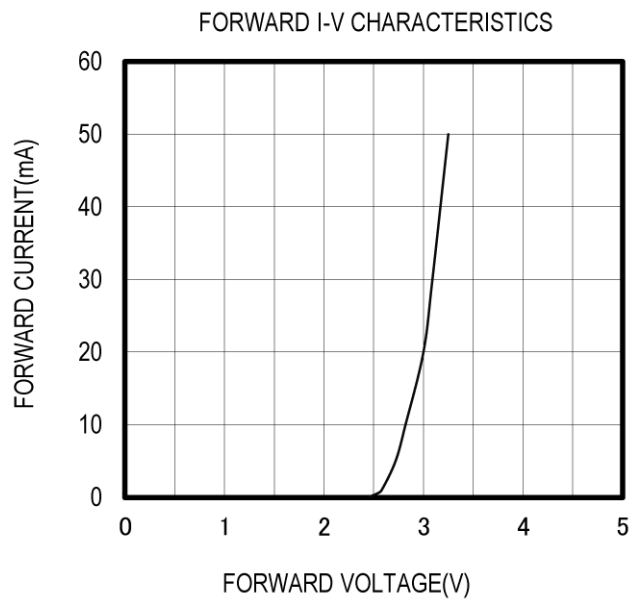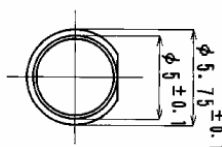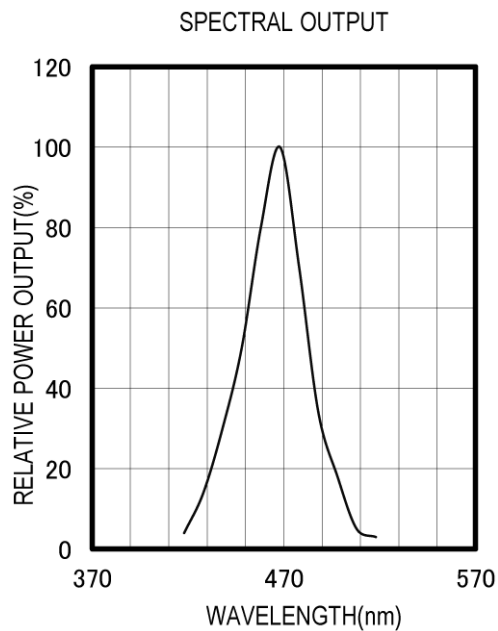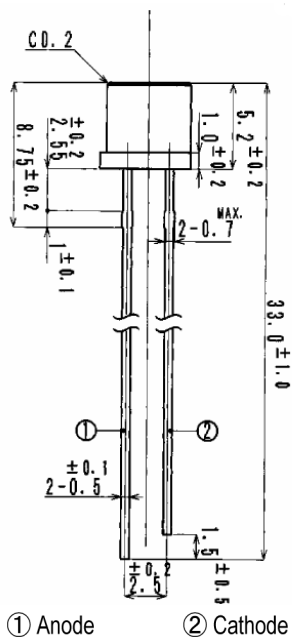


Unit: mm, Tolerance:  $\pm 0.2$


RELATIVE POWER vs FORWARD CURRENT

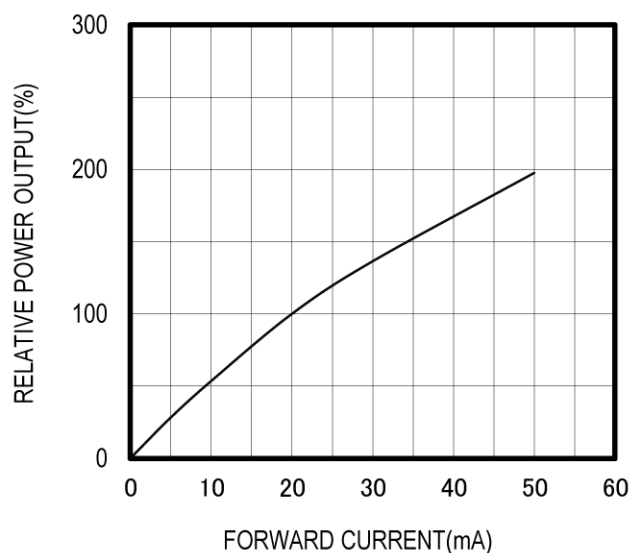

THERMAL DERATING CURVE

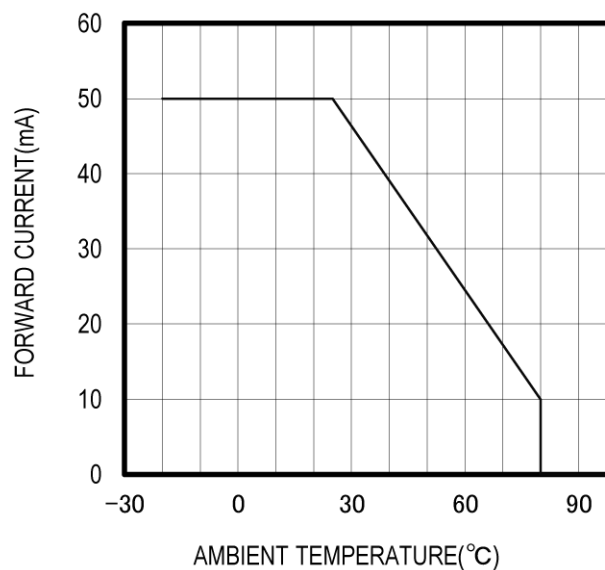

RADIATION PATTERN

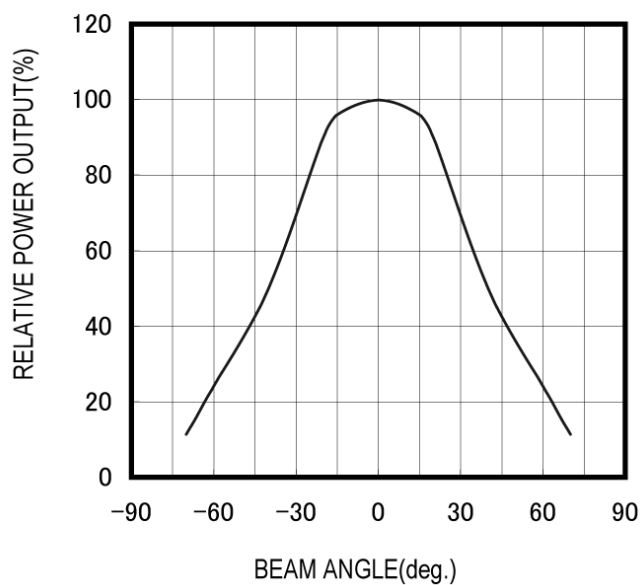

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Marktech Optoelectronics:](#)

[MTE4047N2-UB](#)