



4-PIN TO 4-PIN POWER CABLE

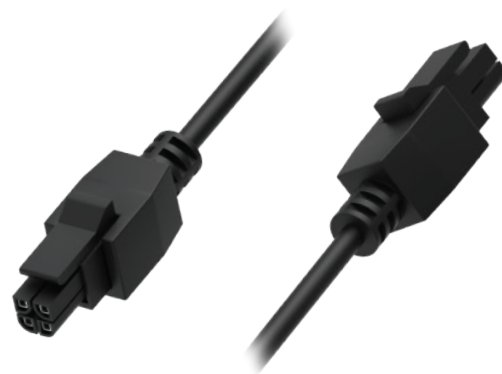

TECHNICAL DATA

GENERAL

Input connector	4-pin, 3 mm pitch
Input voltage max	30 VDC
Output connector	4-pin, 3 mm pitch
Conductor cross section	Stranded, cross section 4 x 0.20 mm ² (24 AWG)
Cable outer diameter	4.5 mm
Maximum current	2 A
Weight	47 g
Total Length	1000 mm
Protection material	PVC 60P BLACK
Flammability rating	UL 94 V-2
RoHS	✓
REACH	✓

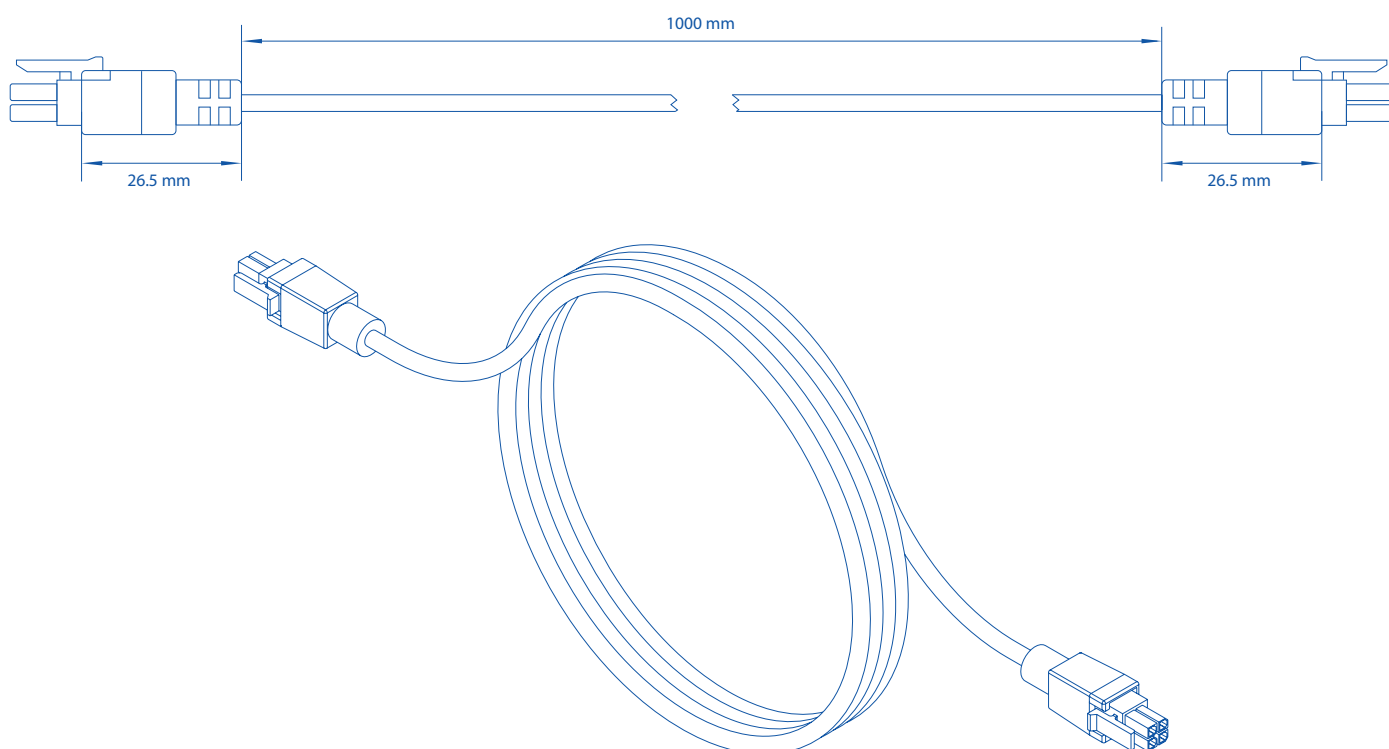

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teltonika:](#)

[PR2PP10B](#)