


MOBILE ADHESIVE SMA ANTENNA

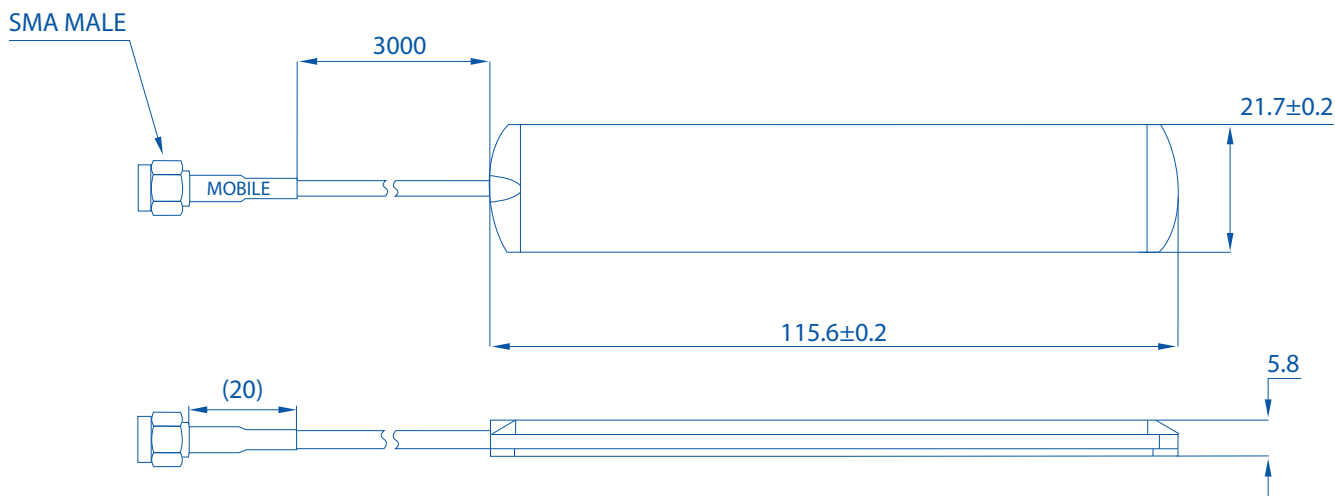

PARAMETER	RATED VALUE
Frequency	824-960/1710-2170 MHz
Polarization	Linear
Gain	2 dBi
V.S.W.R	< 2.0
Impedance	50 Ω
Cable	RG174, 3000 mm
Connector	SMA male
Mounting Method	Adhesive
Operating Temperature	-40 °C to +85 °C
Operating Relative Humidity	95 % max
IP rating	IP50
RoHS Compliant	v



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teltonika:](#)

[PR1AS420](#)