

MOBILE SMA ANTENNA



PARAMETER

Frequency Range

RATED VALUE

698-960/1710-2690 MHz

Polarization

Linear

Gain

3 dBi

V.S.W.R

< 3.0

Impedance

50 Ω

Connector

SMA Male

Operating Temperature


-40 °C to +85 °C

IP rating

IP33

RoHS Compliant

v

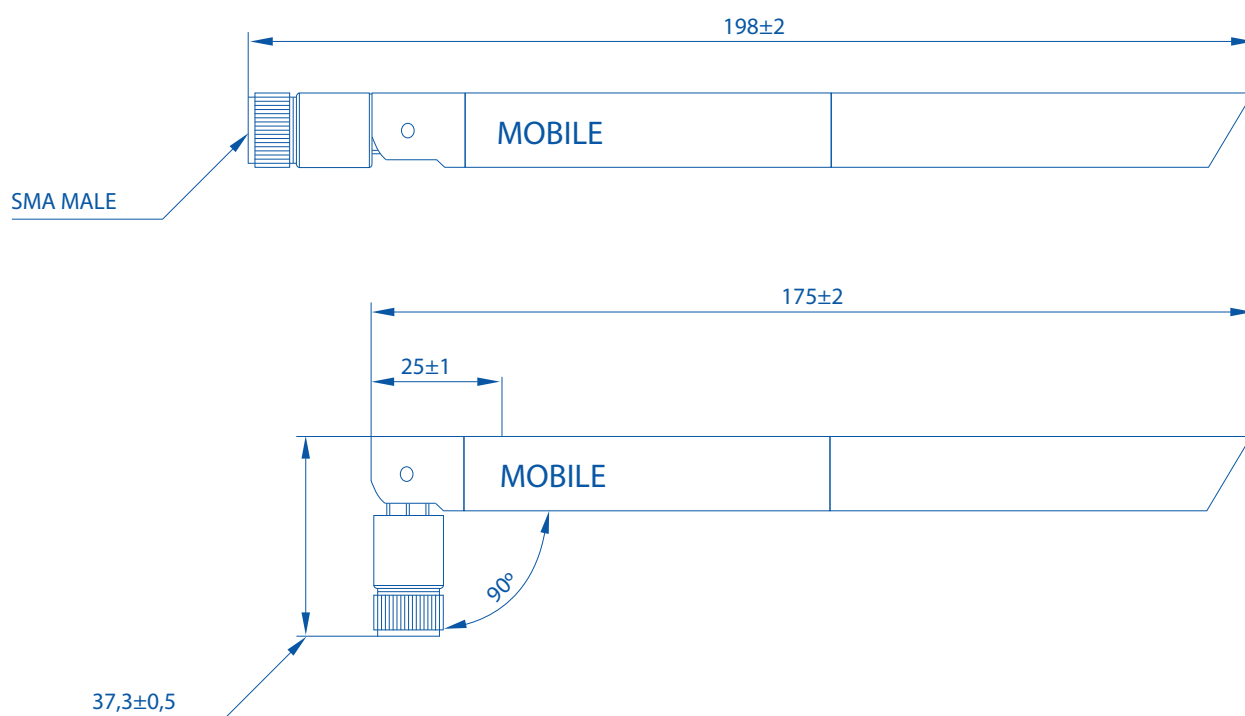

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teltonika:](#)

[PR1US440](#)