


2X5 PIN CONNECTOR

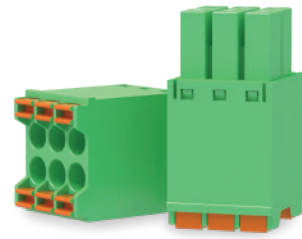

2X3 PIN CONNECTOR

TECHNICAL DATA

GENERAL

Voltage rating	300 V
Current rating	8 A
Withstand voltage	1600 V/1min
Wire range AWG	24 - 16 AWG
Temperature range	-40°C +105°C
Insulator material	PA66
Internal contacts material	Copper alloy
Internal contacts finishing	Sn plated

ADDITIONAL









Strip Length	9 - 10 mm
Pitch	3.5 mm
Shrapnel	Stainless steel
Conductor cross section	0.2 - 1.5 mm ²
Poles	2 x 5
Flammability rating	UL 94 V-0
RoHS	✓
REACH	✓

GENERAL

Voltage rating	300 V
Current rating	8 A
Withstand voltage	1600 V/1min
Wire range AWG	24 - 16 AWG
Temperature range	-40°C +105°C
Insulator material	PA66
Internal contacts material	Copper alloy
Internal contacts finishing	Sn plated

ADDITIONAL

Strip Length	9 - 10 mm
Pitch	3.5 mm
Shrapnel material	Copper alloy
Conductor cross section	0.2 - 1.5 mm ²
Poles	2 x 3
Flammability rating	UL 94 V-0
RoHS	✓
REACH	✓

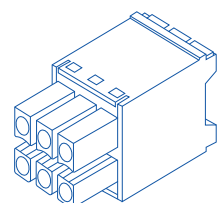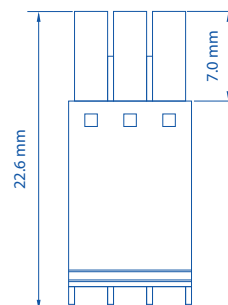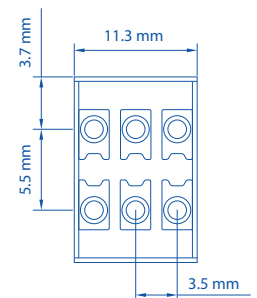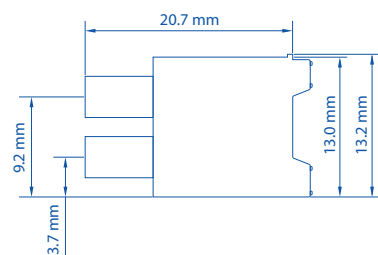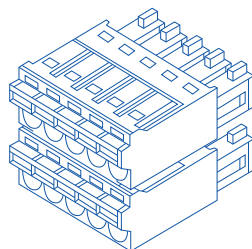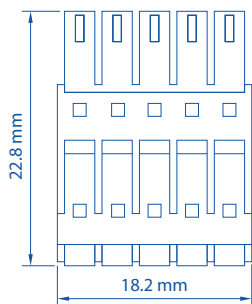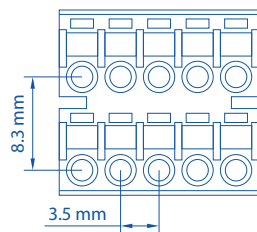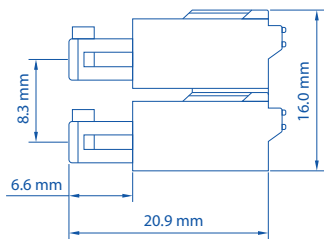

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teltonika:](#)

[PR5MEC15](#)