

# APPC 1540T

15" TFT XGA 4:3 Flush Panel PC with Intel® Celeron® J1900, up to 2.0GHz,  
Touch Screen, 4GB DDR3L, 3 x USB, 2 x COM



## Main Features

- ♦ 4:3 15" XGA fanless LED panel computer
- ♦ Intel® Celeron® J1900, Quad Core, low consumption CPU
- ♦ Flush panel by 5-wire touch screen
- ♦ Dual GbE/2nd display-VGA/Line-out
- ♦ 3 x USB/2 x mini-PCIe sockets/1 x CFast/2 x RS232/422/485
- ♦ DDR3L 4GB/2.5" HDD bracket
- ♦ IP65 compliant front panel
- ♦ Mounting support: panel/wall/stand/VESA 100mm x 100mm
- ♦ Wide range power input 12V~30VDC

## Product Overview

The 15" fanless panel PC APPC 1540T incorporating an industrial motherboard is intended for versatile industrial applications. The panel PC has a touch screen LED backlight LCD panel with 1024 x 768 (XGA) resolution and 400-nit brightness. The front panel which adopts flush design and complies with IP65 standard makes it the perfect fit in industrial applications.

The APPC 1540T supports WWAN/WLAN expansion and others via dual Gigabit Ethernet connectors, two mini-PCIe slots and one SIM card holder. With support for wide power input of 12~30VDC, APPC 1540T can gain a strong foothold in industrial field and machine devices. In addition, APPC 1540T can hook 2nd display via a VGA port for dual independent display. APPC 1540T has two isolated RS232/422/485 ports.

## Specifications

### Panel

- ♦ LCD size: 15", 4:3
- ♦ Resolution: XGA 1024 x 768
- ♦ Luminance: 400cd/m<sup>2</sup>
- ♦ Contrast ratio: 2500
- ♦ LCD color: 16.7M
- ♦ Viewing angle: 88 (U), 88 (D), 88 (L), 88 (R)
- ♦ Backlight: LED

### Touch Screen

- ♦ 5-Wire resistive (flush panel type)
- ♦ Light transmission: 81%
- ♦ Interface: USB

### System

- ♦ CPU: on-board Intel® Celeron® Quad Core processor J1900, up to 2.0GHz, 2M L2 cache
- ♦ BIOS: AMI BIOS
- ♦ System memory: 2 x 204-pin DDR3L SO-DIMM socket, 4GB DDR3L (default), support up to 8GB DDR3L-1066/1333, non-ECC and un-buffered
- ♦ Storage device
  - 1 x External locked CFast socket
  - 1 x Hard drive bay: optional 1 x 2.5" SATA HDD or 1 x SATA DOM

- ♦ Watchdog timer: Watchdog timeout can be programmable by software from 1 second to 255 seconds and from 1 minute to 255 minutes (tolerance 15% under room temperature 25°C)
- ♦ H/W status monitor: monitoring system temperature, and voltage
- ♦ Expansion: 2 x mini-PCIe sockets (support optional Wi-Fi, 3.5G module)

### Rear I/O

- ♦ Ethernet: 2 x RJ45
- ♦ 2nd display VGA port: 1 x DB15
- ♦ Audio port: 1 x Line-out
- ♦ USB: 2 x USB 2.0, 1 x USB 3.0
- ♦ Power switch
- ♦ Reset button
- ♦ 2-Pin remote power on/off switch
- ♦ COM #1: RS232/422/485 w/2.5kv isolated
- ♦ COM #2: RS232/422/485 w/2.5kv isolated


### Audio

- ♦ HD audio codec: realtek ALC886-GR
- ♦ Audio interface: Line-out

### Ethernet

- ♦ LAN chip: dual Intel® I210-AT Gigabit LAN
- ♦ Ethernet interface: 10/100/1000 Base-Tx Ethernet compatible

## Dimension Drawing

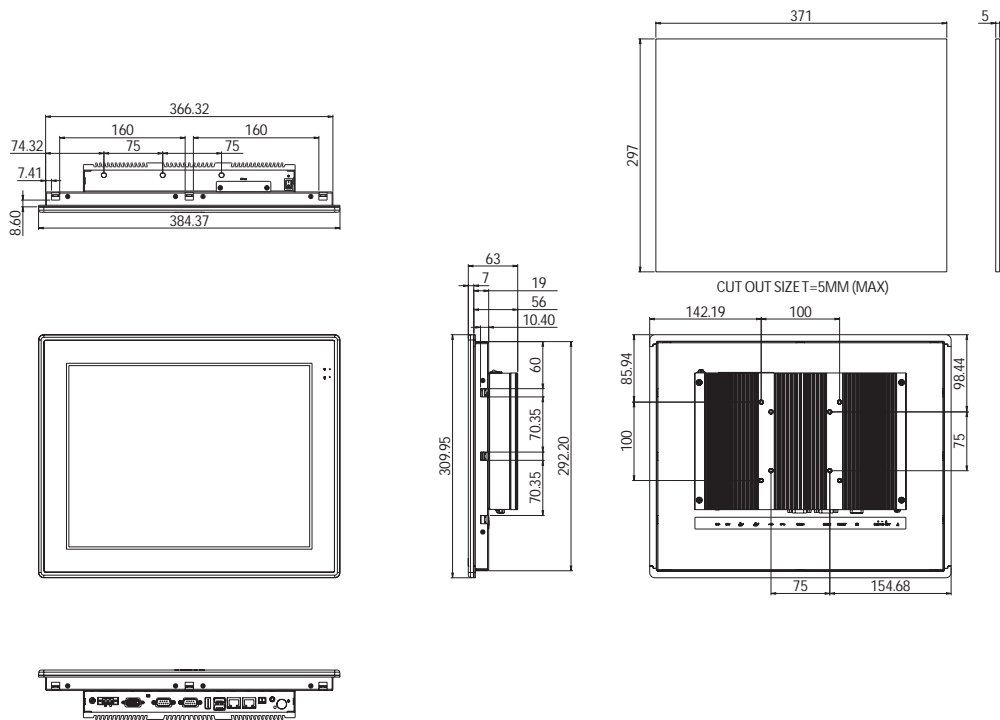

### Mechanical & Environment

- ♦ Color: Pantone black\RAL 15 00 front bezel w/ Pantone 400C\RAL 090 80 10 metal style membrane and black silver PC box
- ♦ IP protection: IP65 front
- ♦ Mounting: panel/wall/stand/VESA 100mm x 100mm
- ♦ Power
  - Power input: 12V~30VDC
  - Power adapter: optional AC to DC power adapter (+12V, 60W)
- ♦ Vibration
  - IEC 68 2-64 (w/HDD)
  - 1Grms @ sine, 5~500Hz, 1hr/axis (HDD operating)
  - 2Grms @ sine, 5~500Hz, 1hr/axis (CFast operating)
  - 2.2Grms @ random condition, 5~500Hz, 0.5hr/axis (non-operating)
- ♦ Shock
  - IEC 68 2-27
  - HDD: 20G@wall mount, half sine, 11ms
- ♦ Temperature
  - Operating temperature: -5°C~60°C
  - Storage temperature: -20°C~75°C
- ♦ Operating humidity: 10%~90% relative humidity, non-condensing limits to be at 90% RH at max 50°C
- ♦ Dimension: 384.37 x 309.95 x 63 mm
- ♦ Weight: 4.7 kg

### Certifications

- ♦ CE approval
- ♦ FCC Class A

### OS Support Lists

- ♦ Windows 10 64-bit
- ♦ Windows 8 32-bit/64-bit
- ♦ Windows 7 32-bit/64-bit
- ♦ WinCE 7.0

## Ordering Information

### Barebone

- ♦ **APPC 1540T-C (P/N: 101A1540T15X0)**  
15" XGA LED backlight touch panel PC, Intel® Celeron® J1900 up to 2.0GHz, touch screen, 4GB DDR3L, 2 x RS232/422/485

### Options

- ♦ **12V, 60W AC/DC power adapter w/o power cord (P/N: 7400060031X00)**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Nexcom:](#)

[10IA1540T15X0](#)