

SPECIFICATIONS

Physical Resolution: 800x600

Supported Resolution: 640x480 - 1920x1080

Brightness: 400 cd/m²

Contrast Ratio: 500:1

Viewing Angle: 140° Horizontal, 120° Vertical

Response Time (Tr/Tf): 10/15ms (Typ.)

Operating Voltage: DC 9V ~ 36V

Power Consumption: <14W


Operating Temp: -4°F ~ 158°F

Storage Temp: -22°F ~ 176°F

Weight: 1.81lbs

24 Month Warranty

All measurements are in [mm]

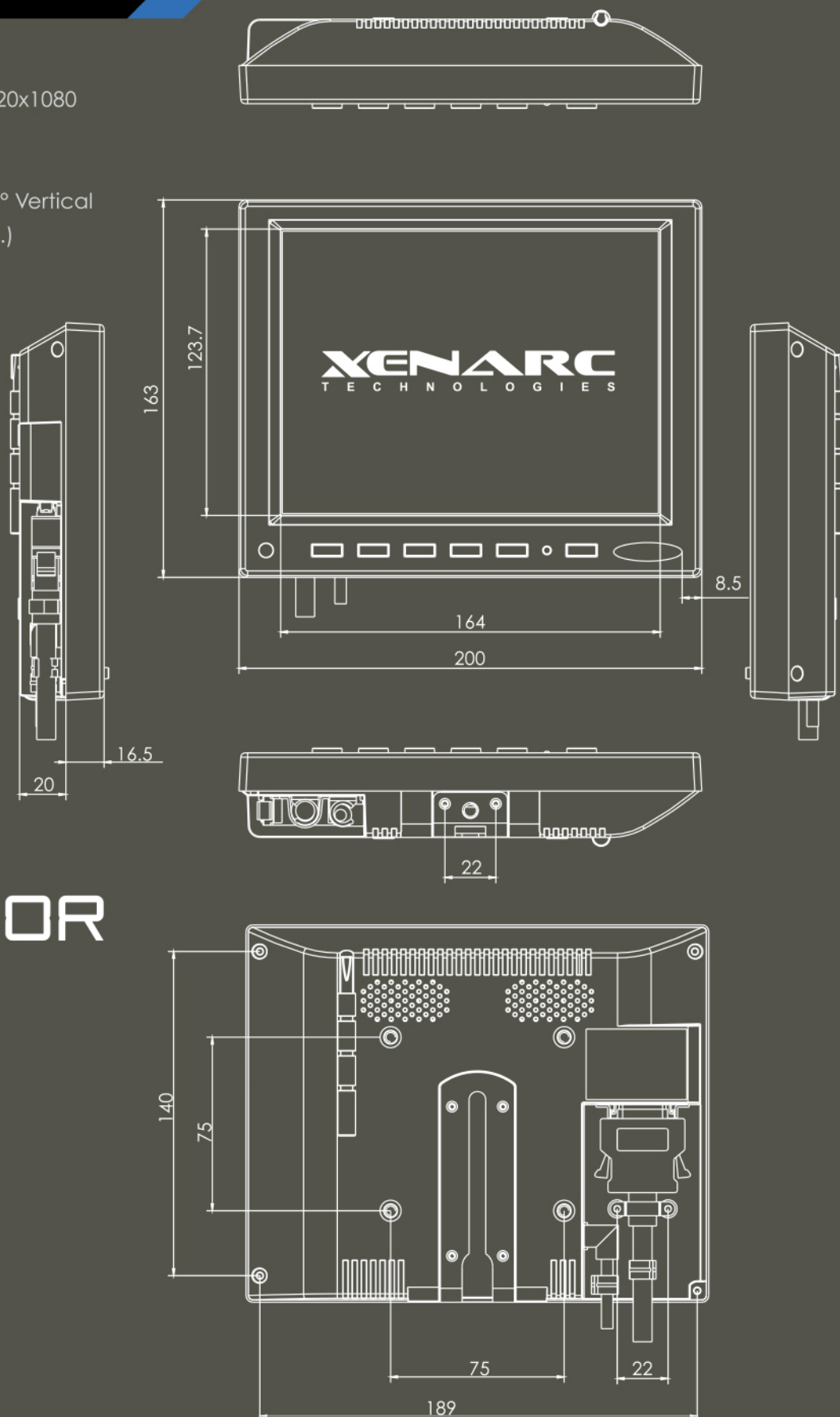

ENTRY LEVEL

8" MONITOR

CERTIFICATIONS



RoHS



TEL: 949.380.8898 FAX: 949.380.0888

EMAIL: SALES@XENARC.COM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Xenarc:](#)

[805TSV](#)