


PICO-APL3-A10-FAI1 PRELIMINARY

AI Edge Computing Kit with Kneron KL520 NPU

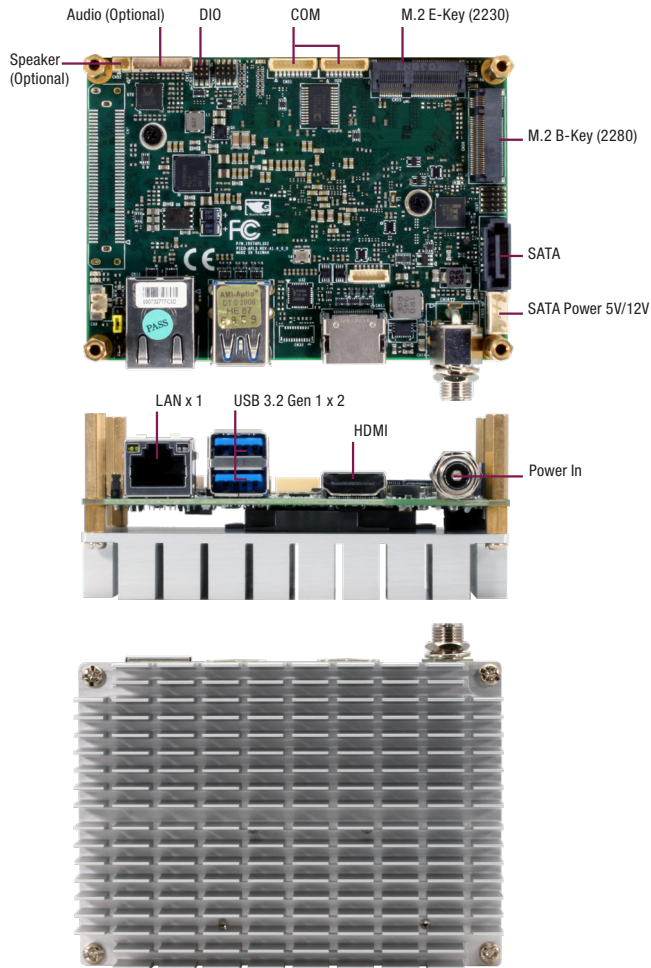

M2AI-2280-520



EverFocus Full HD Camera EUA1200



Features

- Intel® Pentium® N4200 Processor SoC
- Onboard Storage eMMC 32GB
- Onboard DDR3L 4GB
- Single Gigabit Ethernet Support
- HDMI 1.4b for Display
- USB 3.2 Gen 1 x 2, USB 2.0 x 2, SATA 6.0Gb/s x 1
- M.2 B Key (2280) x 1, M.2 E Key (2230) x 1
- M2AI-2280-520 x 1
- EverFocus Full HD Camera EUA1200 x 1



Specifications

System	
Form Factor	Pico-ITX
CPU	Intel® Atom™ Processor SoC
CPU Frequency	Up to 2.4 GHz
Chipset	Intel® Atom™ Processor SoC
Memory Type	Onboard DDR3L 4GB
Max. Memory Capacity	4GB
BIOS	AMI/SPI
Wake On LAN	Yes
Watchdog Timer	255 Levels
Power Requirement	+12V, AT/ATX
Power Supply Type	Lockable
Power Consumption (Typical)	Intel® N4200 processor, DDR3L 4GB, 1.1A@12V
System Cooling	Heatsink
Dimension	3.94" x 2.84" (100 mm x 72 mm)
Gross Weight	0.55 lb (0.25 kg)
Operating Temperature	32°F ~ 140°F (0°C ~ 60°C)
Storage Temperature	-40°F ~ 176°F (-40°C ~ 80°C)
Operating Humidity	0% ~ 90% relative humidity, non-condensing
MTBF (Hours)	110,000
Certification	CE, FCC
Display	
Chipset	Intel® Atom™ Processor SoC
Resolution	HDMI 1.4b: 3840 x 2160@30Hz
LCD Interface	—
I/O	
Storage/SSD	SATA 6.0Gb/s x 1, 5V/12V Power reserved M.2 2280 (B Key) x 1 eMMC 32GB
Ethernet	Realtek 8111G x 1
USB Port	USB 3.2 Gen 1 x 2 Rear IO USB 2.0 x 2 (Internal, co-use with FAN connector)
Serial Port	COM1: RS-232
Audio	—
DIO	4-bit
Expansion Slot	M.2 2230 x 1 (E-Key) I2C, Smbus
SIM	—
TPM	—
Touch	—

Packing List

- PICO-APL3
- M2AI-2280-520
- EverFocus Full HD Camera EUA1200

Ordering Information

Part Number	CPU	Memory	Thermal	Display	Storage	LAN	USB	RS-232	RS-232/ 422/485	Expansion Slot	Power	Temp.	Others
PICO-APL3-A10-FAI1	Celeron® N4200 (Quad Core)	Onboard DDR3L 4GB	w/ Heatsink	HDMI x 1	SATA 3.0 x 1 M.2 2280 (B Key) x 1 eMMC 32GB	GbE x 1	USB 3.2 Gen 1 x 2 (Rear) USB 2.0 x 2 (Internal)	1	—	M.2 2230 (E Key) x 1	+12V (DC Jack)	0°C ~ 60°C	DIO 4 bit

Optional Accessories

Part Number	Description	Qty
1709070500	(TF) SATA Cable, 50cm	1
1702150155	(TF) SATA Power Cable, 15cm	1
1700040151	(TF) USB Cable, 15cm	2
1701090122	(TF) Flat Cable, D-Sub 9P(M), 9P 1.0mm Housing, 12cm	1
125530040C	(TF) Power Adapter. 12V.40W.FSP.FSP040-DHAN3	1
1702031802	Power Cord (US Type)	1
1702031803	Power Cord (European Type)	1
170203180E	Power Cord (Japan Type)	1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kneron:](#)

[PICO-APL3-FAI1](#)