



## Delta 43

450MHz 205mm LENGTH OMNI SWIVEL ANTENNA



### Key Features

- 2.5dBi Peak Gain
- Simple Direct Attach Antenna
- Swivel Knuckle Design

### General Description

The Delta 43 direct connect 450MHz ISM band antenna exhibits good peak gain for its size.

The knuckle joint allows the antenna to rotate and be positioned to obtain the best signal in the mounting location.

Typical applications are Terminals and Smart Water Meters that can be read from a remote handheld device.

### Additional Considerations

- Suitable with a wide variety of manufacturers equipment
- Meets all EU compliance criteria for electronic goods





## Delta 43

450MHz 205mm LENGTH OMNI SWIVEL ANTENNA


### Electrical Specifications

Operating temperature:	-20 - +65°C
Impedance:	50 Ohm
Peak Gain:	2.5dBi
VSWR:	≤1.5:1
Frequency Range:	400~480MHz
Radiation:	Omni
Polarization:	Vertical
Max Input Power:	50W

### Mechanical Specifications

Dimensions:	L205mm
Weight:	40g
Connector:	SMA
Mounting Method:	Direct connect

### VSWR

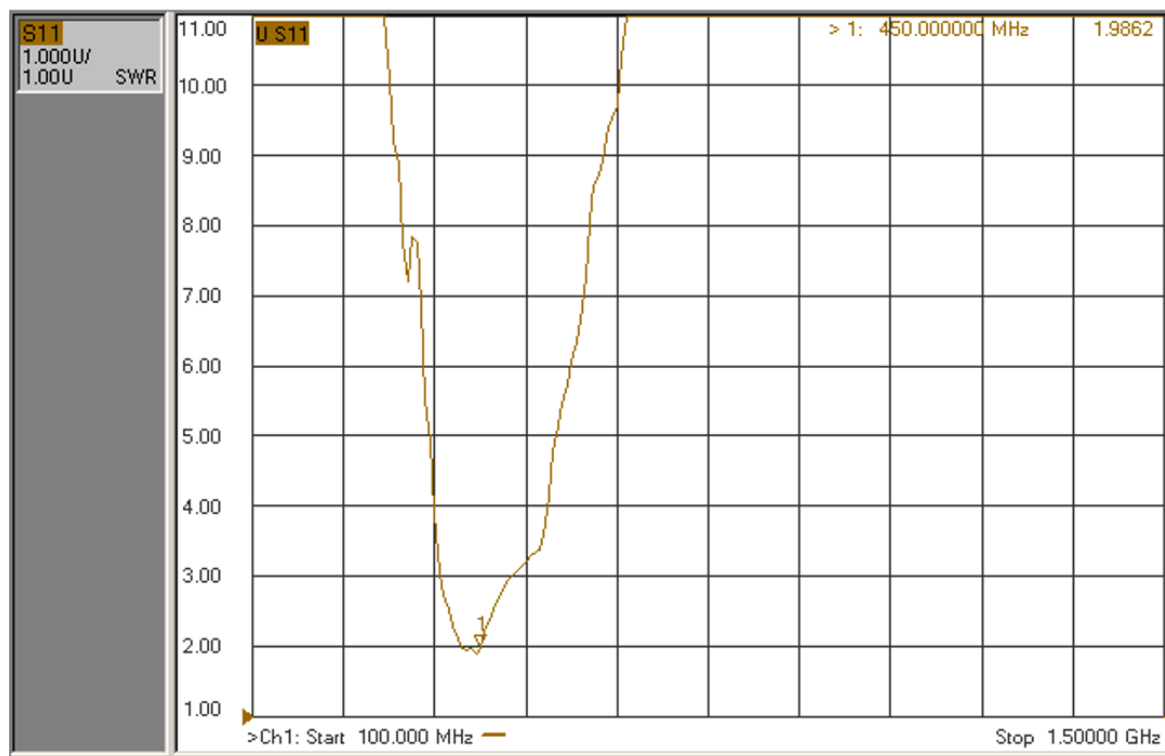





## Delta 43

450MHz 205mm LENGTH OMNI SWIVEL ANTENNA

### Return Loss

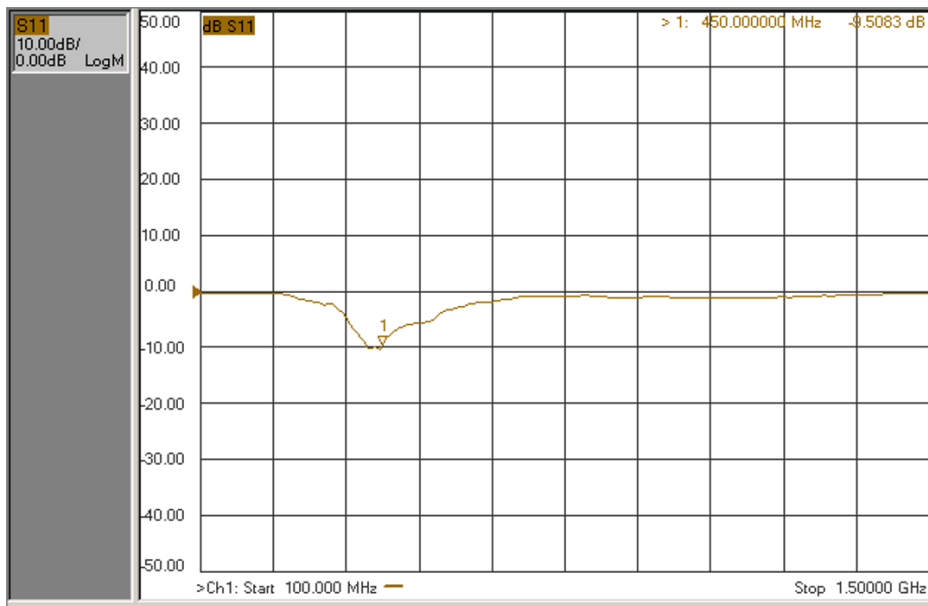

### Efficiency

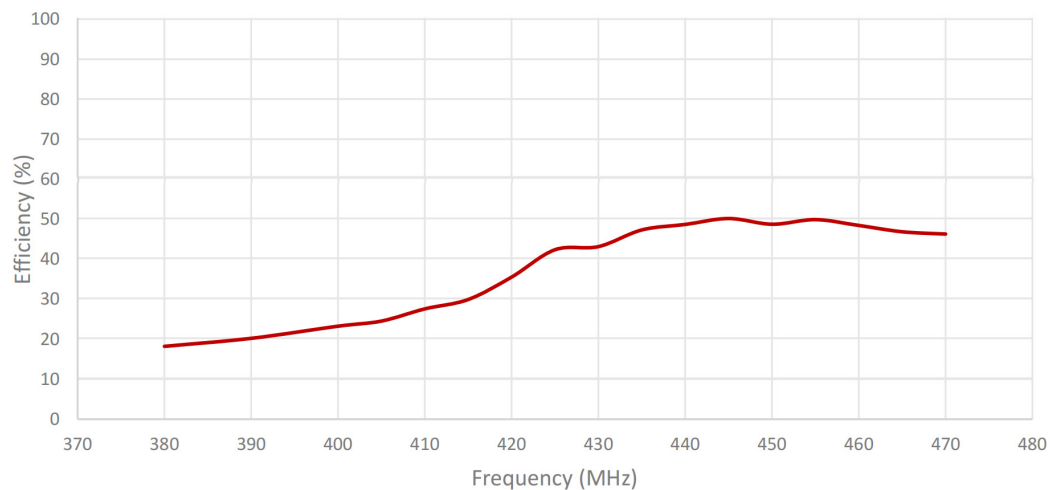

### Ordering Details

Part number	Description
DELTA43/x/SMAM/S/S/17	450MHz 205mm LENGTH OMNI SWIVEL ANTENNA SMA MALE CONNECTOR

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siretta:](#)

[DELTA43/X/SMAM/S/S/17](#)