




G2G085 Series
Centrifugal


Single inlet centrifugal blower with brushless DC motor mounted inside the scroll housing for better performance and compact form/fit

Part Number	CFM @ 0	Curve	Volts	Voltage Range	Watts	dBA	Temp. Max C	Wgt. (oz)	Type Of Bearing	Features	Insul. Class
G2G085-AB02-01	47	1	24	16 to 28	13	53	60	32	Ball	Flange	R
G2G085-AB04-10	47	1	12	8 to 14	10	52	65	32	Ball	Flange	R

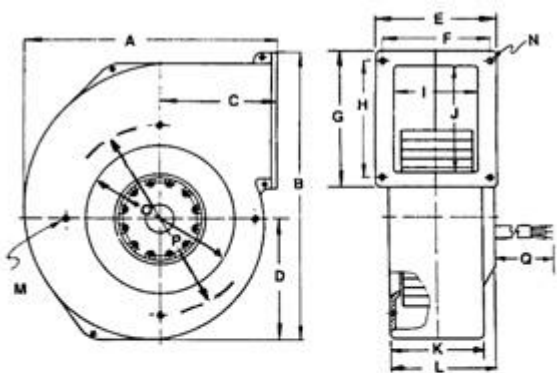

DIMENSIONS - inches (mm)

PART NUMBER	A	B	C	D	E	F	G	H	I	J	K	L	M	N	O	P	Q
G2G085	4.61 (117)	5.00 (127)	2.36 (60)	2.22 (56)	2.99 (76)	2.60 (66)	2.68 (68)	2.28 (58)	2.20 (56)	1.65 (42)	2.36 (60)	3.15 (80)	M4	.22 (5.5)	2.56 (65)	3.31 (84)	11.81 (300)

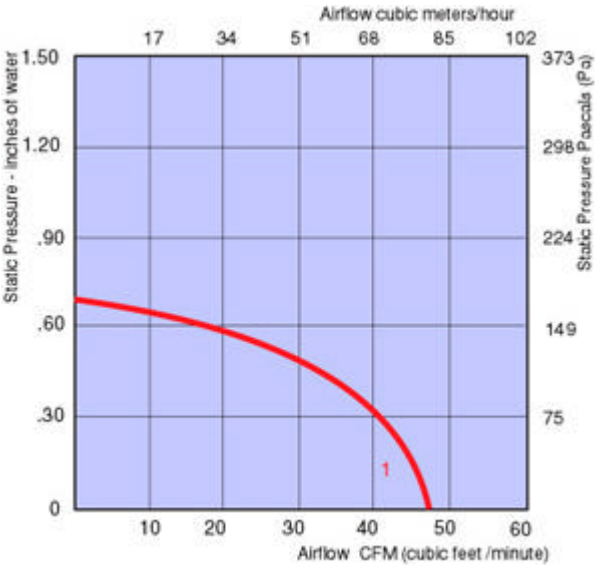

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ebm-papst:](#)

[G2G085-AB04-10](#)