


ECS-MPIL0530

SMD Power Inductor



1.Mechanical Dimension [Unit : mm]

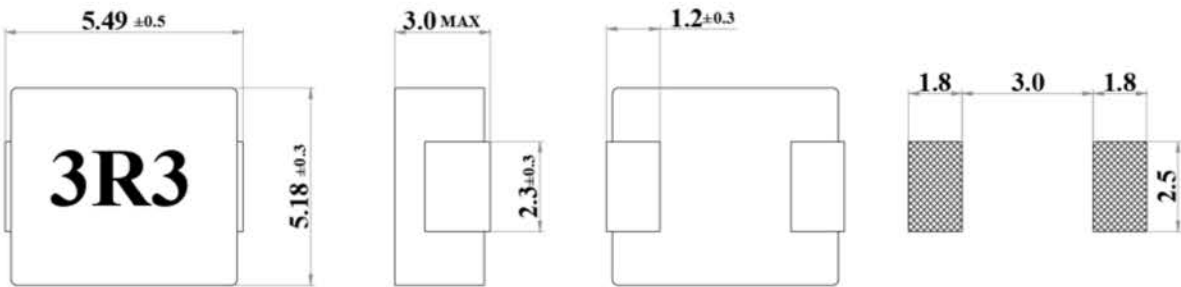

2. Electrical Characteristics



ECS-MPIL0530 Series

Part No.	Inductance (uH ±20%)	DC Resistance (mΩ MAX)	DC Resistance (mΩ TYP.)	Rated Current (A MAX)	Heat Rating Current DC(A)
ECS-MPIL0530-R68MC	0.68	12	11	14.0	8.5
ECS-MPIL0530-1R0MC	1.0	14	13	11.0	7.0
ECS-MPIL0530-1R5MC	1.5	25	20	10.0	6.0
ECS-MPIL0530-2R2MC	2.2	35	29	9.0	5.5
ECS-MPIL0530-3R3MC	3.3	38	32	7.0	5.0
ECS-MPIL0530-4R7MC	4.7	60	50	5.0	3.0
ECS-MPIL0530-220MC	22	324	270	3.0	2.0



Measuring Frequency (L) : 100KHz/0.1V

Rated Current: D.C. Current at which the Inductance drops 30%(MAX.) from its value without current



ECS-MPIL0530-R68MC

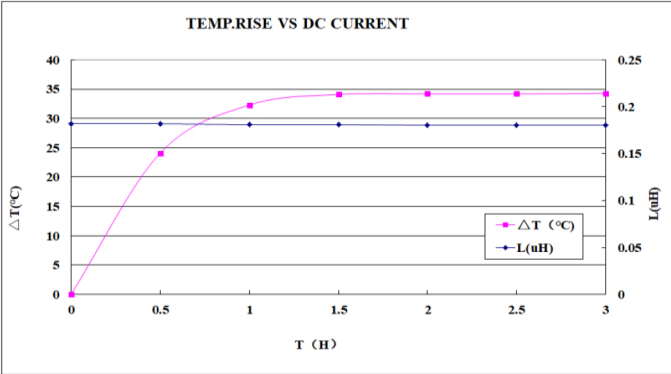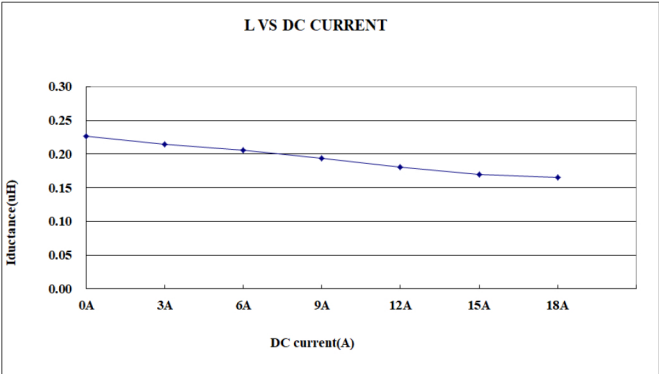



ECS-MPIL0530-1R0MC

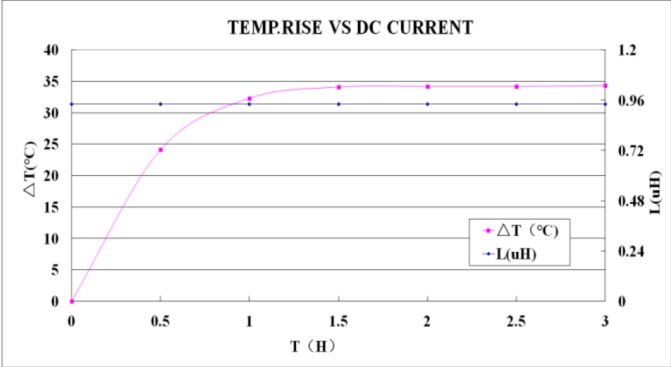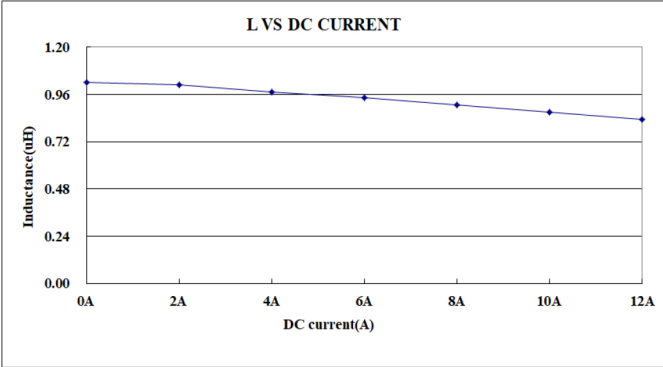



ECS-MPIL0530-1R5MC

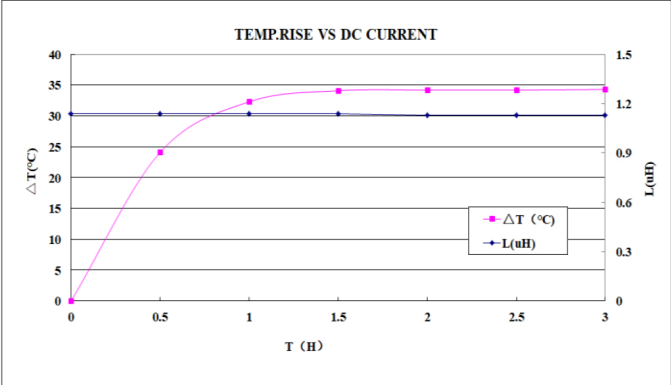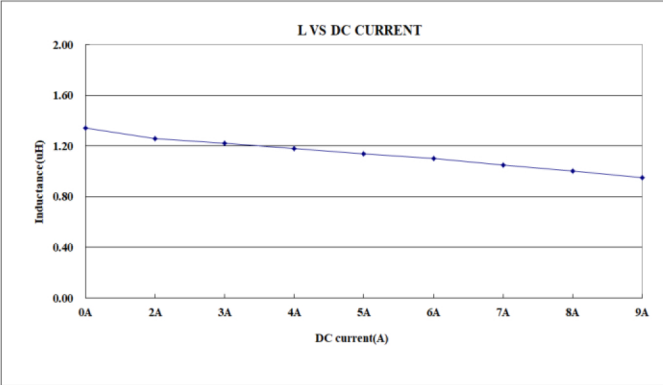



ECS-MPIL0530-2R2MC

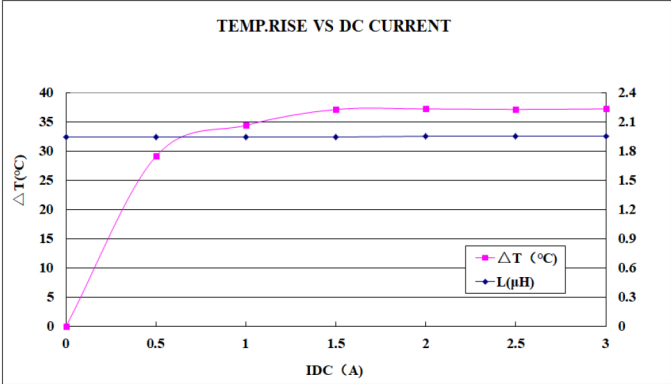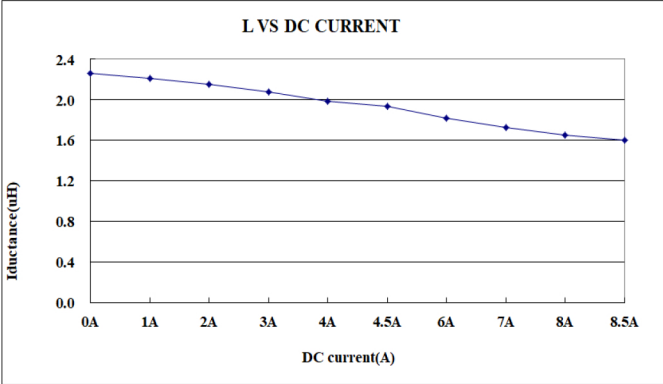



ECS-MPIL0530-3R3MC

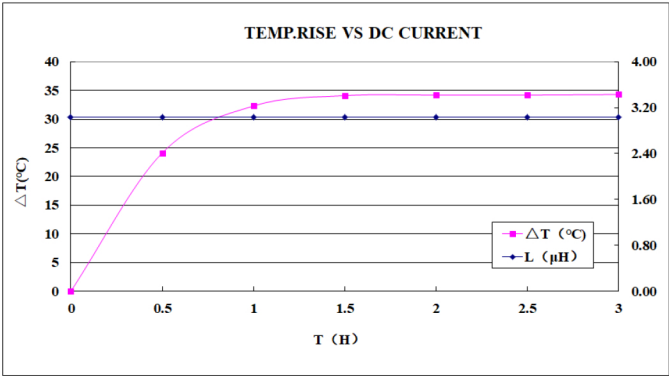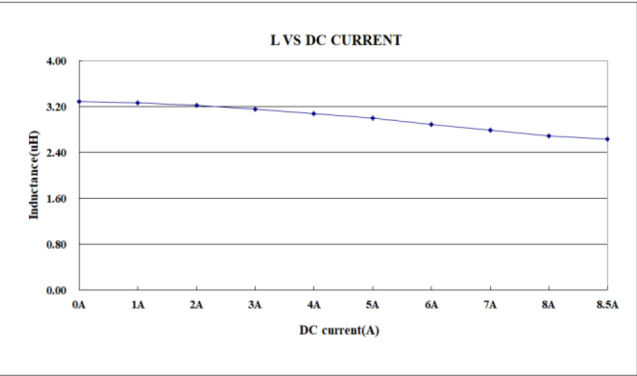



ECS-MPIL0530-4R7MC

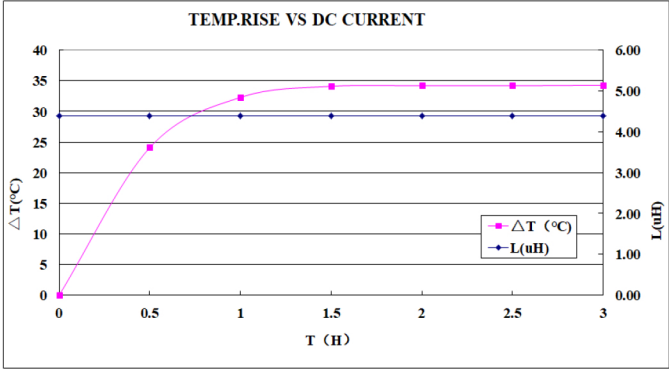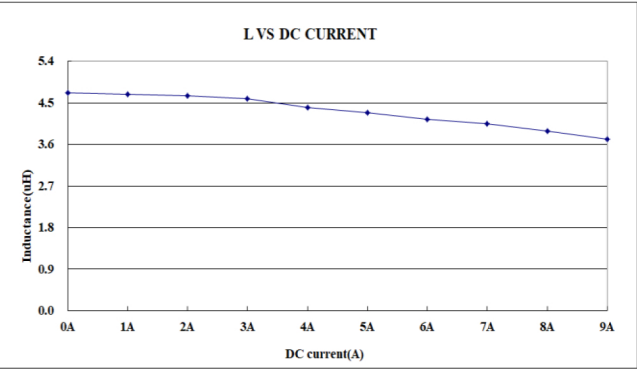

ECS-MPIL0530-6R8MC

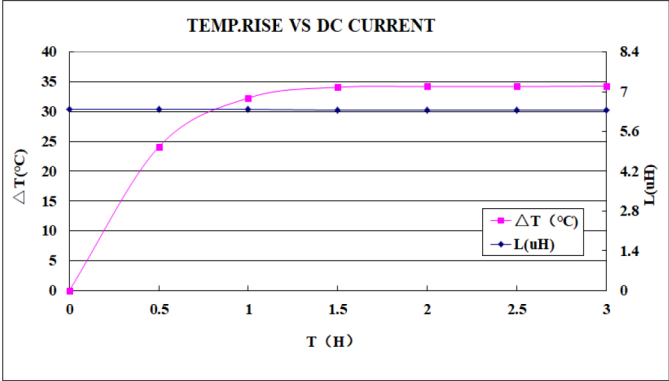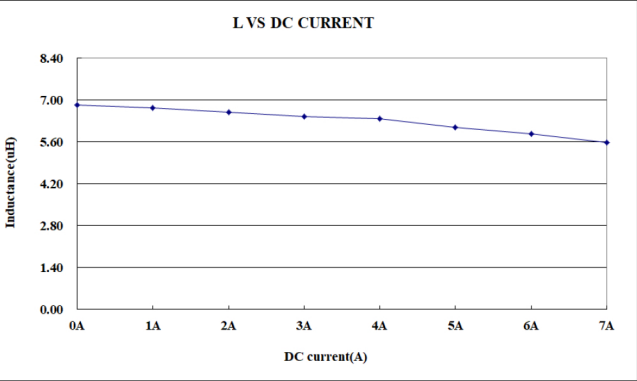

ECS-MPIL0530-220MC

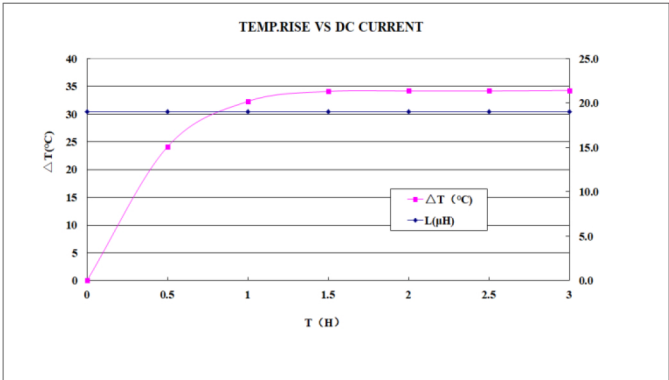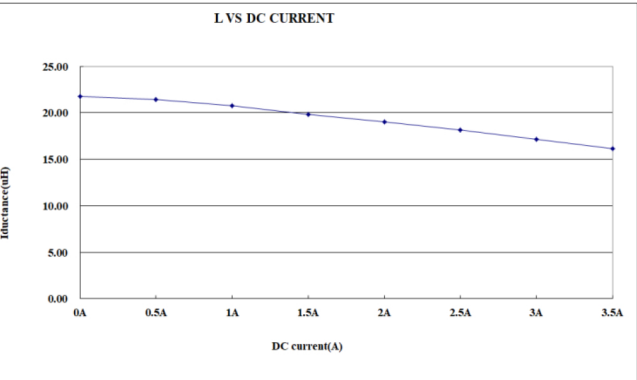

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

ECS:

[ECS-MPIL0630-150MC](#) [ECS-MPIL0530-2R2MC](#) [ECS-MPIL0630-R68MC](#) [ECS-MPIL0630-5R6MC](#) [ECS-MPIL0630-3R3MC](#) [ECS-MPIL0630-R47MC](#) [ECS-MPIL0530-5R6MC](#) [ECS-MPIL0530-1R5MC](#) [ECS-MPIL0630-R56MC](#) [ECS-MPIL0630-6R8MC](#) [ECS-MPIL0630-1R0MC](#) [ECS-MPIL0630-220MC](#) [ECS-MPIL0630-100MC](#) [ECS-MPIL0530-4R7MC](#) [ECS-MPIL0530-3R3MC](#) [ECS-MPIL0630-1R5MC](#) [ECS-MPIL0630-2R2MC](#) [ECS-MPIL0630-4R7MC](#) [ECS-MPIL0630-R82MC](#)