

The ultra-miniature ECX-12L is a very compact SMD Tuning Fork Crystal. The 2.0 x 1.2 x 0.38 mm **low profile** ceramic package is ideal for smart cards, mobile devices, and industrial applications.

## ECX-12L

32.768 KHz  
SMD Tuning Fork Crystal

Request a Sample

### ECX-12L SMD CRYSTAL



- Low Profile 0.38 mm H
- 2.0 x 1.2 mm Footprint
- Low Power RTC Applications such as STM32 [AN2867](#)
- RoHS Compliant
- Applications: Automotive, COTS, Industrial, IOT

### DIMENSIONS (mm)


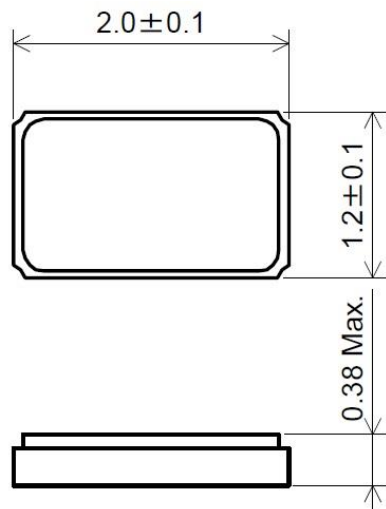


Figure 1) Top, Side, and Bottom views

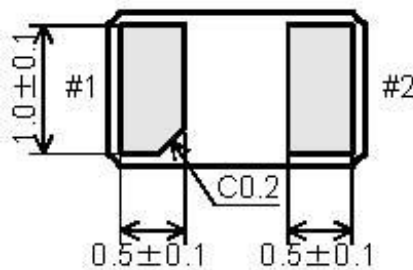

#### PAD CONNECTIONS

1	In/Out
2	Out/In

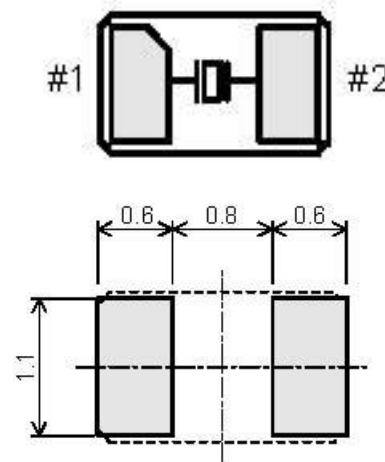


Figure 2) Suggested Land Pattern

### OPERATING CONDITIONS / ELECTRICAL CHARACTERISTICS

PARAMETERS	CONDITIONS	ECX-12L			UNITS
		MIN	TYP	MAX	
Frequency			32.768		KHz
Frequency Tolerance	@ +25°C			± 20 *	ppm
Load Capacitance	Specify in P/N		12.5		pF
Drive Level	DL		0.1	0.5	μW
Equivalent Series Resistance	R1			100K	Ω
Motional Capacitance			7.0		fF
Turnover Temperature		+20	+25	+30	°C
Temperature Coefficient		-0.02	-0.03	-0.040	ppm/°C²
Shunt Capacitance	Co		1.3		pF
Aging (First Year)	@ +25°C ±3°C			±3	ppm
Operating Temperature	Topr	-40		+85	°C
Storage Temperature	Tstg	-55		+125	°C


### PART NUMBERING GUIDE: Example ECS-.327-12.5-12L-TR

ECS - FREQUENCY ABBREVIATION		LOAD CAPACITANCE	PACKAGE	CUSTOM OPTIONS Tolerance	PACKAGING
ECS	.327 = 32.768 KHz	12.5 = 12.5 pF 9 = 9 pF 7 = 7 pF 6 = 6 pF	-12L = ECX-12L	Blank = ±20 ppm * C = ± 10 ppm	TR = Tape & Reel 5K/Reel

\*Contact ECS for availability

Rev.2022

## POCKET TAPE DIMENSIONS (mm)

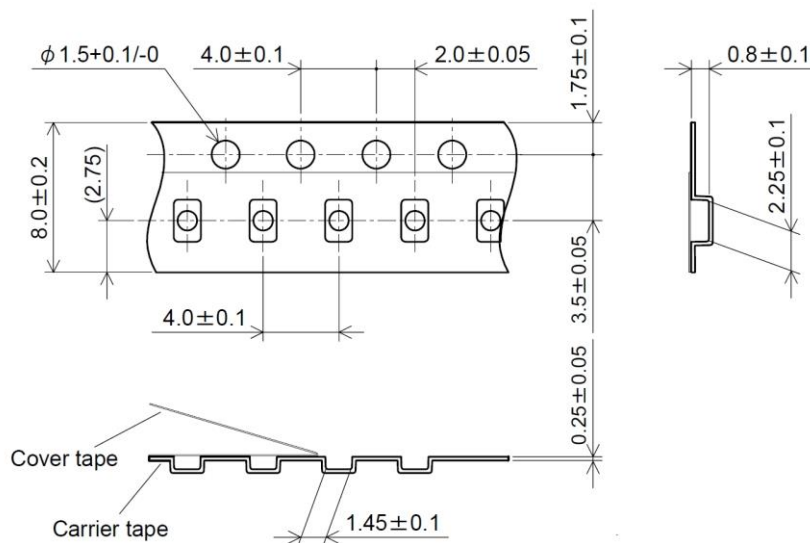

### SOLDER PROFILE

Peak solder Temp  $+260^{\circ}\text{C}$  Max 10 sec Max.

2 Cycles Max.

MSL 1, Lead Finish Au

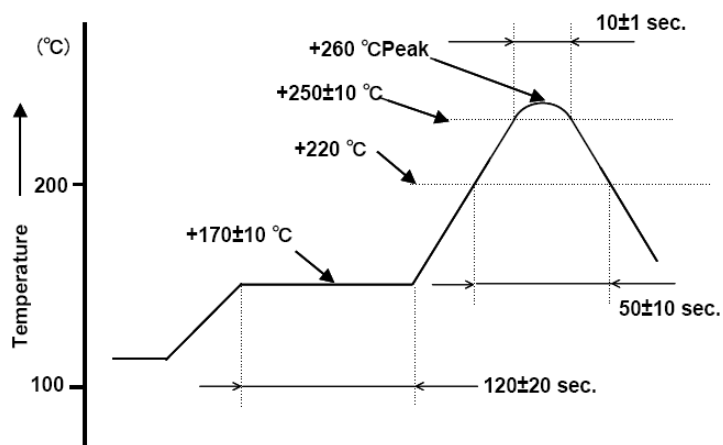


Figure 1) Suggested Reflow Profile

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

ECS:

[ECS-.327-12.5-12L](#) [ECS-.327-12.5-12L](#)