


## Ordering Information


(For generic switches fill out matrix below. For application specific switches see page 15.)

If you don't see the switch you need, please consult the factory.

### Assemblage 2

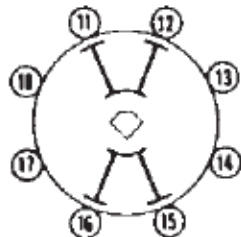

### Assemblage 3

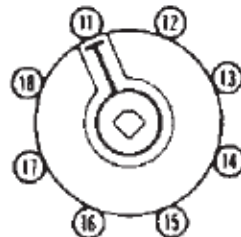

**Note 1:** Nominal torques, weights, and depth behind panel are listed below.

**Note 2:** Assemblages are shown with handle in 0° position (12 o'clock).

Model No. **24** ☐ ☐ ☐ ☐ ☐ ☐

Series \_\_\_\_\_

Assemblage \_\_\_\_\_

2 = Assemblage 2

3 = Assemblage 3

Handle Type \_\_\_\_\_

B = Oval Shank

C = Round Knurled

D = Pistol Grip

E = Removable Oval

Shorting \_\_\_\_\_

Blank = No

S = Yes

Matrix Code	No. of Sections	Weight (lbs.)	Torque (lb./in)	Depth Behind Panel
01 =	1	1.1	8	2.41
02 =	2	1.2	9	2.78
03 =	3	1.3	10	3.53
04 =	4	1.4	11	4.28
05 =	5	1.5	12	4.66
06 =	6	1.6	13	5.41
07 =	7	1.7	14	6.16
08 =	8	1.8	15	6.53
09 =	9	1.9	16	7.41
10 =	10	2.0	17	8.03

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Electroswitch:](#)

[24201B](#)