
 

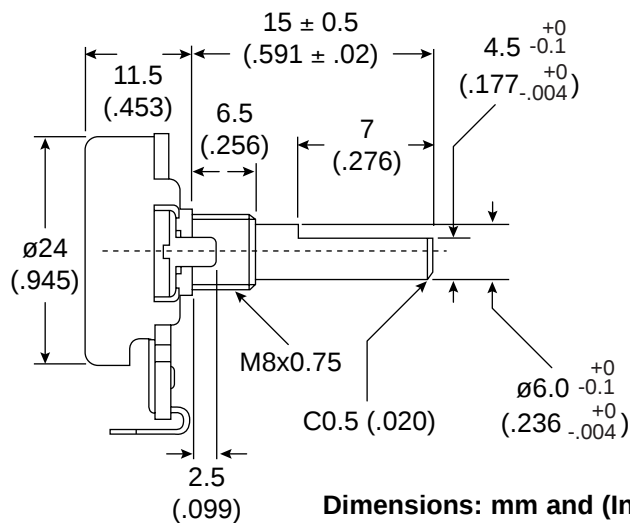




Washer 2 PCS.

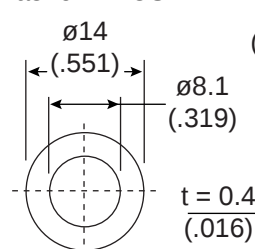



Nut 1 PCS

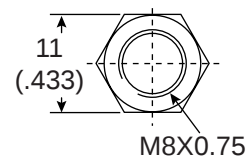

Audio Taper	Linear Taper
313-2440 - 1K	313-2441 - 500
313-2440 - 5K	313-2441 - 1K
313-2440 - 10K	313-2441 - 5K
313-2440 - 50K	313-2441 - 10K
313-2440 - 100K	313-2441 - 25K
313-2440 - 500K	313-2441 - 50K
313-2440 - 1M	313-2441 - 100K
	313-2441 - 250K
	313-2441 - 500K
	313-2441 - 1M
	313-2441 - 2M
	313-2441 - 5M

Electrical Specification:

- Rated wattage: .5W
- Maximum working voltage: 500V
- Slide noise: less than 47 mV
- Insulation resistance: more than 100MΩ
- Withstand voltage: 500VAC for 1 minute
- Temperature range: from -10°C to +70°C
- VR life: 15,000 cycles

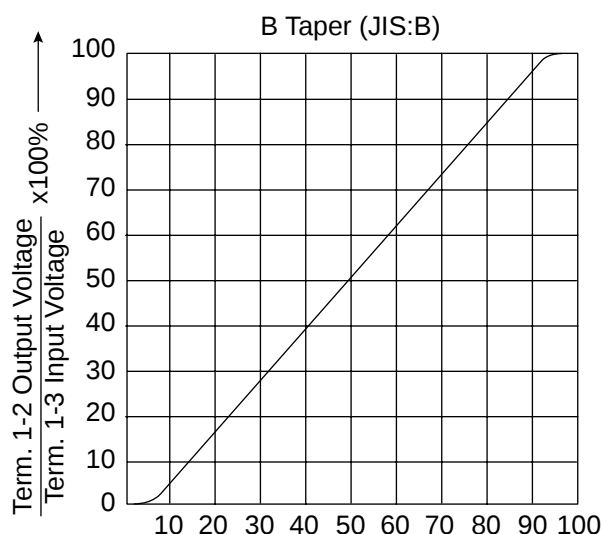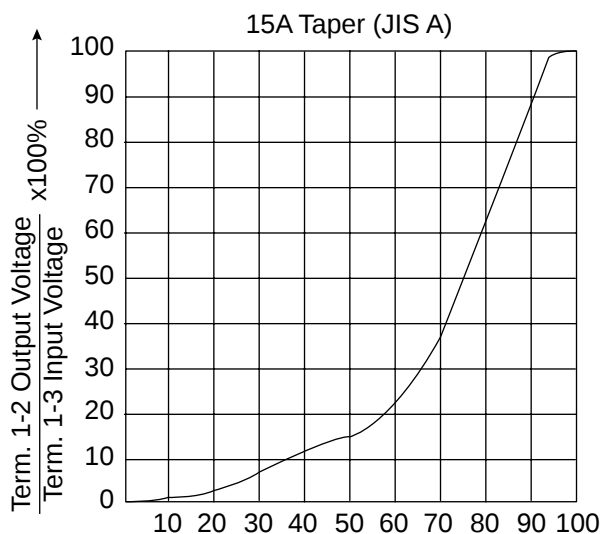

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Alpha (Taiwan):

[RV24A-10-15F-A10K](#) [RV24A-10-15F-B50K](#) [RV24A-10-15F-A1M](#) [RV24A-10-15F-A100K](#) [RV24A-10-15F-B10K](#)
[RV24A-10-15F-B1M](#) [RV24A-10-15F-B250K](#) [RV24A-10-15F-A50K](#) [RV24A-10-15F-B100K](#) [RV24A-10-15F-A1K](#)
[RV24A-10-15F-B2M](#) [RV24A-10-15F-B25K](#) [RV24A-10-15F-A500K](#) [RV24A-10-15F-B500](#) [RV24A-10-15F-B5K](#) [RV24A-10-15F-B5M](#) [RV24A-10-15F-B500K](#) [RV24A-10-15F-B1K](#)