




Rotary Switches

10WW017, 10WW019,
10WW025, 10WW026,
10WW033, 10WW034,
10WW042, 10WW043,
10WW062, 10WW112

Dimensions: mm (in)

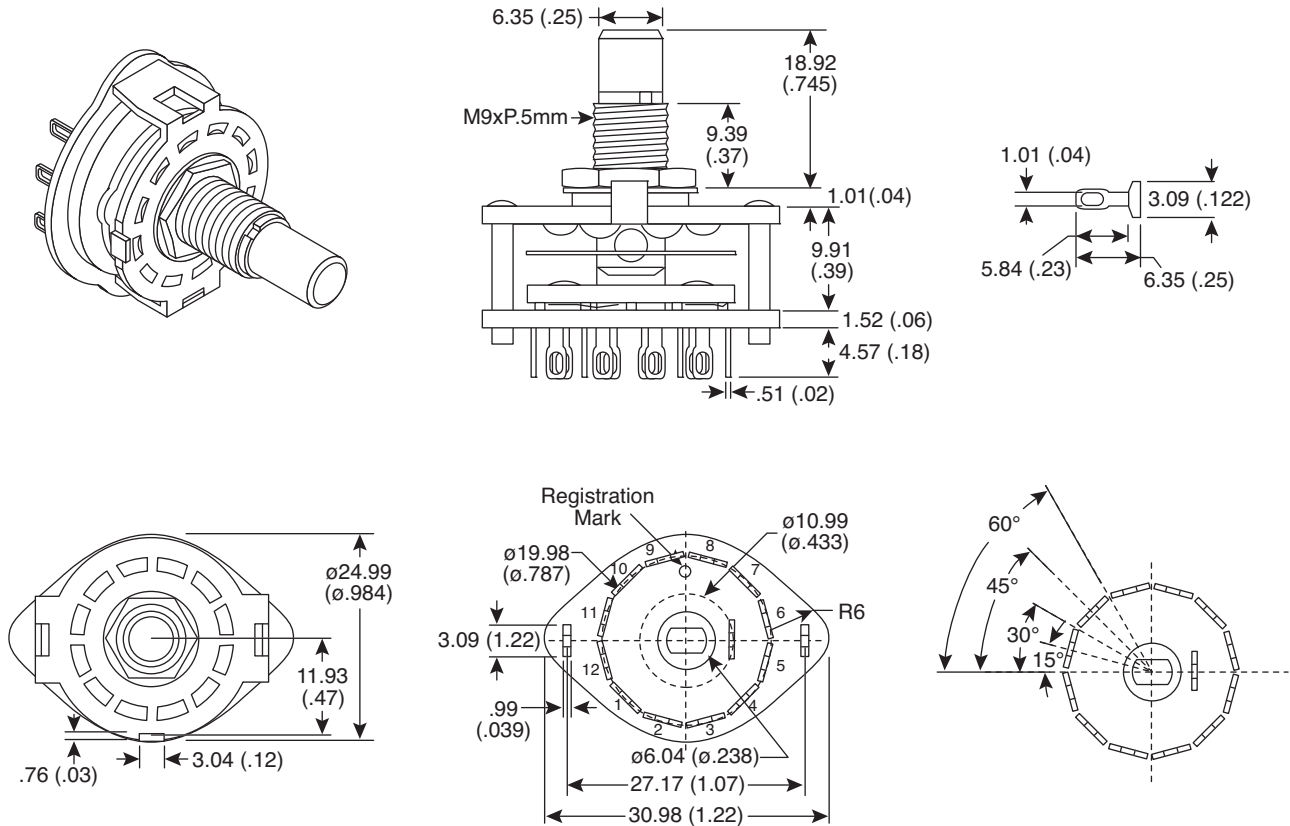

Electrical Specifications:

- Rating: 0.3A 125VAC
- Contact Resistance: 30mΩ max. @ 1A
- Insulation Resistance: 10MΩ @ 500VDC min.
- Dielectric Strength: 500VAC for 1 min.

Mechanical Specifications:

- Type: Shorting contact (make before break)
- Rotation Torque: 1~3KG/cm

Materials:

- Hardware Included: 1 hexagon nut & 2 washers
- Shaft: 1/4"

Mouser Stock No.	Poles	Position
10WW017	1	7
10WW019	1	9
10WW025	2	5
10WW026	2	6
10WW033	3	3
10WW034	3	4
10WW042	4	2
10WW043	4	3
10WW062	6	2
10WW112	1	12

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Alpha \(Taiwan\):](#)

[SR2511-0303-19R0B-E9-S-W](#) [SR2511-0403-19R0B-E9-S-W](#) [SR2511-0112-19R0B-E9-S-W](#) [SR2511-0206-19R0B-E9-S-W](#) [SR2511-0205-19R0B-E9-S-W](#) [SR2511-0304-19R0B-E9-S-W](#) [SR2511-0107-19R0B-E9-S-W](#) [SR2511-0602-19R0B-E9-S-W](#) [SR2511-0109-19R0B-E9-S-W](#) [SR2511-0402-19R0B-E9-S-W](#)