



kingston.com/ssd

XS2000 PORTABLE SSD

Portable pro-formance at your fingertips

Kingston's XS2000 Portable SSD utilizes USB 3.2 Gen 2x2 speeds to deliver next-gen performance in a compact, external drive. With lightning-fast transfer speeds up to 2,000MB/s¹, XS2000 delivers enhanced productivity with little interruption. XS2000 offers high-speed storage options up to 4TB² for offloading and editing high-res images, 8K videos, and large documents in a flash. The drive is future-proofed to keep up with storage demands and compatible with most devices out of the box. It connects with USB Type-C³ allowing content creators to access their data anywhere on a PC or mobile device. Whether you go between work, play and passion projects, the XS2000 includes a removable ruggedized sleeve and IP55-rating⁴ to withstand water and dust, making it the perfect companion for on-location photoshoots or adventures.

- › **Speeds up to 2,000MB/s¹ with USB 3.2 Gen 2x2**
- › **Capacities up to 4TB²**
- › **Compact, pocket-sized form factor**
- › **IP55 rating⁴ with removable rubber sleeve**

[more >>](#)

FEATURES / BENEFITS

USB 3.2 Gen 2x2 Performance — Industry-leading read/write speeds up to 2,000MB/s¹.

High-speed Capacities — Up to 4TB² to support high resolution images, 8K videos, and large documents.

Built for Durability — Tested to be water resistant, dust resistant⁴ and shockproof with an included rubber sleeve.

Pocket-sized Portability — Small, lightweight form factor for easy, on-the-go storage.

SPECIFICATIONS

Interface

USB 3.2 Gen 2x2

Speed¹

2,000MB/s read, 2,000MB/s write

Capacities²

500GB, 1TB, 2TB, 4TB

Dimensions

69.54 x 32.58 x 13.5mm

Weight

28.9g

Casing Material

Metal + Plastic

Operating temperature

0°C~40°C

Storage temperature


-20°C~85°C

Warranty/support⁵

Limited 5-year warranty with free technical support

Compatible with

Windows® 11, 10, 8.1, macOS (v. 10.14.x +), Linux (v. 2.6.x +), Chrome OS™

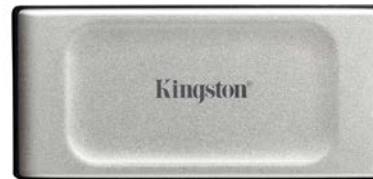

KINGSTON PART NUMBERS

XS2000 Portable SSD
SXS2000/500G
SXS2000/1000G
SXS2000/2000G
SXS2000/4000G

COMPATIBILITY TABLE

	USB 3.2 Gen 2x2
Windows® 11	✓
Windows® 10	✓
Windows® 8.1	✓
macOS (v. 10.14.x +)	✓
Linux (v. 2.6.x +)	✓
Chrome™ OS™	✓

1. Speed may vary due to host hardware, software and usage.

2. Some of the listed capacity on a flash storage device is used for formatting and other functions and thus is not available for data storage. As such, the actual available capacity for data storage is less than what is listed on the products. For more information, go to Kingston's Flash Memory Guide.

3. USB Type-C® and USB-C® are registered trademarks of USB Implementers Forum.

4. IEC/EN 60529 IP55 certified to withstand water flow and limited dust contact. Must be clean and dry before use.

5. Limited warranty based on 5 years or "SSD Life Remaining" which can be found using the Kingston SSD Manager. A new, unused product will show a wear indicator value of one hundred (100), whereas a product that has reached its endurance limit of program erase cycles will show a wear indicator value of one (1). See Kingston.com/wa for details.



THIS DOCUMENT SUBJECT TO CHANGE WITHOUT NOTICE.

©2022 Kingston Technology Corporation, 17600 Newhope Street, Fountain Valley, CA 92708 USA. All rights reserved.
All trademarks and registered trademarks are the property of their respective owners. MKD-439.1US

Kingston
TECHNOLOGY

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kingston:

[SXS2000/1000G](#) [SXS2000/2000G](#) [SXS2000/4000G](#) [SXS2000/500G](#)