



XS1000 EXTERNAL SSD

Pocket-sized file backup

Kingston's XS1000 external SSD is an incredibly convenient file backup solution. Its sleek, compact form factor is designed to fit seamlessly into your lifestyle, allowing you to carry it anywhere with ease. Don't let its size fool you – this tiny powerhouse boasts speeds of up to 1,050MB/s¹ and high capacities of up to 2TB², providing ample speed and space to store your valuable data. With its unrivalled convenience and impressive storage capabilities, the XS1000 is your reliable companion for hassle-free file backup, ensuring your important documents, cherished memories and media files are always readily accessible. Say goodbye to bulk and hello to streamlined storage efficiency with the XS1000 external SSD.

- › Compact, pocket-sized form factor
- › Speeds up to 1,050MB/s¹ with USB 3.2 Gen 2
- › Increased storage up to 2TB²

FEATURES / BENEFITS

Ultimate portability — Compact and weighing just under 29g, this sleek, all-black SSD fits in your palm, allowing you to take your files on the go effortlessly.

Reliable file backup — Take it all with you. Transfer and store your documents, large photos and videos without interruption.

Increased storage — Expand your digital library with high capacities up to 2TB² to preserve life's cherished moments.

USB 3.2 Gen 2 support — Achieve read/write speeds up to 1,050MB/s¹ with backwards compatibility to USB 3.2 Gen 1 ensuring seamless connectivity with legacy devices.

SPECIFICATIONS

Interface

USB 3.2 Gen 2

Speed¹

Up to 1,050MB/s read, 1,000MB/s write

Capacities²

1TB, 2TB

Dimensions

69.54 x 32.58 x 13.5mm

Weight

28.7g

Casing Material

Metal + Plastic

Operating temperature

0°C~40°C

Storage temperature


-20°C~85°C

Warranty/Support³

Limited 5-year warranty with free technical support

Compatible with

Windows® 11, 10, macOS (v.10.15.x +), Linux (v. 4.4.x +), Chrome OS™

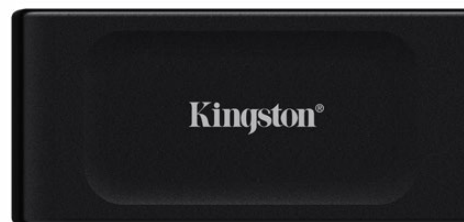

KINGSTON PART NUMBERS

XS1000 External SSD

SXS1000/1000G

SXS1000/2000G

COMPATIBILITY TABLE

	USB 3.2 Gen 2
Windows® 11	✓
Windows® 10	✓
macOS (v. 10.15.x +)	✓
Linux (v. 4.4.x +)	✓
Chrome OS™	✓

1. Based on internal testing. Speed may vary due to host hardware, software and usage. USB 3.2 Gen 2 host device required for optimal speeds.

2. Some of the listed capacity on a flash storage device is used for formatting and other functions and thus is not available for data storage. As such, the actual available capacity for data storage is less than what is listed on the products. For more information, go to Kingston's Flash Memory Guide.

3. Limited warranty based on 5 years or "SSD Life Remaining" which can be found using the Kingston SSD Manager. A new, unused product will show a wear indicator value of one hundred (100), whereas a product that has reached its endurance limit of program erase cycles will show a wear indicator value of one (1). See Kingston.com/wa for details.



THIS DOCUMENT SUBJECT TO CHANGE WITHOUT NOTICE.

©2023 Kingston Technology Corporation, 17600 Newhope Street, Fountain Valley, CA 92708 USA. All rights reserved. All trademarks and registered trademarks are the property of their respective owners. MKD-462 EN

Kingston
TECHNOLOGY

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kingston:](#)

[SXS1000R/1000G](#) [SXS1000R/2000G](#)