

5MM RGB LED DIODE - COMMON ANODE(+)

Weight 0.4 g



DESCRIPTION

5mm RGB LED diode in through-hole version with 4 pins. Each of those represents one color (-), while longest pin is common anode(common +) for all three colors.





- **Voltage:** 3.4V for blue and green, 2.3V for red
- **Current:** 20mA per color, total max. 60mA
- **Diode size:** 5mm, diffused
- **Light angle:** 25 degrees

FEATURES

- Voltage: 3.4V for blue and green, 2.3V for red
- Current: 20mA per color, total max. 60mA
- Light angle: 25 degrees
- Diode size: 5 mm / 0.2", diffused

USEFUL LINKS

OTHER IMAGES

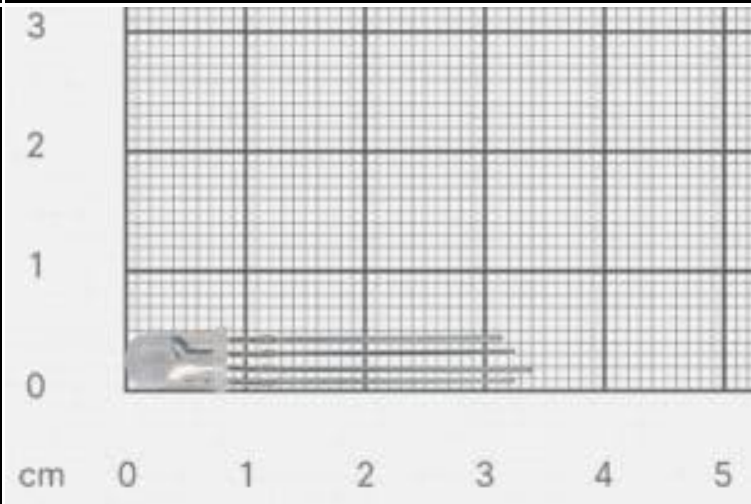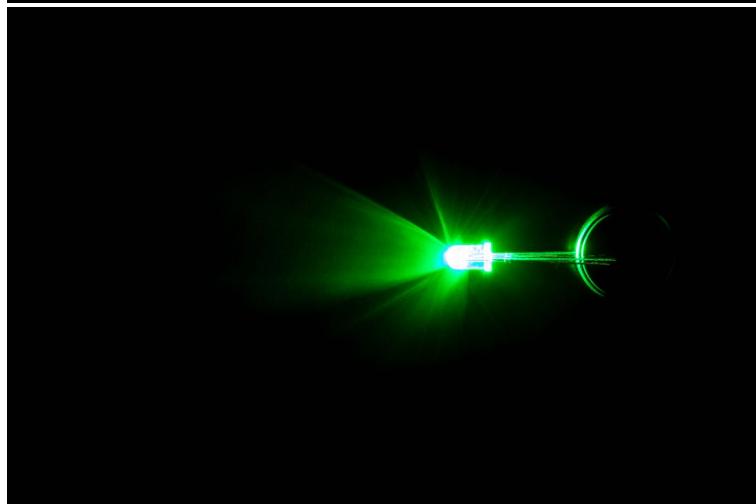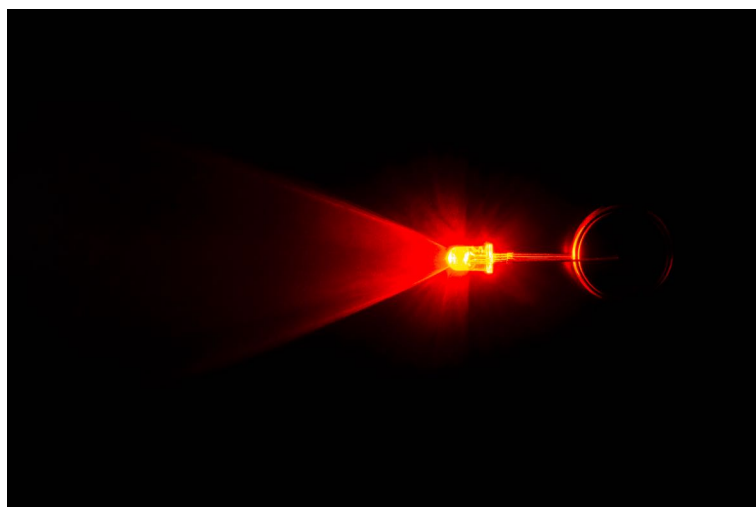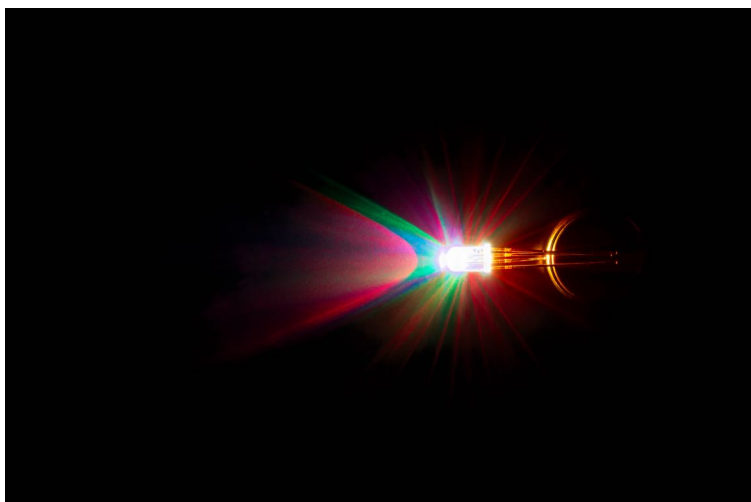

Weight

0.4 g

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Soldered:

109113