

# MR1000 SERIES DETECTOR SWITCH

ANTI-VANDAL  
SWITCHES

DETECTOR  
SWITCHES

DIP  
SWITCHES

KEYLOCK  
SWITCHES

NAVIGATION  
SWITCHES

PUSHBUTTON  
SWITCHES

ROCKER  
SWITCHES

ROTARY  
SWITCHES

SLIDE  
SWITCHES

SNAP ACTION  
SWITCHES

TACTILE  
SWITCHES

TOGGLE  
SWITCHES


CAP  
OPTIONS




## APPLICATIONS / MARKETS



Commercial Appliances

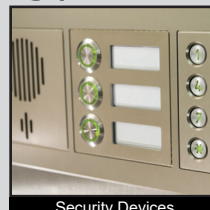


Security Devices

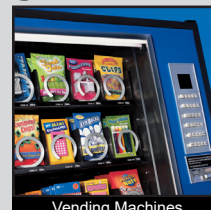

Vending Machines



HVAC

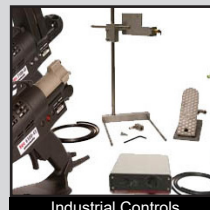

Industrial Controls



Medical Equipment

**RoHS**

## SPECIFICATIONS

Contact Rating: 0.5A, 10VAC or 10VDC  
Contact Resistance: 150MΩ  
Contact Arrangement: SPST N.O.

## FEATURES & BENEFITS

- Recessed switch
- Magnetic contact
- 9.52 [0.375 in] Press fit
- 457.20 [18.000 in] #22AWG wire leads
- Closed gap options

## PART NUMBER CONFIGURATOR

Series



MR1000

DIM "X"



A - 19.0 [0.75 in]  
B - 25.0 [1.00 in]

Housing Color



W - White

Lead Length



A - 457.20 [18.000 in]

Specifications subject to change without notice 9.19.2018



**E-SWITCH®**



www.e-switch.com

800.867.2717


1

# MR1000 SERIES DETECTOR SWITCH

## BODY DIMENSIONS

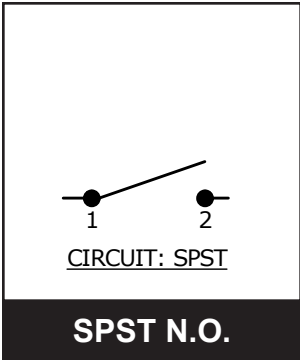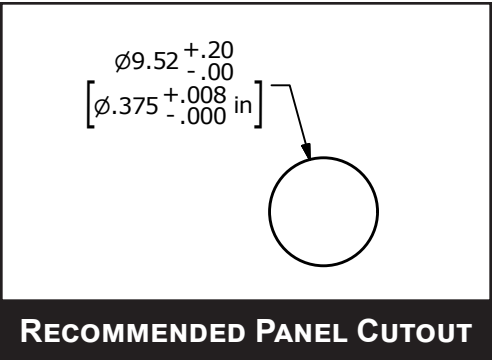

	DIM "X"	DIM "X"
CLOSED GAP	A = 19.0 [0.75 in]	B = 25.0 [1.00 in]
DEPARTURE GAP	A = 22.0 [0.87 in]	B = 28.0 [1.10 in]

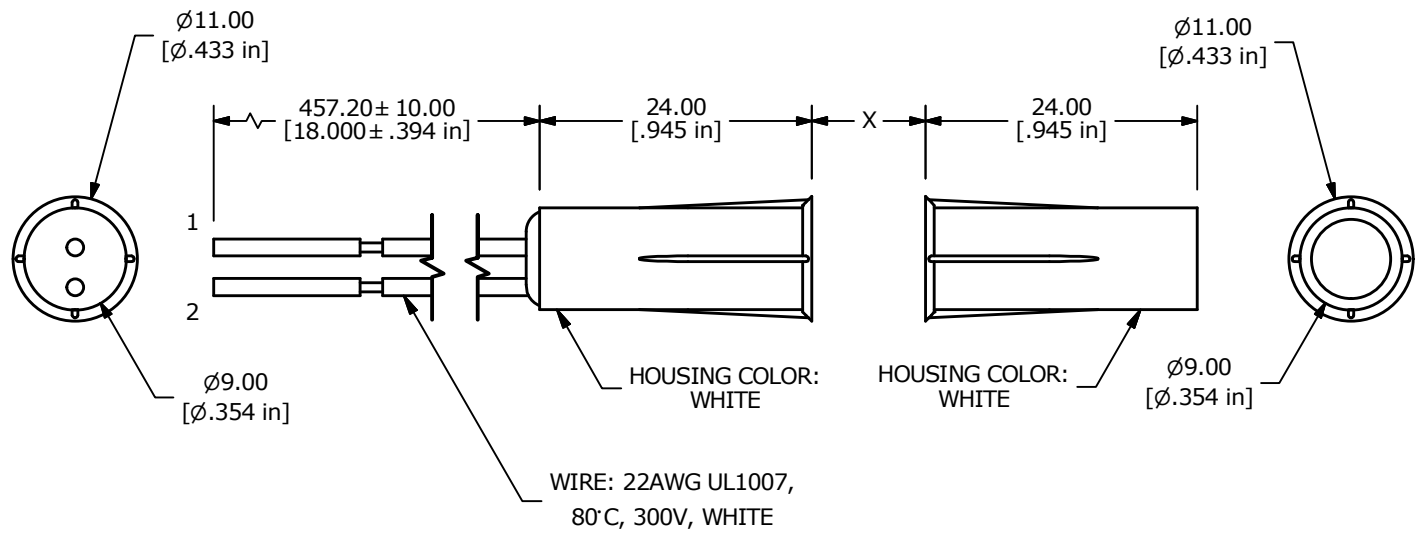

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[MR1000BWA](#) [MR1000AWA](#)