



APPLICATIONS / MARKETS




Audio / Visual



Computer Peripherals



Consumer Electronics

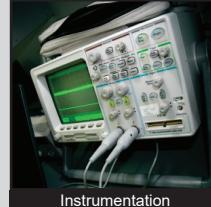

Instrumentation



Security Devices



Medical Equipment

RoHS

SPECIFICATIONS

Contact Arrangement: SPST
Contact Rating: 50mA @ 12VDC
Contact Resistance: 100mΩ Initial
Insulation Resistance: 100 MΩ Min.
Dielectric Strength: 250V RMS
Electrical Life: 100,000 cycles
Operating Temperature: -25°C to 70°C
Storage Temperature: -25°C to 70°C
Travel: 0.25mm ± 0.1mm
Actuation Force: 350 gf ± 100gf
Panel Thickness: 3.5mm Max.

FEATURES & BENEFITS

- 500mm long wire leads with connectors
- Single color and bi-color LED options
- Sharp tactile response
- Panel Mount

PART NUMBER CONFIGURATOR




TL1275



C - Snap-in Bezel



 A2 - Standard Housing



WA500 - 500mm Long Wire Leads



Q - Silver



P - Illuminated Power Symbol



R - Red
B - Blue
G - Green
W - White
Y - Yellow
RG - Red-Green

Specifications subject to change without notice 12.5.2018




E-SWITCH®

www.e-switch.com


800.867.2717

TL1275 SERIES TACT SWITCH



BODY DIMENSIONS

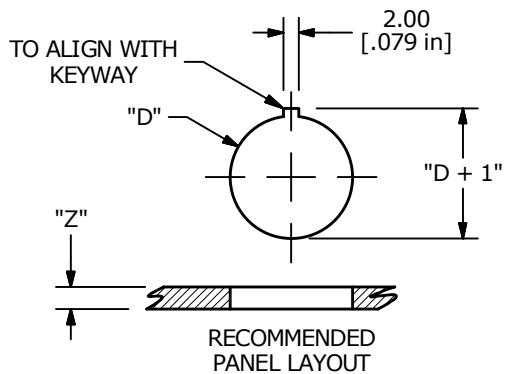

"Z"	"D"
0-0.5	16.0-16.1
0.5-2.0	16.1-16.2
2.0-2.5	16.2-16.4
2.5-3.0	16.4-16.6
3.0-3.5	16.6-16.8

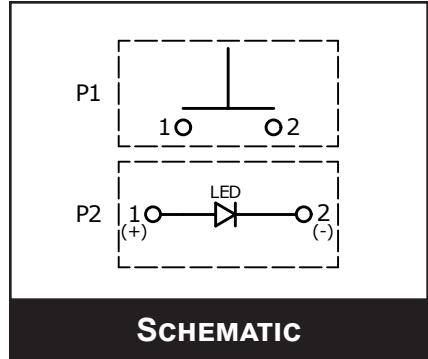

WIRE CHART			
CONNECTOR	POSITION	SWITCH	WIRE
P1	1	1	300V 105°C 26 AWG AWM, BLACK
P1	2	2	300V 105°C 26 AWG AWM, BLACK
P2	1	+	300V 105°C 26 AWG AWM, RED
P2	2	-	300V 105°C 26 AWG AWM, GREEN

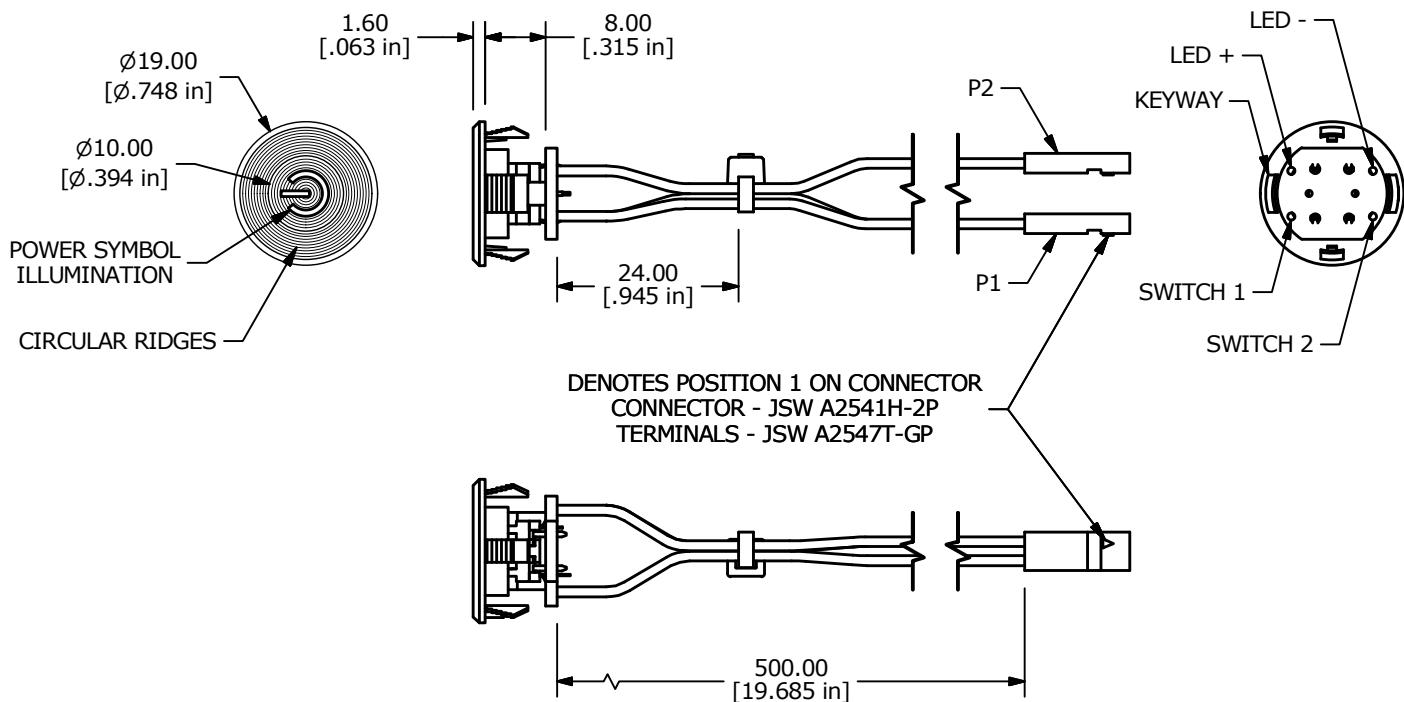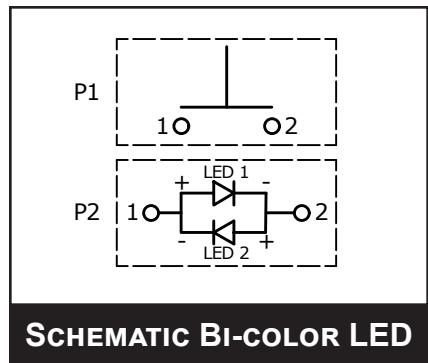

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES

TACTILE
SWITCHES

TOGGLE
SWITCHES

CAP
OPTIONS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[TL1275CA2WA500QPR](#) [TL1275CA2WA500QPRG](#) [TL1275CA2WA500QPB](#) [TL1275CA2WA500QPG](#)