


E200 SERIES PUSHBUTTON SWITCH

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS




APPLICATIONS / MARKETS

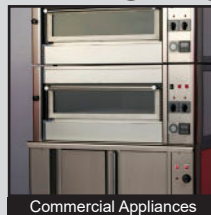


Commercial Appliances



Security Devices

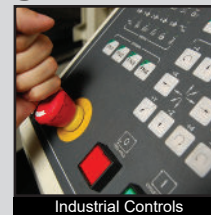


Industrial Controls

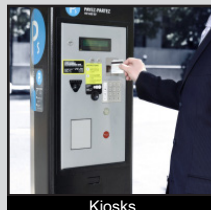

Kiosks



Electrical Housewares

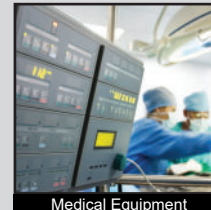

Medical Equipment

RoHS

SPECIFICATIONS

Contact Arrangement: 1NO/1NC+1NO/1NC, 1NO/1NC, 2NO, 1NO

Contact Rating: 200mA @ 250VDC
5A @ 250VAC [VDE](Pending)
6A @ 24 VDC
8A @ 125VAC

Agency Approvals: ANSI/UL508, VDE (Pending)

Contact Resistance: 50mΩ Max. (Initial)

Insulation Resistance: 100 MΩ Min. @ 500VDC

Dielectric Strength: 1,500VAC

Electrical Life: 50,000 Cycles MIN

Mechanical Life: 100,000 Cycles MIN

Operating Temperature: -25°C to 55°C (with lamp)
-25°C to 70°C (without lamp)

Storage Temperature: -40°C to 85°C

Actuation Force: 2.0 kgf

Panel Thickness: 5.0mm MAX.

Moisture Protection: IP65

FEATURES & BENEFITS

- Easy operation
- High actuation force
- Multiple illumination options
- Pushlock turn design to reset
- 16mm cutout size
- IP65 rated

PART NUMBER CONFIGURATOR

Series



E200

Actuator Options



R11 = Illuminated
R22 = Non-Illuminated

Housing Options



A1 = Illuminated
1NO/1NC+1NO/1NC
B1 = Illuminated 1NO/NC
C1 = Non-Illuminated
1NO/1NC+1NO/1NC
D1 = Non-Illuminated
1NO/1NC

Illumination Options



0 = No Lamp
F = Neon 110V AC
G = Neon 220V AC
H = LED 6V DC
J = LED 12V DC
K = LED 24V DC
K1 = LED 12 to 24 V AC/DC
P = LED 120V AC
A = Incandescent 6V AC/DC 200mA
B = Incandescent 14V AC/DC 80 mA
C = Incandescent 28V AC/DC 40mA
D = Incandescent 48V AC/DC 25mA
E = Incandescent 60V AC/DC 20mA
M = Incandescent 6V AC/DC 40mA
N = Incandescent 14V AC/DC 40mA
L = Incandescent 33V AC/DC 35mA

Actuator Color



R = Red

Specifications subject to change without notice 4.25.2024



E-SWITCH®


www.e-switch.com

800.867.2717




1

ANTI-VANDAL SWITCHES	DETECTOR SWITCHES	DIP SWITCHES	KEYLOCK SWITCHES	NAVIGATION SWITCHES	PUSHBUTTON SWITCHES	ROCKER SWITCHES	ROTARY SWITCHES	SLIDE SWITCHES	SNAP ACTION SWITCHES	TACTILE SWITCHES	TOGGLE SWITCHES	CAP SWITCHES
----------------------	-------------------	--------------	------------------	---------------------	---------------------	-----------------	-----------------	----------------	----------------------	------------------	-----------------	--------------


RECOMMENDED PANEL CUTOUT

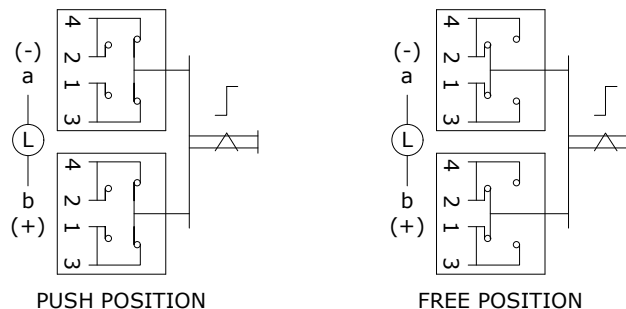

PUSHLOCK TURN TO RESET

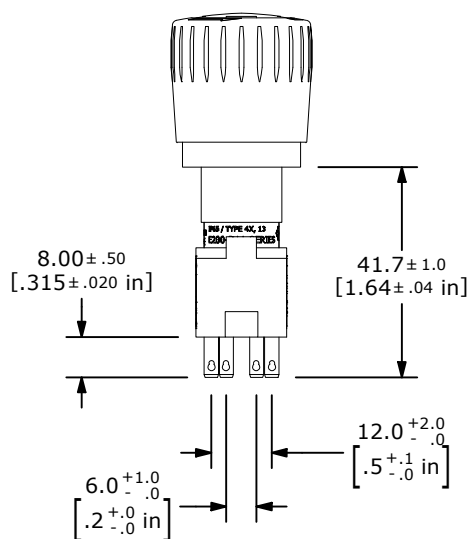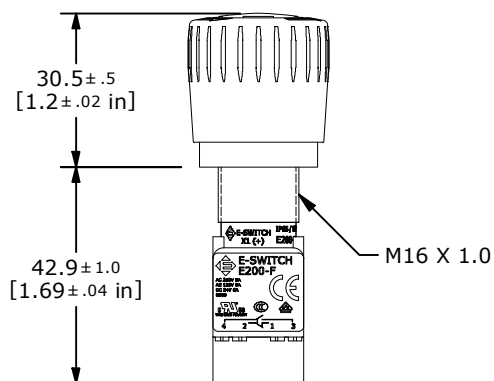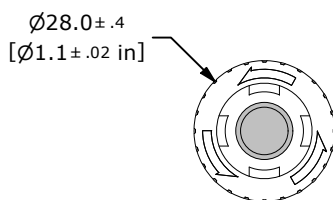







SIDE VIEW SHOWN
WITHOUT TERMINAL
SHROUD

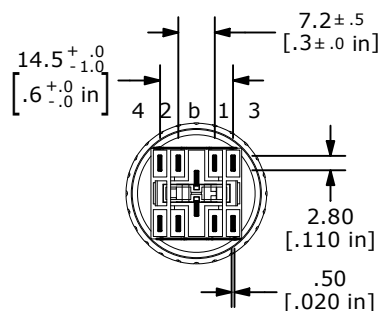

BOTTOM VIEW SHOWN
WITHOUT SHROUD ACTUATOR

E200 SERIES PUSHBUTTON SWITCH

BODY DIMENSIONS - NON-ILLUMINATED

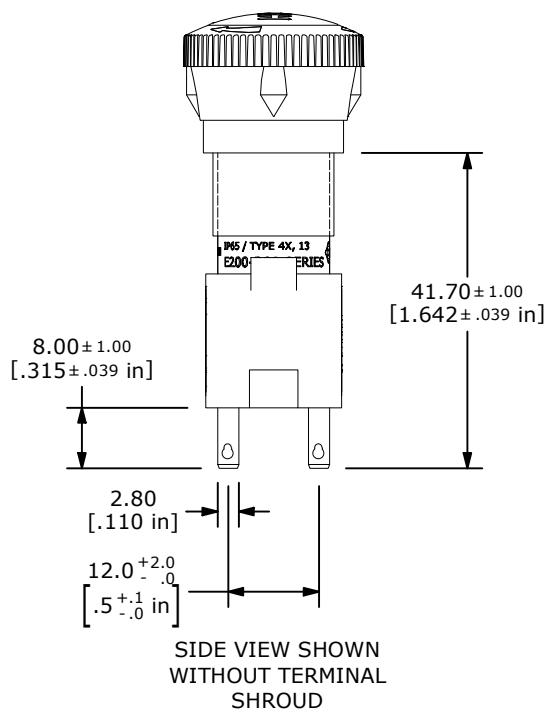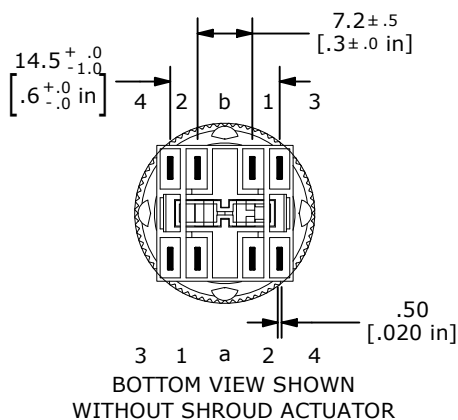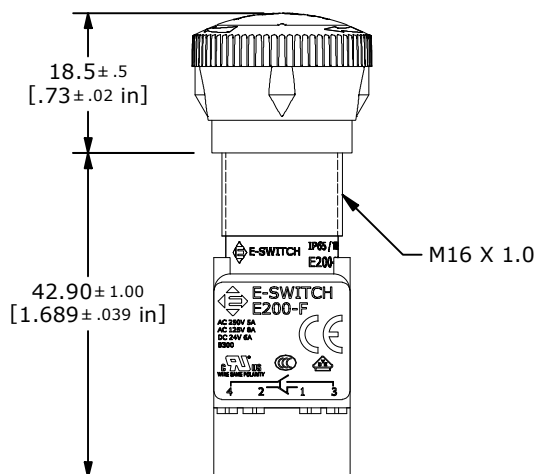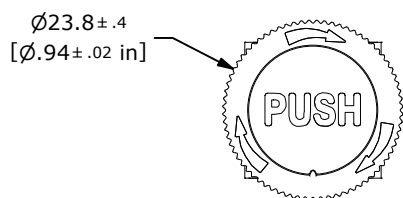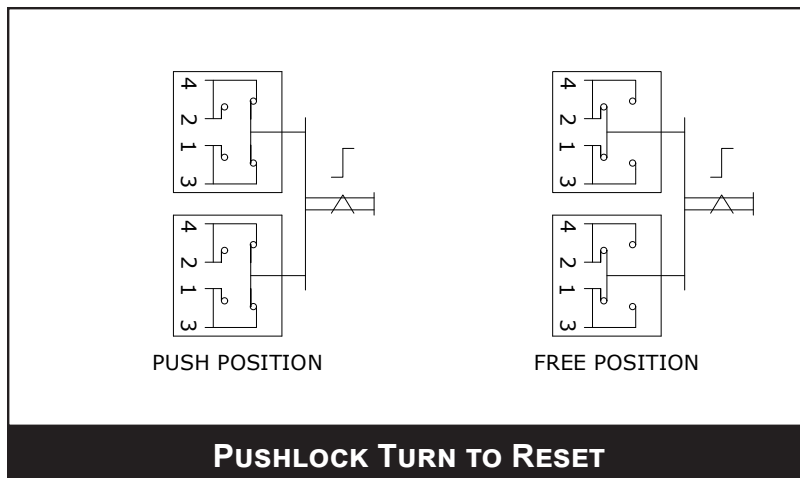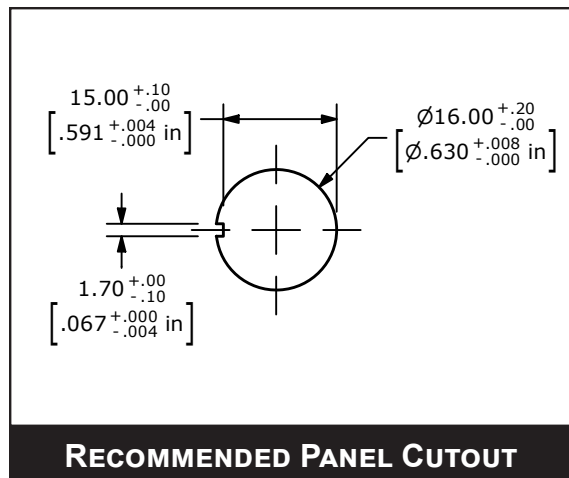

E-SWITCH®

www.e-switch.com

800.867.2717

3

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[E200-R11-A1KR](#) [E200-R22-C10R](#)