


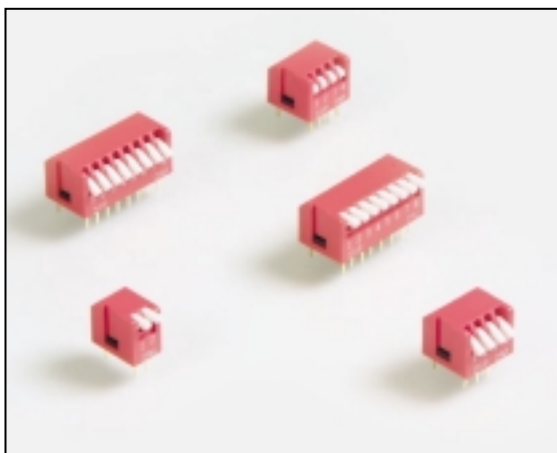

SPECIFICATIONS

Switch Function:	SPST, 1 thru 12 positions (except position 11)
Contact Rating:	Switch: 25mA @ 24V DC Carry: 100mA @ 50V DC
Insulation Resistance:	100 MΩ Min. @ 500V DC
Contact Resistance:	Initial: 50 mΩ typical @ 2-4V DC @ 100mA After Life: 100mΩ typical @ 2-4 DC @ 100mA
Operating Life:	2,000 make-and-break cycles, each circuit
Operating Force:	1000 gf max.
Travel (Actuator):	2.0 mm typical
Dielectric Strength:	500V RMS min. @ sea level between adjacent terminals
Temperature Range:	Operating/Storage: -40° C to 85° C
Vibration:	To MIL-STD-202F, Method 201 A
Shock:	To MIL-STD-202F, Method 213B, Condition A
Soldering:	
Recommendations:	Wave: 500 F (260 C) for 5s max; Hand: 30W soldering iron @ 608 F (320 C) for 2s typical. Keep all switches in the "OFF" position during soldering and cleaning process.

MATERIALS

Housing and Actuator:	Glass filled polyester (PBT) UL94-V0
Contacts:	Phosphor Bronze with gold plate over nickel plate
Terminals:	Phosphor Bronze with gold plate over nickel plate
Tape:	Mylar

PACKAGING

Switches are supplied in standard IC tubes with all poles "OFF".

HOW TO ORDER

Series	Model No.	Termination	Circuit	No. of Positions	Actuator	Seal
KA						
	P=Piano Type	1=PC Pin	1=SPST	02 03 04 05 06 07 08 09 10 12	R=Recessed Act., Top Side OFF E=Extended Act., Top Side OFF V=Recessed Act., Top Side ON W=Extended Act., Top Side ON	(None)=Std. Unsealed T=Top Tape Sealed


EXAMPLE

KA → P → 1 → 1 → 04 → R → T


SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE.

PIANO DIP SWITCHES


TERMINATION OPTIONS

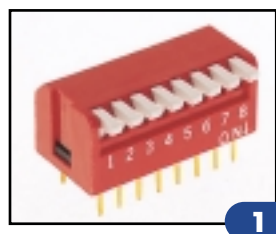


PC Pin

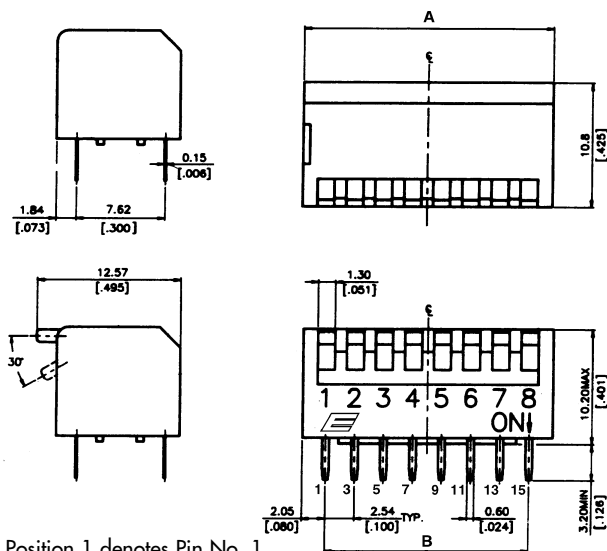

P.C. MOUNTING

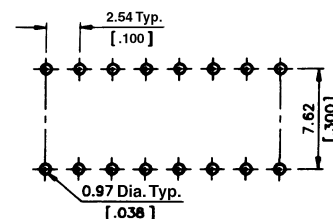


Schematic

 


ACTUATOR OPTIONS

Positions:	2	3	4	5	6	7	8	9	10	12
"A"	6.64	9.18	11.72	14.26	16.8	19.34	21.88	24.42	26.96	32.04
Dimension:	(.261)	(.361)	(.461)	(.561)	(.661)	(.761)	(.861)	(.961)	(1.061)	(1.261)
"B"	2.54	5.08	7.62	10.16	12.7	15.24	17.78	20.32	22.86	27.94
Dimension:	(.100)	(.200)	(.300)	(.400)	(.500)	(.600)	(.700)	(.800)	(.900)	(1.100)


NUMBER OF POSITIONS

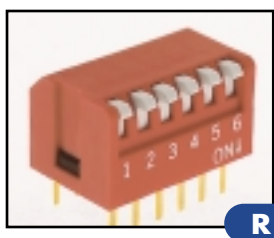


Recessed topside "OFF"

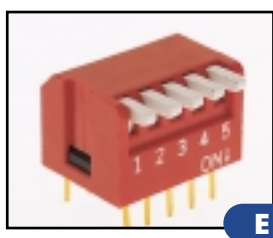

Extended Topside "OFF"

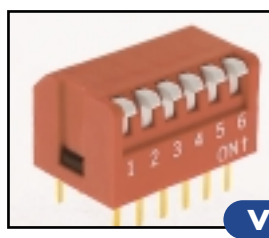


Recessed Topside "ON"

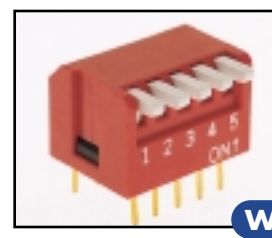

Extended Topside "ON"

SEAL OPTIONS

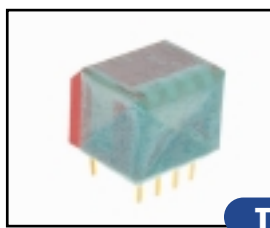

Top Tape Sealed

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[KAP1104V](#) [KAP1106V](#)