

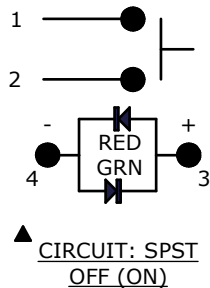


▲ LED SPECS	UNITS	RED	GREEN
FORWARD CURRENT	mA	20	20
FORWARD VOLTAGE @20mA	V	2.0-2.5	2.1-2.5
LUMINOUS INTENSITY @ 20mA	mcd	400	60

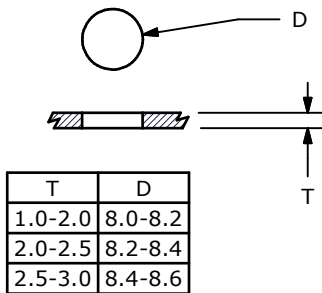

NOTES:

- ALL DIMENSIONS IN MM [INCH]
- GENERAL TOLERANCE: X.X=±0.4
X.XX=±0.25
- RATING: 30VDC @ 100mA
- CONTACT RESISTANCE: 50 Milli-OHMS MAX.
- INSULATION RESISTANCE: 100Mega-OHMS MIN@500VDC.
- OPERATING FORCE: 250 ± 100gf
- TRAVEL: 1.8± 0.3mm
- OPERATING TEMPERATURE: -40°C TO 85°C
- OPERATING LIFE: 50,000 CYCLES
- ▲ 10. LED: RED (FORWARD), GREEN (REVERSE)
- ▲ 11. ▲ DENOTES CRITICAL PARAMETERS
- 2002/95/EC (ROHS) COMPLIANT

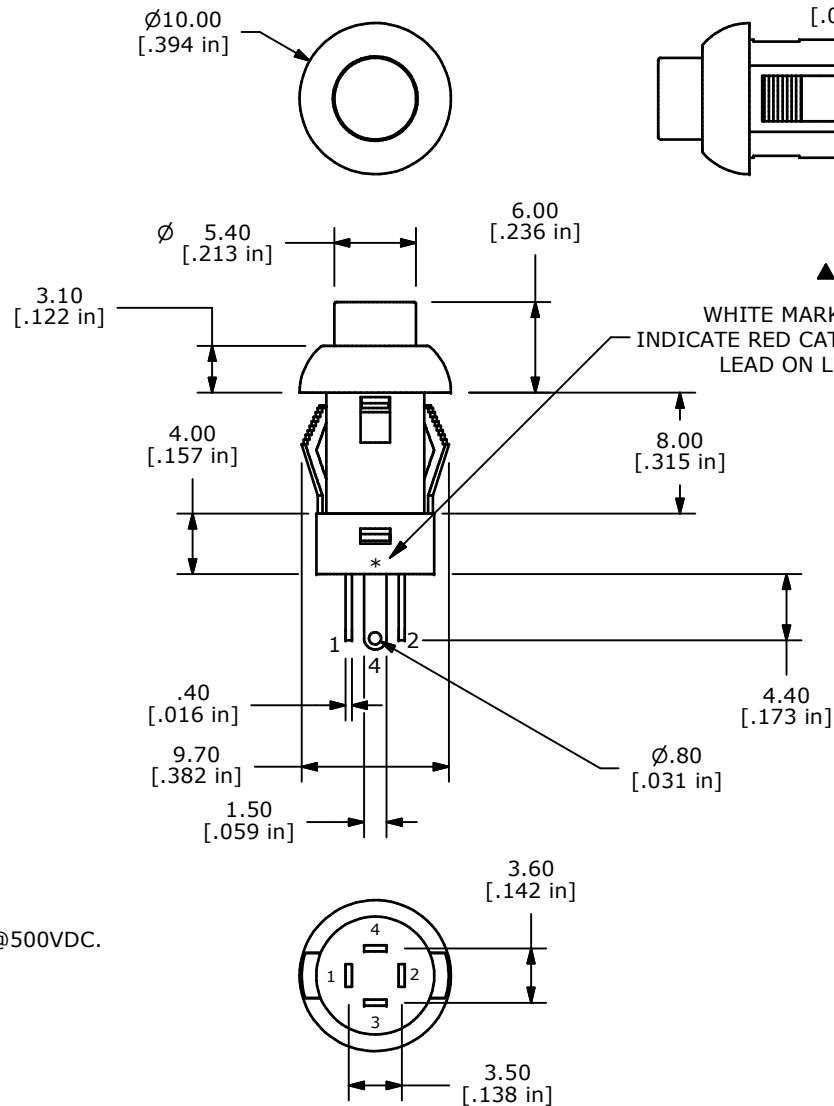

ISOMETRIC



TITLE LP10A1ARG

A	21073	NEW RELEASE	3/19/13	EBP
REV	PCR NO	DESCRIPTION	DATE	BY

THE INFORMATION CONTAINED IN THIS DOCUMENT IS PROPRIETARY
TO E-SWITCH AND IS NOT TO BE COPIED OR TRANSFERRED

SCALE	DATE 3/19/2013	DR EBP	DWG B200205	REV A
-------	-------------------	-----------	----------------	----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[LP1OA1ARG](#)