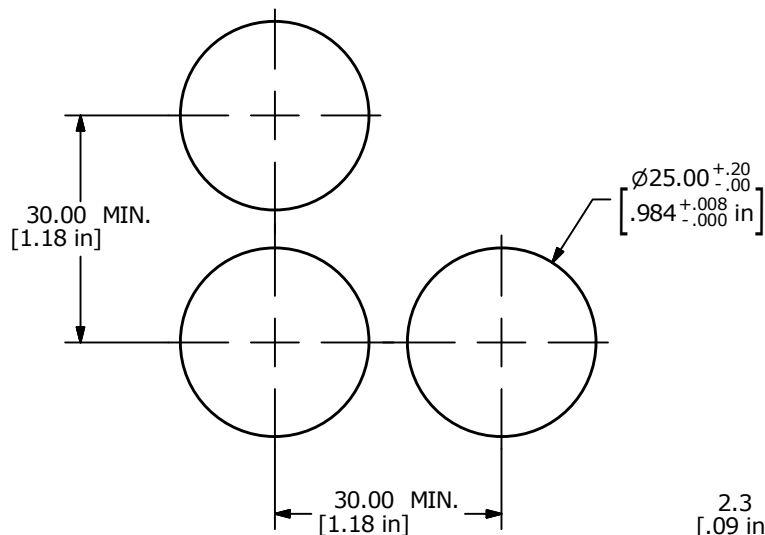


▲ Parts List

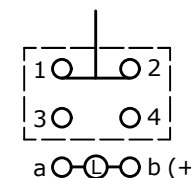
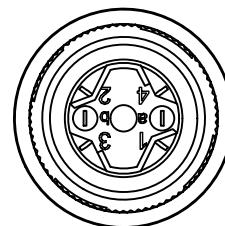
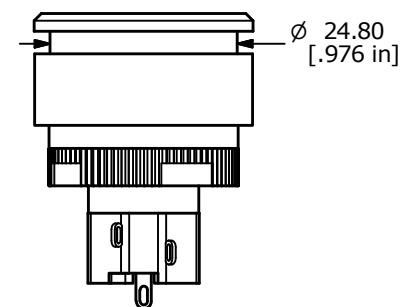
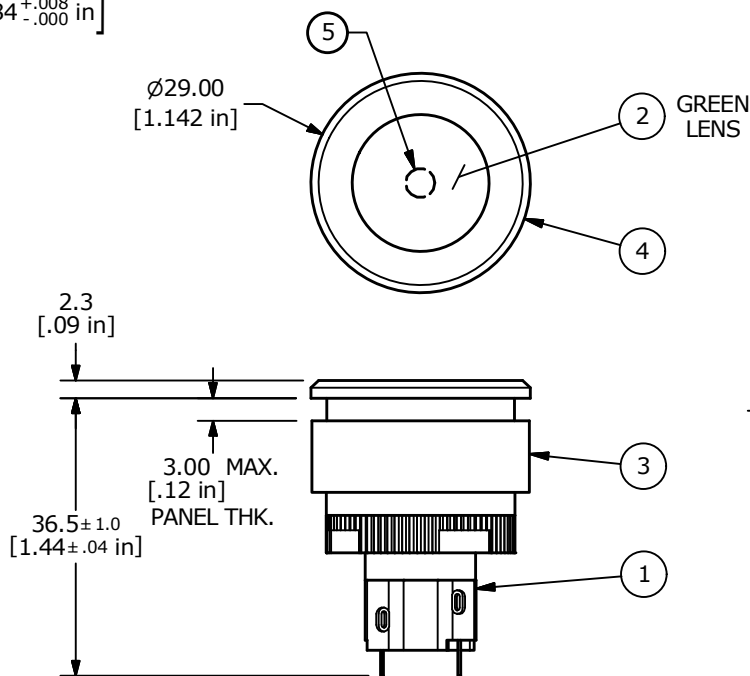
ITEM	QTY	PART NUMBER	DESCRIPTION
1	1	F060602	LASEEV11
2	1	F060202	25mm GREEN LENS
3	1	F051705	29mm FLUSH MOUNT RETAINER
4	1	F051704	29mm FLUSH MOUNT BEZEL
5	1	F050422	24 VDC GREEN LED



RECOMMENDED PANEL MOUNTING

NOTES:

- ALL DIMENSIONS IN MM [INCH].
- GENERAL TOLERANCE: X.X = ± 0.4
X.XX = ± 0.25
- TERM. NOS. FOR REF. ONLY.
- RATING: 5A @250VAC
8A @125VAC
0.2A @250VDC
6A @24VDC
- INSULATION: 1,000 M Ω MIN.
- DIELECTRIC STRENGTH: 2000V FOR 1 MIN.
- SEALED TO IP65.
- TRAVEL: 3.0mm FULL TRAVEL, 2.0mm LATCH
- ELECTRICAL LIFE: >50,000 CYCLES
- OPERATING TEMP: -25C to +55C
- PANEL THICKNESS: 0.5mm to 3.0mm
- LAMP VOLTAGE: LED 24V DC GREEN
- ▲ DENOTES CRITICAL PARAMETER.
- PACKAGE: BOX/20 PCS PER.

▲ SPDT
CONTACT CONFIGURATION

E-SWITCH®

B	23586	update Bezel dia. to 29.00mm	10/2/18	MW
A	18121	RELEASE FOR PRODUCTION	6/4/08	BLR
REV	PCR NO	DESCRIPTION	DATE	BY

THE INFORMATION CONTAINED IN THIS DOCUMENT IS PROPRIETARY
TO E-SWITCH AND IS NOT TO BE COPIED OR TRANSFERRED

TITLE LASEEV31KGRNGRN

SCALE
1:1DATE
6/4/2008DR
BLRDWG
XF0751PREV
B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[LASEEV31KGRNGRN](#)