

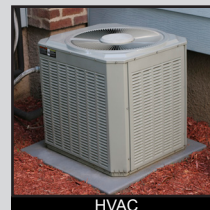


ST4 SERIES TOGGLE SWITCH

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS

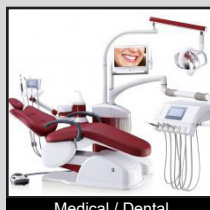

APPLICATIONS / MARKETS

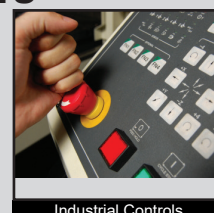

RoHS

SPECIFICATIONS

Contact Rating: 16(8)A 125/250VAC μ T55
20(8)A 125/250VAC μ T55
20A 6-30VDC μ T55

Electrical Life: 10,000 Cycles

Contact Resistance: 50m Ω Max. initial

Insulation Resistance: 50M Ω Min.

Dielectric Strength: 1500V RMS

Operating Temperature: -10°C to 55°C

Storage Temperature: -10°C to 65°C

Circuit Function: SP or DP
2 or 3 Position

Agency Approvals: cURus

Moisture Protection: IP68

Panel Thickness: 1-8mm

FEATURES & BENEFITS

- Multiple termination options
- Single or double pole
- Available in both 2 or 3 position circuits
- Multiple Actuator options

PART NUMBER CONFIGURATOR

Series	No. of Poles	Function	Rating	Actuator	Termination
S T 4	S D	P 1 2 3 4 5 6 7 8 9 10	A B D	T 2	C 1 2 S 1 2
ST4	S - Single Pole D - Double Pole	P1 - OFF - (ON) P2 - OFF - ON P3 - ON - ON P4 - (OFF) - ON P5 - (ON) - OFF P6 - (ON) - ON P7 - ON - (ON) P8 - ON - OFF - ON P9 - ON - OFF - (ON) P10 - (ON) - OFF - (ON)	A - 16(8)A 125/250VAC μ T55 B - 20(8)A 125/250VAC μ T55 D - 20A 6-30VDC μ T55	T1 - 17mm Metal Bat T2 - 22mm Plastic Bat	C1 - 3/16 Quick Connect C2 - 1/4 Quick Connect S1 - Solder Lug S2 - Screw Terminal

* () denotes momentary

Specifications subject to change without notice 6.9.2021



E-SWITCH®


www.e-switch.com

800.867.2717

1

ST4 SERIES TOGGLE SWITCH


No. of Pole AND Function Options

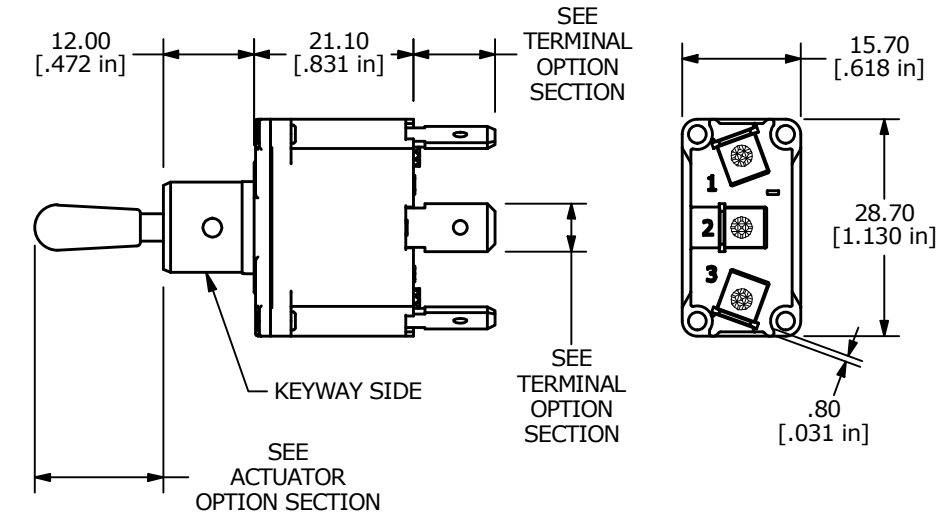

S - SINGLE POLE

			
FUNCTION	POS. 1	POS. 2	POS. 3
P1	OFF	N/A	(ON)
P2	OFF	N/A	ON
P3	ON	N/A	ON
P4	(OFF)	N/A	ON
P5	(ON)	N/A	OFF
P6	(ON)	N/A	ON
P7	ON	N/A	(ON)
P8	ON	OFF	ON
P9	ON	OFF	(ON)
P10	(ON)	OFF	(ON)
TERMINAL CLOSURE	1-2	OPEN	2-3

() = MOMENTARY

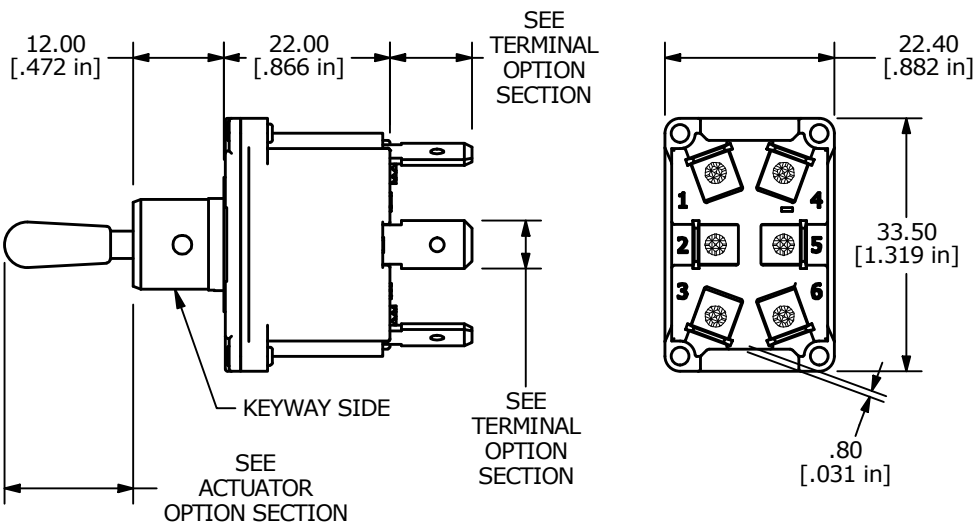

D - DOUBLE POLE




			
FUNCTION	POS. 1	POS. 2	POS. 3
P1	OFF	N/A	(ON)
P2	OFF	N/A	ON
P3	ON	N/A	ON
P4	(OFF)	N/A	ON
P5	(ON)	N/A	OFF
P6	(ON)	N/A	ON
P7	ON	N/A	(ON)
P8	ON	OFF	ON
P9	ON	OFF	(ON)
P10	(ON)	OFF	(ON)
TERMINAL CLOSURE	1-2, 4-5	OPEN	2-3, 5-6

() = MOMENTARY





ST4 SERIES TOGGLE SWITCH

ACTUATOR OPTIONS

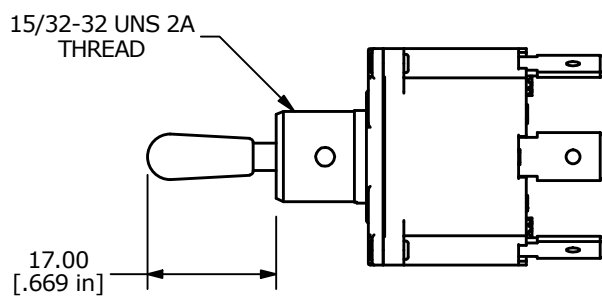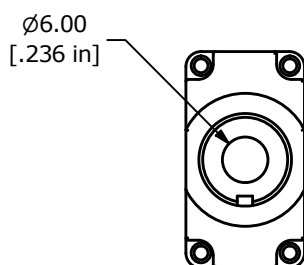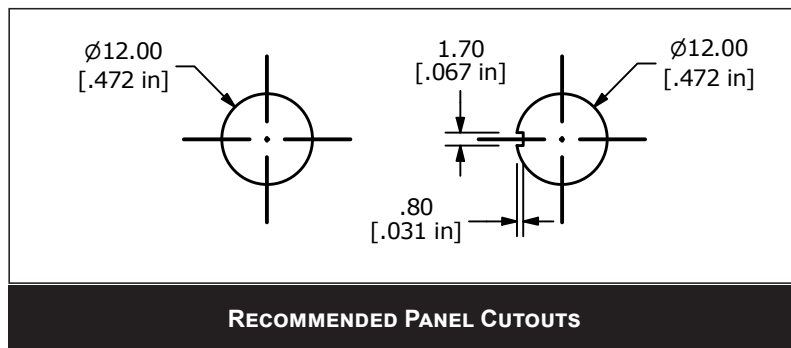

T1 = 17mm METAL BAT

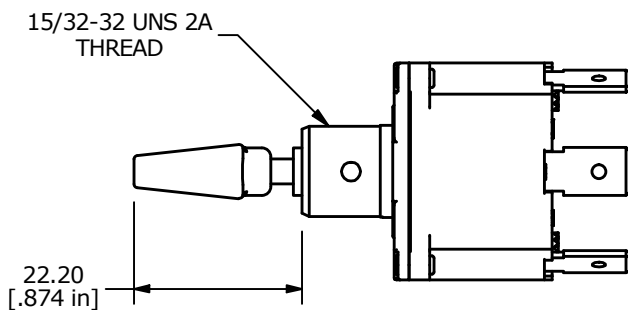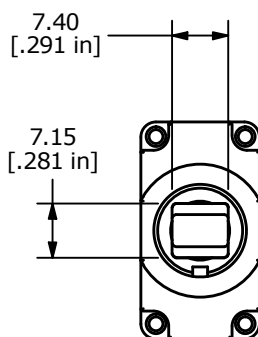

T2 = 22mm PLASTIC BAT



E-SWITCH®



www.e-switch.com

800.867.2717



3

ST4 SERIES TOGGLE SWITCH



TERMINAL OPTIONS

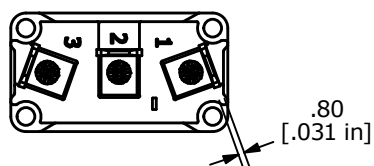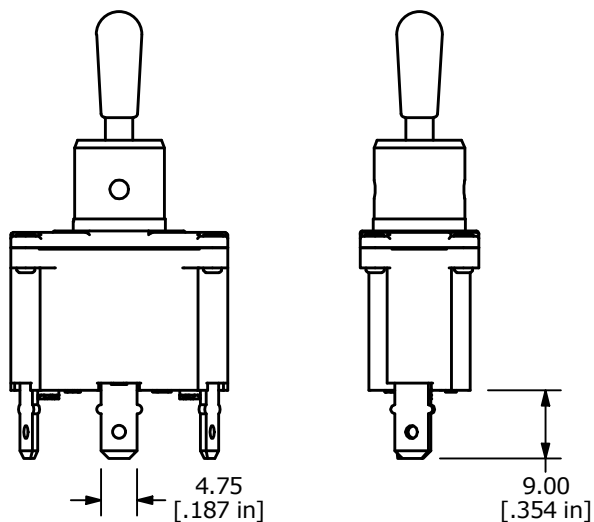



C1 = 3/16 QUICK CONNECT

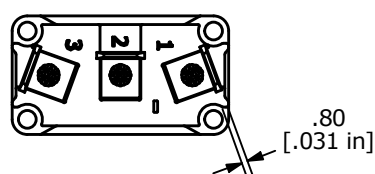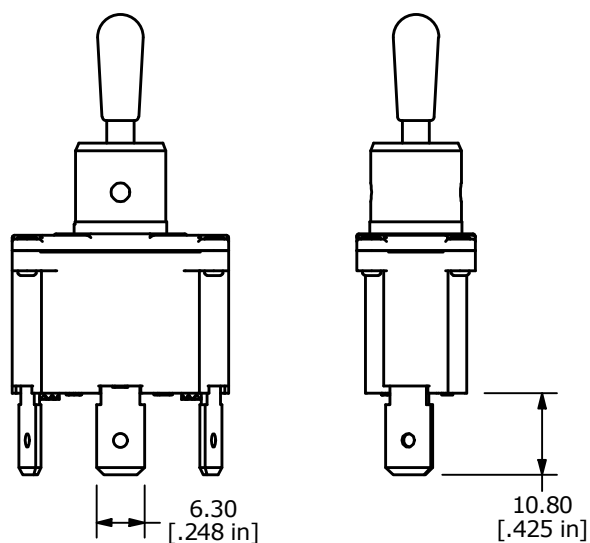

C2 = 1/4 QUICK CONNECT

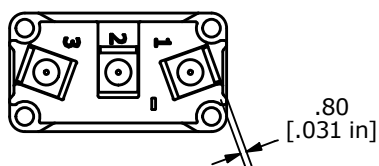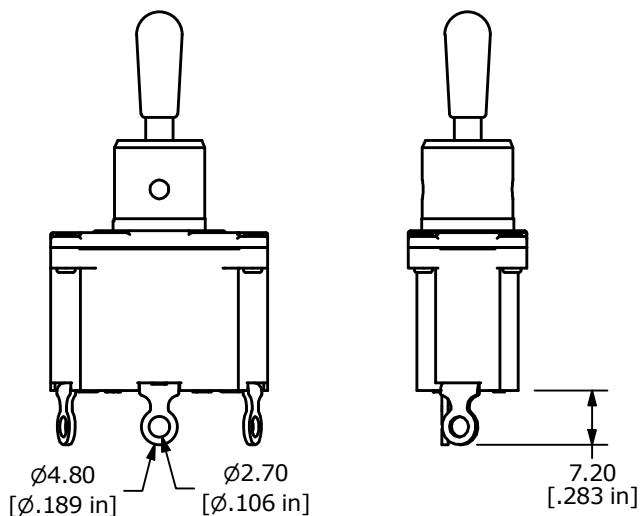

S1 = SOLDER LUG

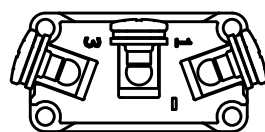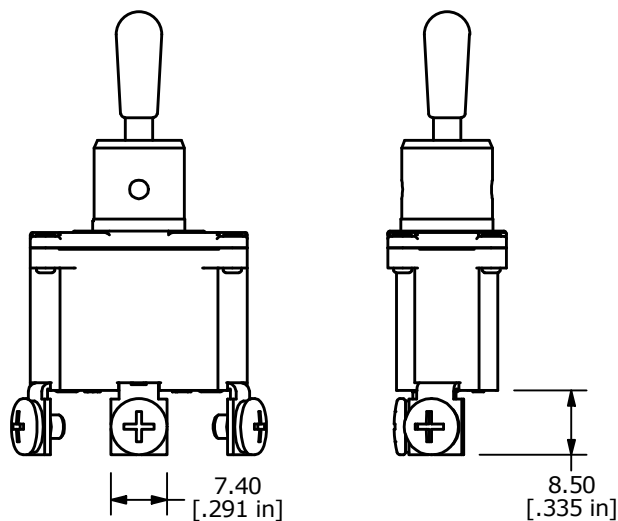

S2 = SCREW TERMINAL



E-SWITCH®

www.e-switch.com

800.867.2717

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[ST4DP5AT1S2](#) [ST4SP8AT2C2](#) [ST4DP10DT2C1](#) [ST4SP2BT1S1](#)