
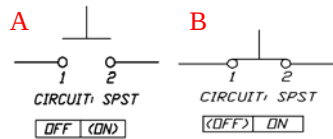


PS1024 PANEL MOUNT PUSH BUTTON SWITCHES

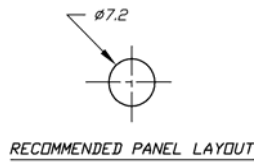

MECHANICAL SPECIFICATIONS



Mechanical Life: 6,000 Cycles
Electrical Life: 6,000 cycles

ELECTRICAL SPECIFICATIONS

Contact Rating: 3A@125VAC
1.5A@250VAC
Contact Resistance (Initial Max): 50m Ohms
Insulation Resistance: 500M Ohms Min.
Dielectric Strength: 1000VAC 1 minute

ENVIRONMENTAL SPECIFICATIONS

Operating/Storage Temp: -20°C to 65°C

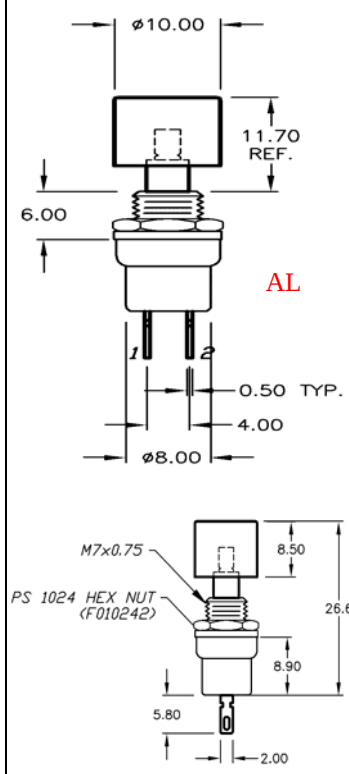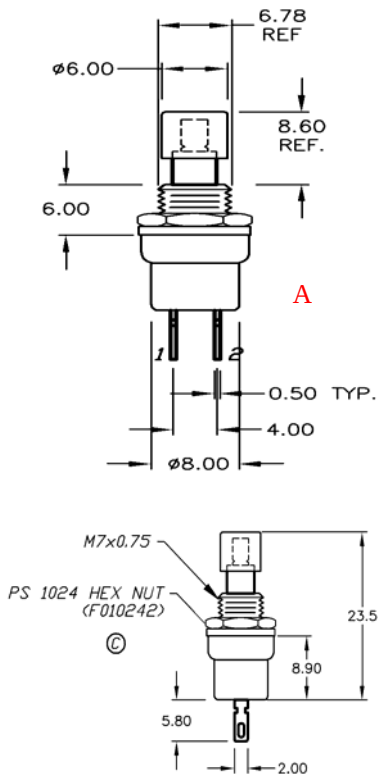

How To Order

SERIES

PS1024

CIRCUITA=OFF-(ON)
B=(OFF)-ON

()=Momentary

BUTTON STYLEA=6mm ROUND CAP
AL=10mm ROUND CAP
N=NO CAP**CAP COLOR**BLK=BLACK
RED=RED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[PS1024AT-RED](#) [PS1024AT-BLK](#) [PS1024AL-BLK](#) [PS1024AL-RED](#) [PS1024ANOCAP](#) [PS1024ABLK](#) [PS1024ARED](#)
[PS1024BLBLK](#) [PS1024BBLK](#) [PS1024ALBLK](#) [PS1024ALRED](#) [PS1024BLKCAP](#) [PS1024ABLK](#) [PS1024ARED](#)