
 
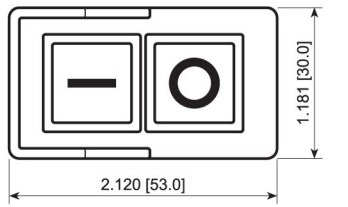





KJD17 Series





Panel Cutout

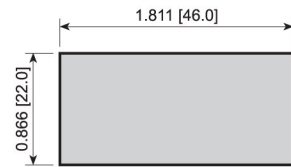

Function Options

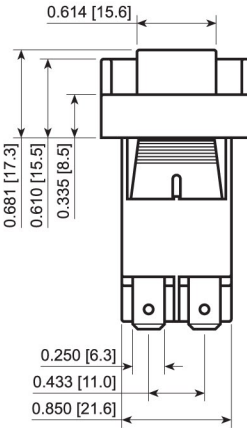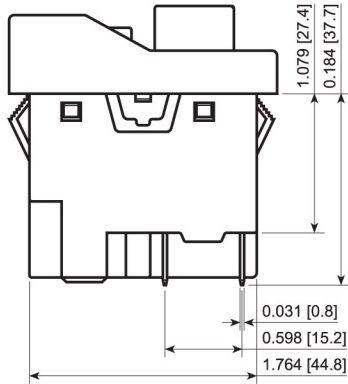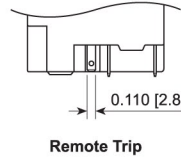

Water Protection Options

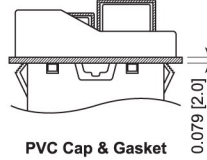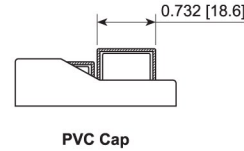

FEATURES:

- Heavy Duty Industrial Design
- Electromagnet Provides Automatic Safety Protection Against Power Outages and Restarts
- PVC Cap for Dust and Water Protection

SPECIFICATIONS:


RATING: 16A 120VAC [cURus UL508]
 16A 220/240VAC [cURus UL508]
 1/2 HP 120VAC [cURus UL508]
 2HP 220/240VAC [cURus UL508]

TEMPERATURE: -25°C to 55°C
ELECTRICAL LIFE: 10,000 Cycles
CONTACT RESISTANCE: 50mΩ Max.
INSULATION RESISTANCE: 100MΩ Min. at 500VDC
DIELECTRIC STRENGTH: 1,500VAC for 1 Minute
INGRESS PROTECTION: IP54 with PVC Cap

MATERIALS:

BODY: Polyamide 6/6
ACTUATOR: Polyamide 6/6
CONTACTS: Silver Alloy
TERMINALS: Silver Plated Brass

PUSHBUTTON

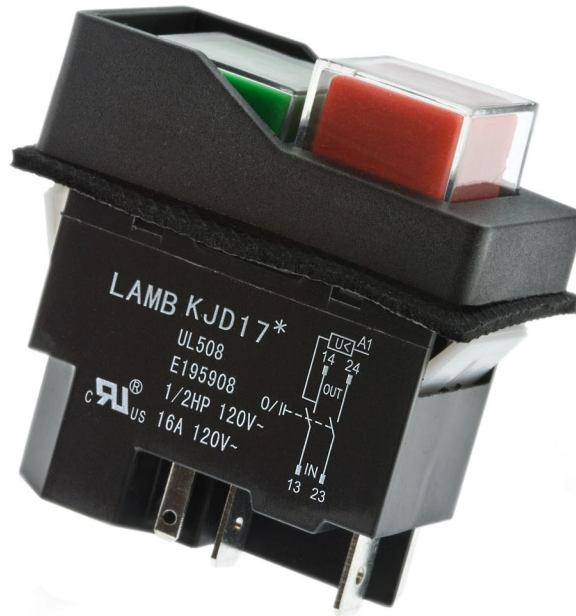

KJD17-22212-112

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE

Series	Actuation Guard	Function	Voltage and Frequency	Marking Style	Water Protection	Bezel Color	Actuator Color	Marking Color
KJD17	2 - Guarded	1 - Off-On 2 - Off-On w/ Remote Trip 3 - NO+NC w/ Remote Trip	1 - 120V-50Hz 2 - 120V-60Hz 3 - 230V-50Hz 4 - 230V-60Hz 5 - 240V-50Hz 6 - 240V-60Hz	0 - None 1 - I/O Vert. 2 - I/O Horiz. 3 - O Only	1 - None 2 - PVC Cover 3 - PVC Cover and Rubber Gasket	1 - Black 6 - Yellow	1 - Red/Green	1 - Black 2 - White

EXAMPLE PART NUMBERS:

KJD17-21213-112 2P1T Off-On
 120V 60Hz., PVC Cap, I/O Vert.

KJD17-22213-112 2P1T Off-On
 120V 60Hz., Remote Trip, PVC Cap, I/O Vert.



E-SWITCH®

www.e-switch.com

800.867.2717

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[KJD17-11411-112**](#) [KJD17-21313-112**](#)