



KJD17 Series

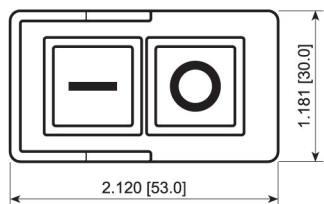

Panel Cutout




 Function Options




Remote Trip


 
Water Protection Options



PVC Cap

 

PVC Cap & Gasket

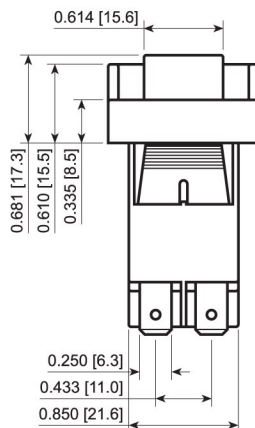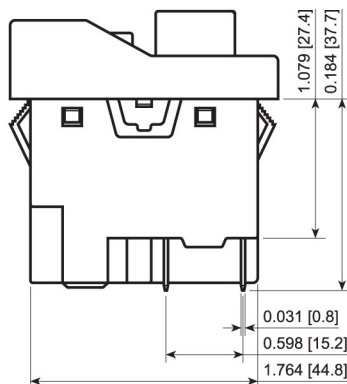

FEATURES:

- Heavy Duty Industrial Design
- Electromagnet Provides Automatic Safety Protection Against Power Outages and Restarts
- PVC Cap for Dust and Water Protection

SPECIFICATIONS:

RATING: 16A 120VAC [cURus UL508]
16A 220/240VAC [cURus UL508]
1/2 HP 120VAC [cURus UL508]
2HP 220/240VAC [cURus UL508]

TEMPERATURE: -25°C to 55°C

ELECTRICAL LIFE: 10,000 Cycles

CONTACT RESISTANCE: 50mΩ Max.

INSULATION RESISTANCE: 100MΩ Min. at 500VDC

DIELECTRIC STRENGTH: 1,500VAC for 1 Minute

INGRESS PROTECTION: IP54 with PVC Cap


MATERIALS:

BODY: Polyamide 6/6

ACTUATOR: Polyamide 6/6

CONTACTS: Silver Alloy

TERMINALS: Silver Plated Brass

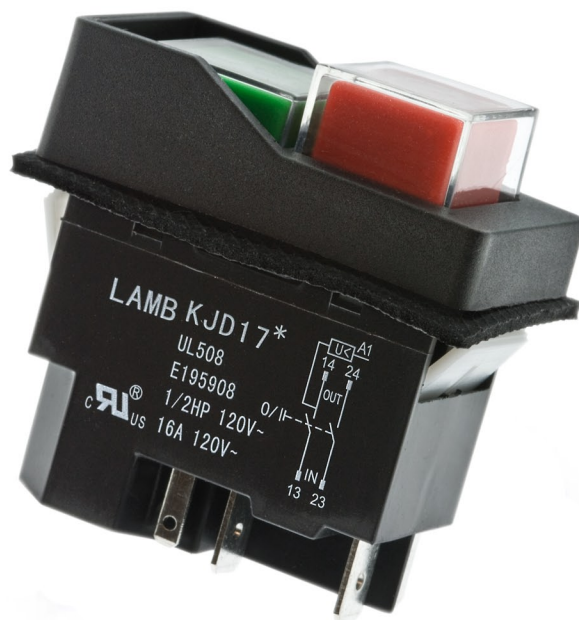

KJD17-22212-112

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE

Series	Actuation Guard	Function	Voltage and Frequency	Marking Style	Water Protection	Bezel Color	Actuator Color	Marking Color
KJD17	2 - Guarded	1 - Off-On 2 - Off-On w/ Remote Trip 3 - NO+NC w/ Remote Trip	1 - 120V~/50Hz 2 - 120V~/60Hz 3 - 230V~/50Hz 4 - 230V~/60Hz 5 - 240V~/50Hz 6 - 240V~/60Hz	0 - None 1 - I/O Vert. 2 - I/O Horiz. 3 - O Only	1 - None 2 - PVC Cover 3 - PVC Cover and Rubber Gasket	1 - Black 6 - Yellow	1 - Red/Green	1 - Black 2 - White

EXAMPLE PART NUMBERS:

KJD17-21213-112 2P1T Off-On
120V 60Hz., PVC Cap, I/O Vert.

KJD17-22213-112 2P1T Off-On
120V 60Hz., Remote Trip, PVC Cap, I/O Vert.



E-SWITCH®

www.e-switch.com

800.867.2717

PUSHBUTTON

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[KJD17-21213-112](#) [KJD17-21413-112](#) [KJD17-22213-112](#) [KJD17-22413-112](#) [KJD17-21521-612](#) [KJD17-21513-112](#)
[KJD17-21223-112](#) [KJD17-21313-112](#)